

RGB-RP is a 5-24V RGB power repeater, with 3x 3A output channels; designed to increase the quantity of colour changing of RGB tapes that can be used in one application. Suitable for domestic, commercial and retail internal lighting applications.

- Designed for extending quantity of RGB LED strip lights
- Use with one RGB controller to control multiple connections
- Provides 3 channel outputs
- Easy installation via quick connect terminals

RGB Power Repeater

Applications

- Accent Lighting
- Mood Lighting
- Cove Lighting
- Under Cabinet Lighting
- Decorative Lighting
- Display Cabinet Lighting




LOW
POWER
12V

HIGH
POWER
24V

★ LED Power Repeater Specification

Part Number	RGB-RP
Input/Output	5-24V
Output Current	3A max @ 24V, per channel
Output Channels	3
Operating Temperature	-20°C to +50°C
Dimensions	105 x 46 x 28mm (Case No: 8043DA)
Fixing Centre	97mm
Weight	66g

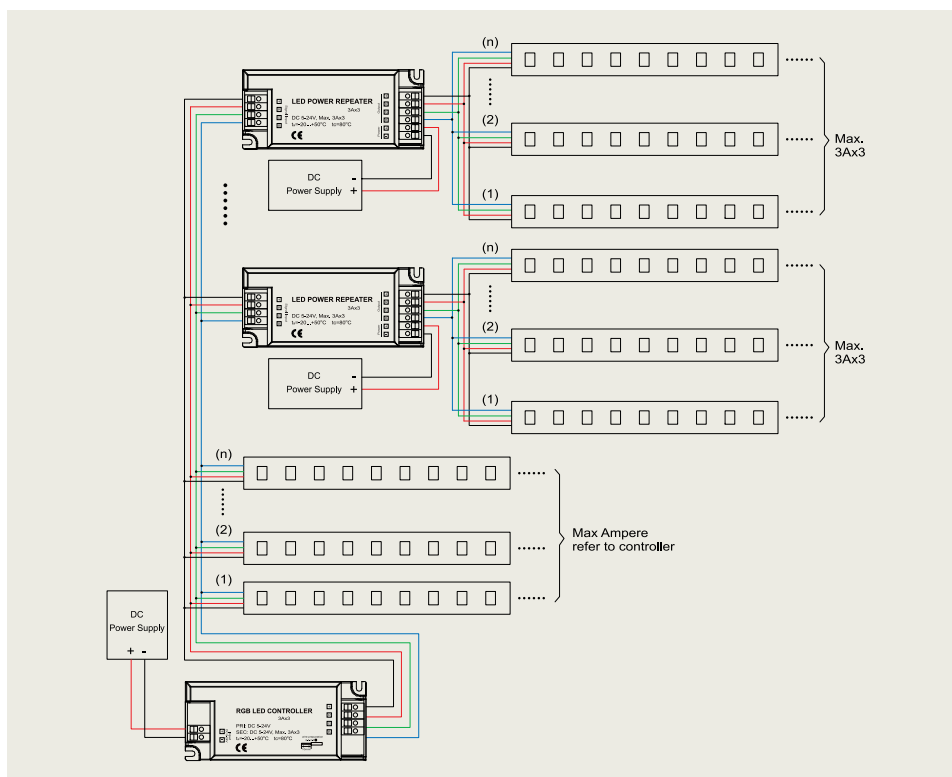

Representative colours of LED strips may change; purchase from the same batch code for colour consistency