

Sealing frame - CES-B10-HFFS-PLBK - 0801663

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Sealing frame with locking latch, size B10, with flat gasket, for 6 small sleeves



Key commercial data

Packing unit	1 pc
GTIN	4 046356 674096
Weight per Piece (excluding packing)	121.8 g
Custom tariff number	85472000
Country of origin	Poland

Technical data

Dimensions

Length	99.2 mm
Width	58.5 mm
Height	20 mm

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-40 °C ... 120 °C

General

Frame type	Sealing frame
Material	PA
Inflammability class according to UL 94	V0
Color	black
Installation instructions	One large sleeve requires the space of 4 small sleeves, M4 mounting screws
	Leak-tightness is guaranteed with underwall and perpendicular mounting; the CES-B24-WRG-BK flat gasket (supplied as standard)

Sealing frame - CES-B10-HFFS-PLBK - 0801663

Technical data

General

	should be inserted between the wall and the sealing frame in the case of wall mounting.
--	---

Classifications

eCl@ss

eCl@ss 4.0	23110102
eCl@ss 4.1	23110102
eCl@ss 5.0	23110102
eCl@ss 5.1	23110102
eCl@ss 6.0	23110102
eCl@ss 7.0	23110102
eCl@ss 8.0	23110102

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC002498
ETIM 5.0	EC002498

UNSPSC

UNSPSC 6.01	27113201
UNSPSC 7.0901	27113201
UNSPSC 11	27113201
UNSPSC 12.01	27113201
UNSPSC 13.2	27113201

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / cULus Recognized

 
Ex Approvals

Approvals submitted

Approval details

Sealing frame - CES-B10-HFFS-PLBK - 0801663

Approvals



Accessories

Accessories

Seal


Flat gasket - CES-B10-WRG-BK - 0801725



Flat gasket made of NBR, size B10


Drawings

Dimensioned drawing

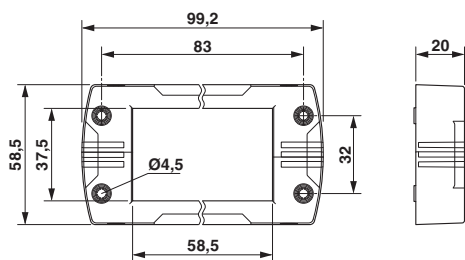

Dimensional drawing

Dimensioned drawing

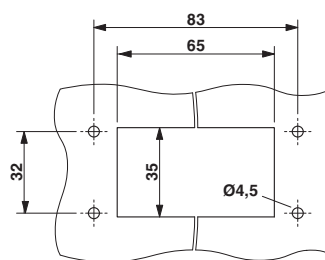

Panel cutout