


Deep groove ball bearings, single row, seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
40	90	23	42,3	24	1,02	-	5000	0,63	6308-2RS1 *

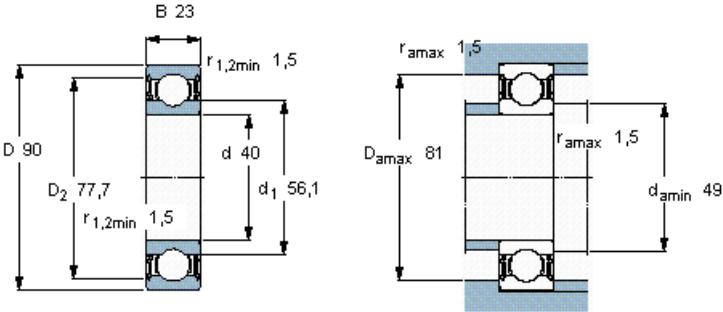

Calculation factors

k_f 0,03
 f_0 13