



Datasheet

Stock No: 267-4259

ENGLISH

RS Pro FDFNYD1 Series Red Insulated Crimp Receptacle, 2.8 x 0.5mm, 22 → 16 AWG



Product Details:

RS Pro Shrouded Female Receptacle Crimp Terminals

A range of fully insulated or shrouded double crimp female receptacle terminals made from brass with a copper sleeved barrel and flared nylon insulation. These shrouded female receptacle crimp connectors are colour coded for use with different wire sizes and accept a variety of tab sizes. For suitable crimp tool please see stock number 267-3133.



- Red 0.5 - 1.5 mm²
- Blue 1 - 2.6 mm²
- Yellow 2.5 - 6.5 mm²

Approvals

UL Listed

Specifications:

Tab Size: 2.8 x 0.5mm
 Colour: Red
 Insulation: Insulated
 Wire Size: 22 → 16 AWG
 Gender: Female
 Connector Type: Quick Disconnect Terminal
 Series: FDFNYD1
 Contact Material: Brass
 Contact Plating: Copper
 Length: 21.5mm
 Insulation Material: Nylon

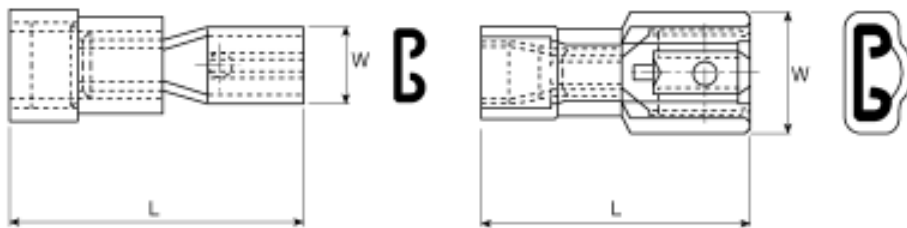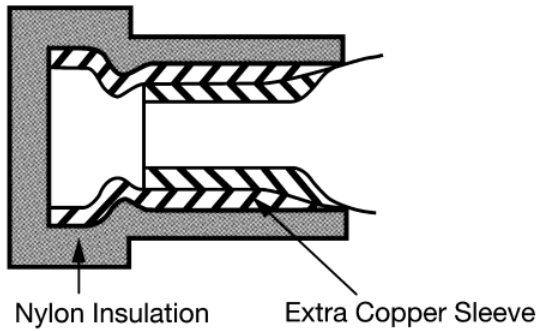

Type	Unshrouded						Shrouded					
	Red		Blue		Yellow		Red		Blue		Yellow	
	W	L	W	L	W	L	W	L	W	L	W	L
Size A	6.6	20.0	6.6	20.7	6.6	23.0	9.4	21.5	9.4	21.5	9.4	24.2
Size B	4.9	19.2	4.9	19.2			7.4	19.2	7.4	20.2		
Size C	5.0	19.2	5.0	19.2			7.4	19.2	7.4	20.2		
Size D	3.2	19.2					5.8	19.2				
Size E	3.2	19.2					5.8	19.2				