




Schneider Electric - Magnecraft Relays
1300 South Wolf Road
Des Plaines, IL 60018
Phone: 847-441-2540 • Fax: 847-881-0741
E-Mail: relays@magnecraft.com • Web site: www.sere relays.com

Item # 70-788EL11-1, 70-788EL11-1 Socket / 25 Amp Rating, 300 Volts

11 Pin Logic Style, Finger Safe, DIN Mount, Elevator Terminals, Module Compatible

This Item is Normally Stocked

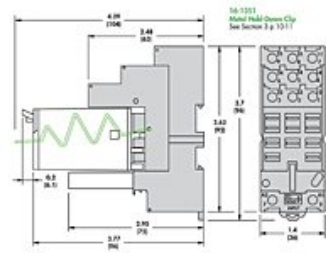

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

Specifications

Check Inventory	Check Distributor Inventory
Contact Configuration	3PDT
Number of Terminals	11
Mounting Style	DIN Rail

Electrical Rating

Current Rating	25 A
Nominal Voltage Rating	300 V

Temperature

Storage Range	- 40 to + 105 °C
---------------	------------------

Construction

Protection Category (Finger Safe)	IP 20
Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Steel Zinc Plated
Screw Style	Combination Head
Screw Size	M3.5 mm
Screw Torque 3.5 mm (Maximum)	9 / 1.0 Lb-in / Nm
Terminal Connection	Elevator
Terminal Layout	Logic
Base	Square

Miscellaneous

Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	10 / 14 (2) AWG, 6 / 2.5 (2) mm_
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	10 / 14 (2) AWG, 6 / 2.5 (2) mm_
DIN Rail Mounting, EN 60715	35 mm
Flammability Rating	94V-0 Class
Body Color	Light Gray
DIN Locking Method	Red Plastic Locking Clip

Product Certifications

Agency Approvals	CE RoHS UL CSA
------------------	-------------------------