


Deep groove ball bearings, single row, shield on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
3	10	4	0,54	0,18	0,007	130000	63000	0,0015	623-2Z

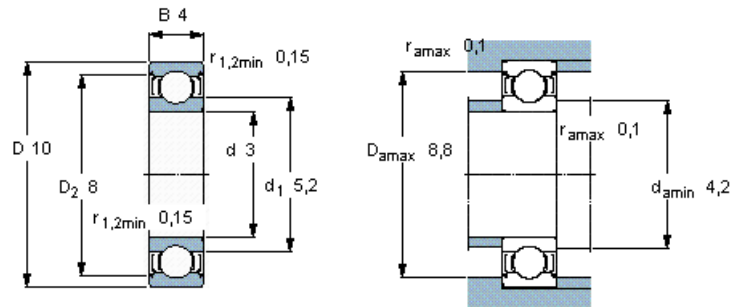

Calculation factors

k_r 0,025

f_0 7,5