


150.10 CUT-OFF, INSERTS

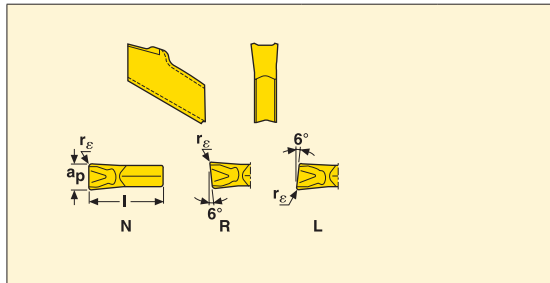

• Inserts, please see page 88-99

Size	Dimensions in inch		
	a _p	l	r _ε
1.4	0.055	0.354	0.006
2	0.078	0.354	0.006
2.25	0.088	0.354	0.006
2.5	0.098	0.354	0.007
3	0.122	0.354	0.008
4	0.161	0.354	0.009
5	0.2	0.354	0.01
6	0.25	0.354	0.012

Inserts	Part. No.	Grades						
		Coated						Uncoated
		T25M	T350M	CP500	CP600	TGP35	TGP45	HX
		EDP	EDP	EDP	EDP	EDP	EDP	
150.10-12	150.10 -2.5N-12	01967	18157	65083	06809	57890	42434	
	150.10 -2.5R6-12	24840			06810			
	150.10 -2.5L6-12	05313			06811			
	150.10 -3N-12	01398	16957	65071	48838	57886	42482	
	150.10 -3R6-12	24843			06818			
	150.10 -3L6-12	24841			06819			
	150.10 -4N-12	05308	18160	65113	48839	57889	42533	
	150.10 -4R6-12	05307						
	150.10 -4L6-12	05305						
	150.10 -5N-12	05316				57897		
	150.10 -6N-12	33982				57898		
	150.10-14	150.10 -1.4N-14			65081	07536		
150.10 -2.0N-14			18175	65075	07532		42421	55447
150.10 -2.25N-14			18177	65082	04334		42426	55448
150.10 -2.5N-14		01968	18166	65077	48841		42439	55449
150.10 -2.5R6-14		28775			06812		42461	
150.10 -2.5L6-14		28774			06813			
150.10 -3N-14		01216	16960	65111	48846	57893	42515	55450
150.10 -3R6-14		05311		65080	06838		42530	
150.10 -3L6-14		24842			06839		42467	
150.10 -4N-14		05310	16967	65073	48847	57891	42546	55451
150.10 -4R6-14		05314						
150.10 -4L6-14		05315						
150.10 -5N-14		05319		65086	48848			
150.10 -6N-14		33983		65085	48851			
150.10-16	150.10 -1.4N-16			65112	32960		42420	
	150.10 -2.0N-16		18173	65079	29843		42422	
	150.10 -2.25N-16	00845	16953	65074	00850		42433	00849
	150.10 -2.5N-16	16539	16955	65076	48853		42459	42922
	150.10 -2.5R6-16	16542			06814		42463	16543
	150.10 -2.5L6-16	16545			06816			
	150.10 -3N-16	16599	16964	65070	48854	57565	42517	16514
	150.10 -3R6-16	16518			06840	57895	42532	
	150.10 -3L6-16	16527			06841		42474	
	150.10 -4N-16	16601	16968	65072	48855	57806	42560	16515
	150.10 -4R6-16	16521					45398	16522
	150.10 -4L6-16	42904						
	150.10 -5N-16	16603		65084	48856	57790	42568	16516
	150.10 -5R6-16	16524						
	150.10 -5L6-16	16533						
	150.10 -6N-16	16548		65087	48858	57896	42584	16549