



Data Specification Sheet

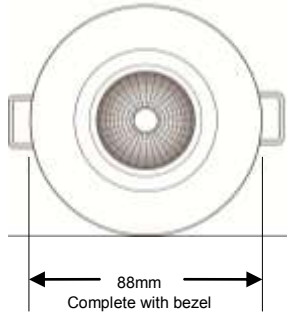

Shown with Bezel (not included)

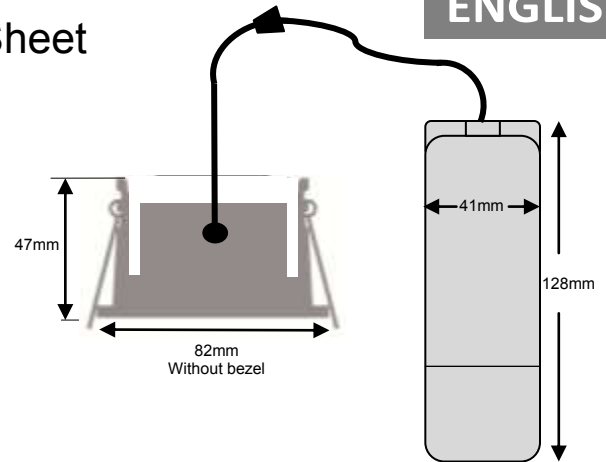

IP20 LED Fire Rated Tilt Downlight c/w Dimmable Driver

Description	IP20 LED Fire Rated Tilt Downlight c/w Dimmable Driver		
Code	851-2964 Warm White IP20 LED Fire Rated Tilt Downlight 851-2961 Cool White IP20 LED Fire Rated Tilt Downlight		
Code – Bezel Only	858-0967 Matt White Bezel	858-0951 Brass Bezel	858-0964 Chrome Bezel
	858-0955 Brushed Chrome Bezel		
Bezel Diameter	88mm		
Rim Diameter	82mm		
Cut Out	72mm		
Minimum Depth (Void)	75mm		
Total length of driver lead	300mm		
Weight	0.36Kg		
Maximum Tilt Angle	25°		
Recommended product location	Indoor Outdoor		
Finishes available (Bezels sold separately)	Matt White, Brass, Chrome, Brushed Chrome		
Control Gear Type	8W 180mA SELV LED Dimmable Driver supplied pre-wired to downlight		
Lamp Supplied	Fixed non-replaceable 8W COB LED		
Class	Class II. Must not be Earthed		
IP	IP20		
Photometric Testing	Yes		
Lumen Output	460lm Warm White – 530lm Cool White		
Beam Angle	38°		
Dimmable	Yes		
Instruction sheet	Yes		
Origin of manufacture	China		
Main materials:			
• Chassis	Pressed Steel		
• Body	Die cast		
• Bezel	Die cast		
Method of fix	Twin fixed spring		
Electrical Connections	Loop in 10Amp L.N. + Earth Park Nylon Connector, Push-in Terminals		
CE mark	Yes		
Batch coding details on product	Yes		
Certificate of Conformity (Held on File)	Yes		
Manufactured in accordance	EN60598-1 General requirements EN60598-2-1 Fixed general purpose luminaires EN60598-2-2 Recessed luminaires Part P (Installation requirements) BS476 – Part 21 & Part 23 Fire rating		