

Elite shaverlight (with push plate and shaver socket)

ELITE WHITE 11W LYNX-S PUSH PLATE+SHAVER

0053400



Product features

- Slim profile 11w compact fluorescent shaverlight for either vertical or horizontal surface mounting which is suitable for Zone 3 bathroom applications (no waterjets). Luminaire comes complete with push plate for switching of the lamp, dual voltage (120V/240V) shaver socket and 11w Lynx-S warm white (2700K) lamp. White finish.



PRODUCT OVERVIEW

| | |
|-------------------------------|--|
| Certifications | CE |
| Colour temperature (K) | 2700 |
| Colour | White |
| Control gear mounting | Integral |
| Control gear type | Conventional |
| CRI (Ra) | 80 |
| Product EAN number | 5410288534008 |
| Electrical protection | Class II |
| Environment | Internal |
| General application | Hospitality, Residential & Consumer |
| IP rating | IP21 |
| Product code | 0053400 |
| Light colour | Warm white |
| Mount | Wall Surface |
| Product name | ELITE WHITE 11W LYNX-S PUSH PLATE+SHAVER |
| Included lamp | 0025883 |
| ETIM Class | EC002892 |

DATA TABLE

General data

| | |
|----------------------------|--|
| Certifications | CE |
| Environment | Internal |
| General application | Hospitality, Residential & Consumer |
| Product code | 0053400 |
| Mount | Wall Surface |
| Product name | ELITE WHITE 11W LYNX-S PUSH PLATE+SHAVER |
| ETIM Class | EC002892 |

Optical data

| | |
|-------------------------------|------|
| Colour temperature (K) | 2700 |
|-------------------------------|------|

Elite shaverlight (with push plate and shaver socket)

ELITE WHITE 11W LYNX-S PUSH PLATE+SHAVER

0053400

| | |
|--------------------------------|------------|
| CRI (Ra) | 80 |
| Distribution type | Symmetric |
| Light colour | Warm white |
| Adjustable chromaticity | N |

Electrical data

| | |
|--|--------------|
| Control gear mounting | Integral |
| Control gear type | Conventional |
| Electrical protection | Class II |
| Energy efficiency level | A |
| kWh per 1000 hours burning time | 14 |
| Mains voltage (V) | 100-240V~ |

 
Physical data

| | |
|------------------------------------|-------|
| Colour | White |
| Diffuser finish | Opal |
| Nominal Product Height (mm) | 92 |
| IP rating | IP21 |
| Nominal Product Length (mm) | 480 |
| Weight (kg) | 1.292 |
| Nominal Product Width (mm) | 50 |

Packaging

| | |
|-------------------------------------|---------------|
| Product EAN number | 5410288534008 |
| Packaging single height (cm) | 52.9 |
| Packaging single length (cm) | 5.3 |
| Single packaging type | Carton |
| Packaging single width (cm) | 12.3 |
| Units per outer package | 1 |
| Packaging outer height (cm) | 5.3 |
| Packaging outer length (cm) | 52.9 |
| Packaging outer width (cm) | 12.3 |

TECHNICAL DRAWINGS




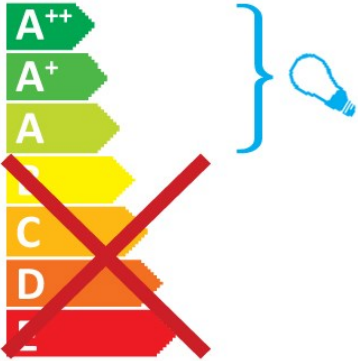
Elite shaverlight (with push plate and shaver socket)

ELITE WHITE 11W LYNX-S PUSH PLATE+SHAVER


0053400


SYLVANIA 0053400

 This luminaire is compatible with bulbs of the energy classes:





This luminaire is sold with a bulb of the energy class:

874/2012 

 This luminaire is compatible with bulbs of the energy classes:

This luminaire is sold with a bulb of the energy class:

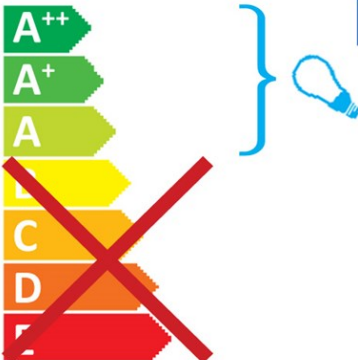

SYLVANIA 0053400  874/2012