

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [52207-1433](#)
Status: **Active**
Overview: [FFC-FPC \(SMT\)](#)
Description: FFC/FPC Connector, Right-Angle, SMT, ZIF, Top Contact Style Receptacle, 14 Circuits, Lead-Free, High Barrier Packaging

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-52207-009 \(PDF\)](#)
[Packaging Specification SPK-52207-002 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family FFC/FPC Connectors
Series [52207](#)
Overview [FFC-FPC \(SMT\)](#)
Product Name Easy-On™
UPC 887191276526

Physical

Circuits (Loaded) 14
Color - Resin Natural
Contact Position Top
Durability (mating cycles max) 30
Entry Angle 90° Angle
Flammability 94V-0
Mated Height 2.70mm
Material - Metal Phosphor Bronze
Material - Plating Mating Silver, Tin-Bismuth
Material - Plating Termination Silver, Tin-Bismuth
Material - Resin Nylon
Net Weight 547.800/mg
Number of Rows 1
Orientation Right Angle
PC Tail Length 2.00mm
PCB Locator No
PCB Retention Yes
Packaging Type Embossed Tape on Reel
Pitch - Mating Interface 1.00mm
Pitch - Termination Interface 1.00mm
Polarized to PCB Yes
Stackable No
Temperature Range - Operating -30°C to +85°C
Termination Interface: Style Surface Mount
Wire/Cable Type FFC/FPC


Electrical

Current - Maximum per Contact 1A
Voltage - Maximum 125V

Material Info

Reference - Drawing Numbers

Packaging Specification SPK-52207-002

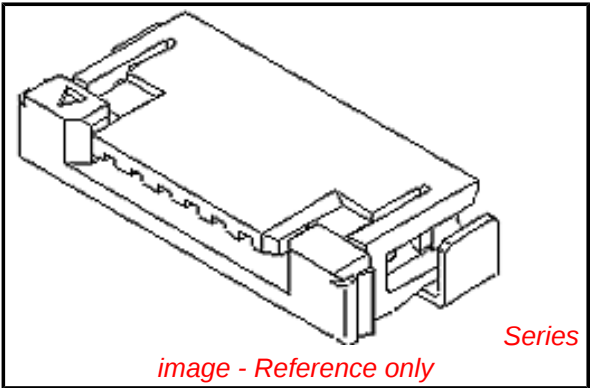

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[52207Series](#)

This document was generated on 10/22/2013

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION