



The supplier acknowledges that, with the acceptance of the drawing, he is in a position to manufacture the illustrated part in accordance with the drawing in reproducible form and series production. Through the selected manufacturing processes no impairments will arise in the material and structure which could subsequently lead to an impairment of the component. Verbal agreements over and above that are not valid. Deviations from this rule must be written and must be signed by the purchaser.

This drawing may not be copied, reproduced or made available to third parties in any way whatsoever without or prior written approval.

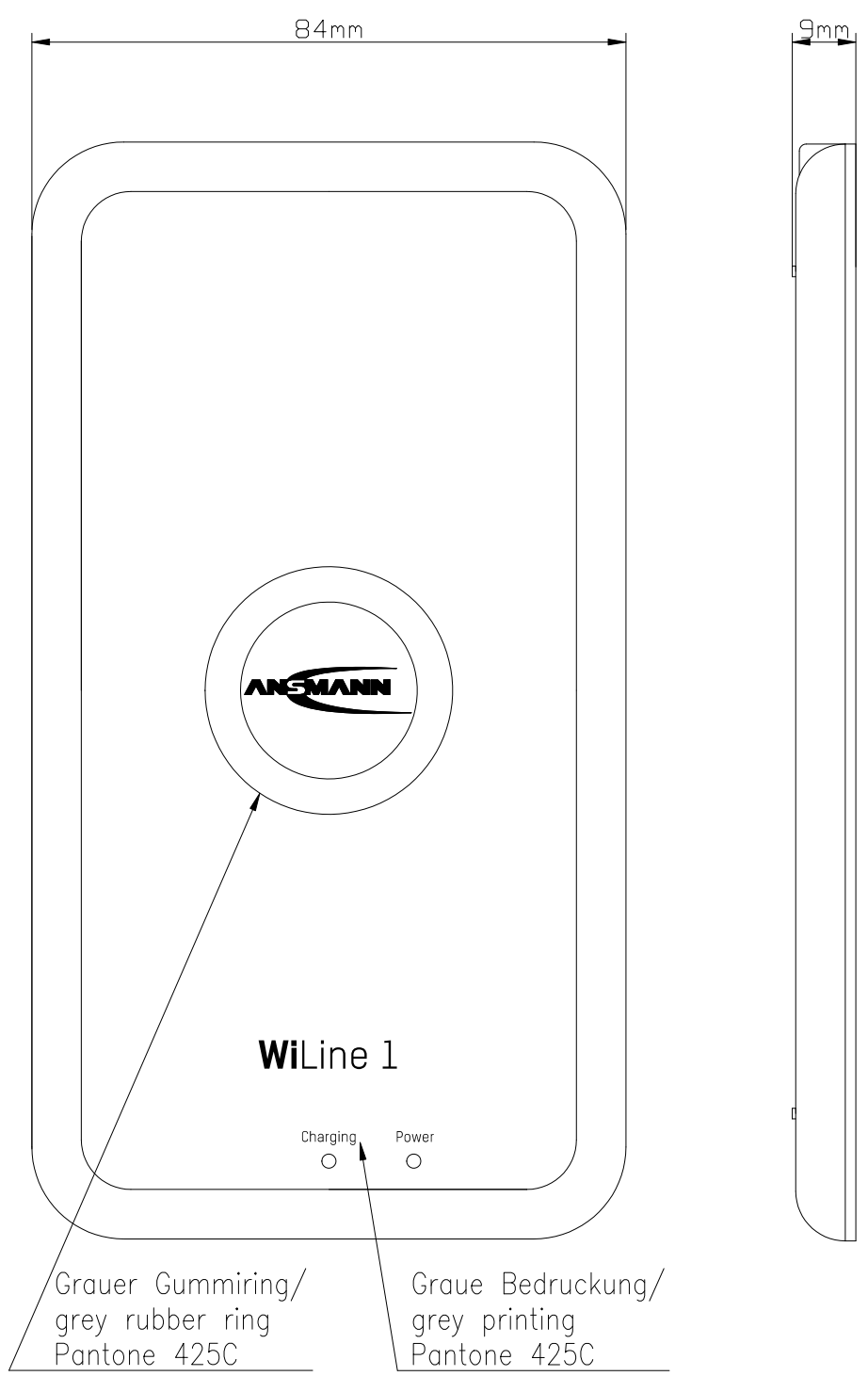

Grauer Gummiring/  
grey rubber ring  
Pantone 425C

Graue Bedruckung/  
grey printing  
Pantone 425C

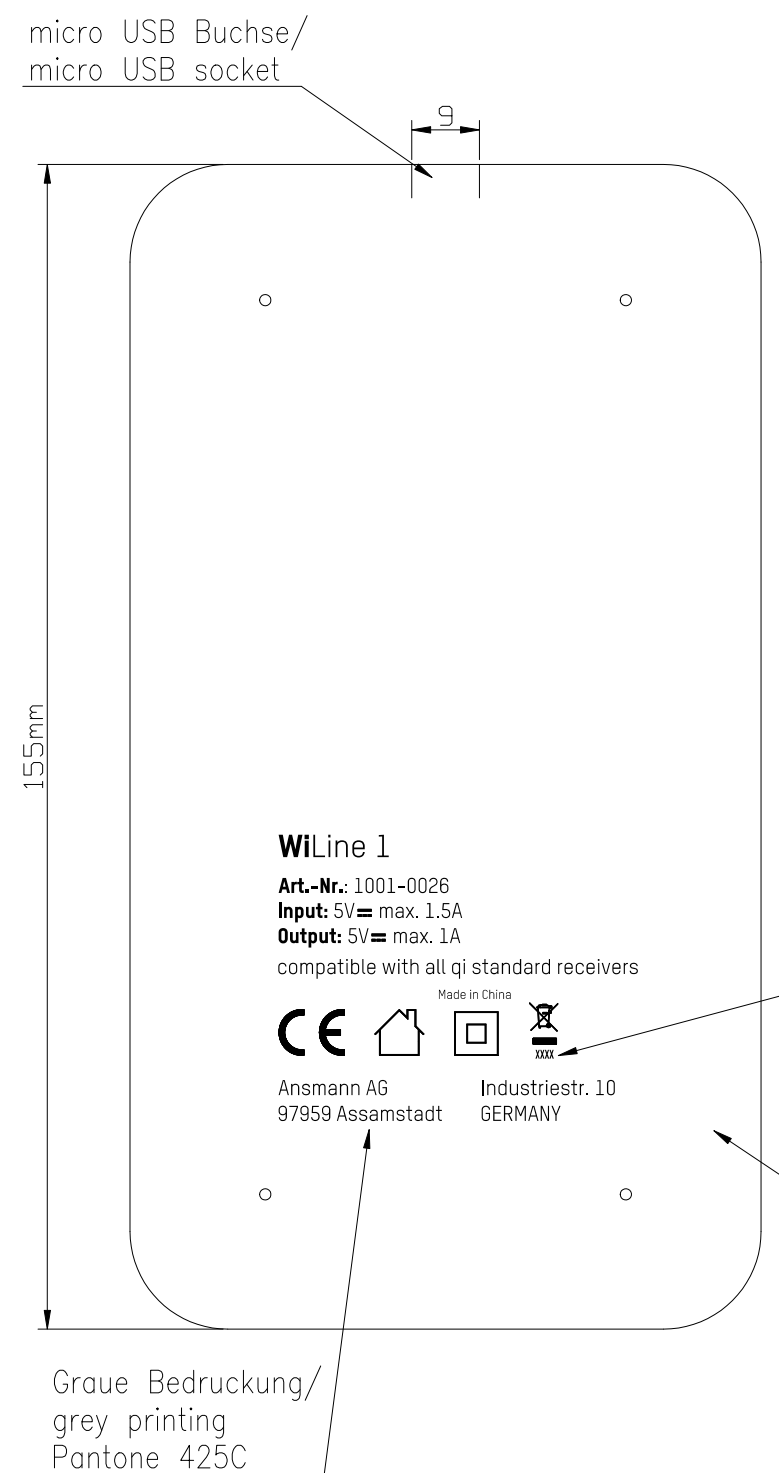


Graue Bedruckung/  
grey printing  
Pantone 425C

Technische Daten/  
technical data

Eingangsspannung/ input voltage	: 5V ±5%
Eingangsstrom/ input current	: max. 1500mA
Schutzart/ protection	: IP 20
Betriebstemperatur/ operating temperature	: 0°C.....+25°C
Lagertemperatur/ storage temperature	: -25°C.....+70°C
Gewicht/ weight	: 113g inkl. Zubehör, ohne Verpackung/ 113g incl. accessories, without package
Gehäuse/ CASE	: Tischgehäuse schwarz gummiert desktop housing black rubber coated
Gehäusematerial/ case material	: ABS plastic
Zubehör/ accessories	: USB -> micro USB Kabel USB -> micro USB cable
Approbation/ approval	: CE

Verschlüsseltes Produktionsdatum/  
date code (coded production date)

Schwarzes Gehäuse, gummiert/  
black housing, rubber coated

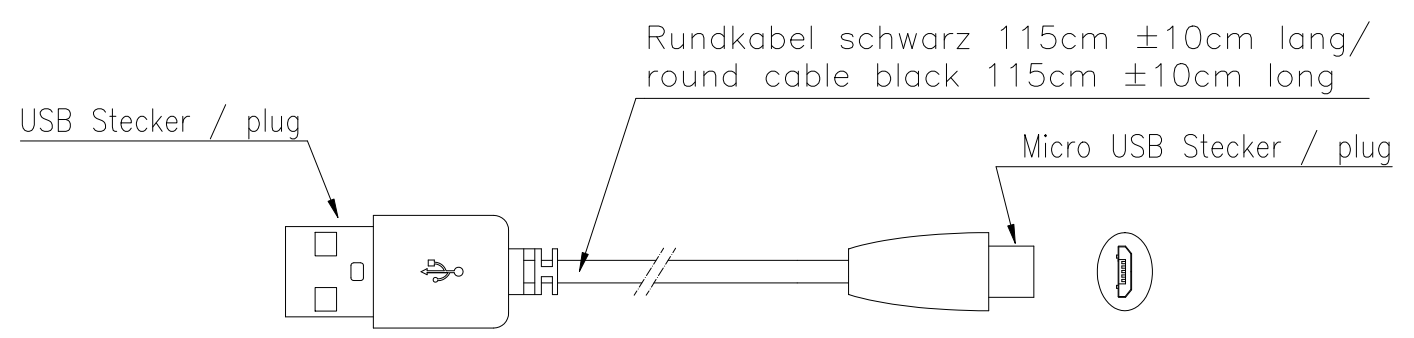

Application range for inquiry		Allowable deviation general tolerances		Surface		Model:		Material:	
		DIN ISO 2768-m				Scale (DIN A3): 1:1		All dimensions in mm	
		2014		Date		Name		Weight:	
		Drawn by		24.07		CB		Drawing name	
		Approved by						WiLine 1	
Version		Change		Date		Name		Drawing number Part number	
V0		---		24.07.14		CB		1001-0026	
Project: 0070614		Replaced by:		Replacement through:		Sheet 1/1			

