

 
Product selected: Sylproof Superia PC T8 26mmØ 2x58W lamp with A2 ballast & 3H emergency

Moisture proof diffuser luminaire. Housing made of polycarbonate. Colour light grey. With top and fitting end cut outs for mains supply and further wiring as well as for through wiring by means of heat resistant internal wiring. Injection mulded diffuser with internal prism for even lighting distribution. Diffuser fixed to the body by using stainless steel clips. Inject gasket for high IP rate. Aluminium reflector. Gear tray made of steel, saved by maintenance cord. D-Mark for electronic ballast version. Polyurethane seal gasket

Product Image



Product Line Drawing




Lamp	L	I	H	F
1 x 18/14/24 - 2x14/24	662	92	99	400
1 x 36/28/54 - 2x28	1285	92	99	900
1 x 58/35/49/90 - 2x35/49	1565	92	99	930
1 x 70	1865	92	99	1026
2 x 18	662	137	99	400
2 x 36/54	1285	137	99	900
2 x 58	1565	137	99	930
2 x 70	1865	137	99	1026

Lamp(s)

No Image No Image

Light distribution

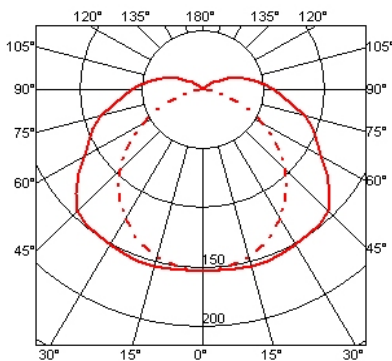

Product Details

Order code	0056177
Item name	Sylproof Superia PC T8 26mmØ 2x58W lamp with A2 ballast & 3H emergency
Mounting	Ceiling pendant, Ceiling surface
Technical description	Polycarbonate body & diffuser. Stainless steel fixing
Place of use	Interior
Colour	Grey
Length (mm)	1565
Width (mm)	137
Height (mm)	99
Weight (kg)	3.5
Housing	Polycarbonate
Shock resistance	2 J
Distribution type	Symmetric
Diffuser finish	Prismatic
Diffuser material	Polycarbonate
LOR (%)	62%
Reflector finish	Aluminium
Reflector material	Polycarbonate
Lamps description	2 x 58W T26 G13
Lamp included	No
Number of heads	1
Control gear availability	Included
Control gear type	Electronic
Control gear description	Electronic ballast with reduced losses
Control gear mounting	Integral
Emergency	Included
Emergency type	Integral
Emergency mode	Maintained
Emergency duration	3 Hours
T Class Max	25°C
T Class Min	0°C
Voltage (V)	220-240

Certifications

