

compacPRO



Overview 0

Cabinets 1

Wall mounted
cases 2

Accessories for
cabinets and wall
mounted cases 3

Climate control 4

Desk-top cases 5

Subracks/
19" chassis 6

Front panels,
plug-in units 7

Systems 8


Power supply
units 9

Backplanes 10


Connectors, front
panel component
system 11

Appendix 12

Desk-top cases - *compacPRO*

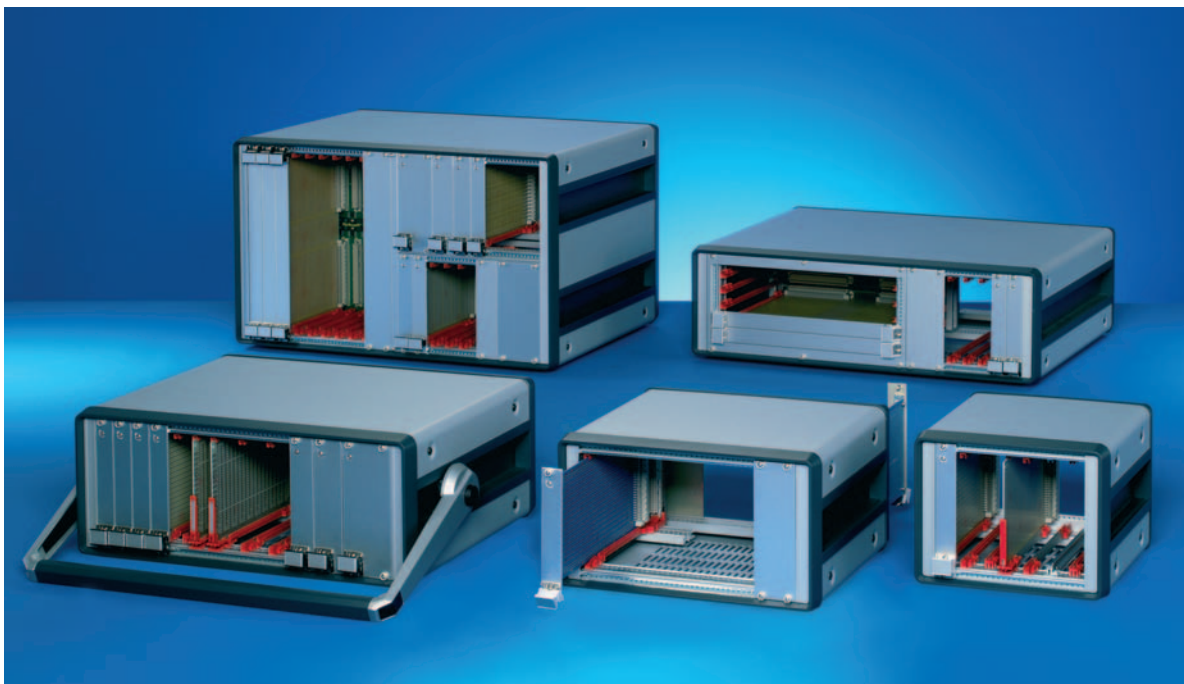

01503009

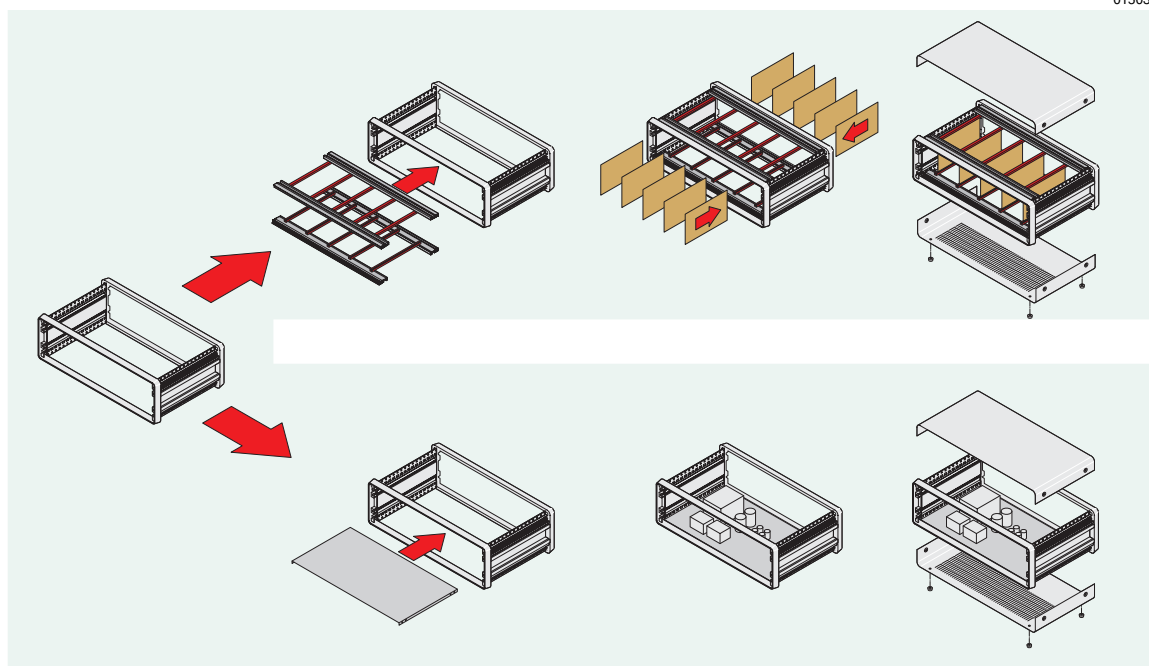

Various mounting possibilities

02004079

Standards

- Internal dimensions according to IEC 60297-3
- Type of protection IP 20 according to IEC 60529
- Protective GND/earth connection according to EN 50178 / EN 60950 / EN 610101 / EN 610101A2

Modifications

- Special colours
- Special depths
- Cut-outs in cover, base plate or side panels
- Printing of front and rear panels
- Customised assembly service



Further important information can be found on the internet
under www.schrack.biz




Desk-top cases - *compacPRO*

Overview 5.72

Robust desk-top case or portable case

- Simple assembly and multiple mounting possibilities
- Identical front and rear sides
- Various versions
- For 19" components or individual electrical equipment
- The solution for good value

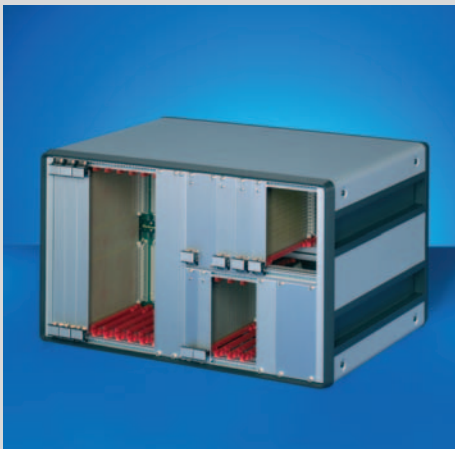

02004003

Desk-top case

- 2 ...6 U

Cases


2, 3, 4 U 5.74
6 U 5.75

compac accessories

Front panels /
rear panels 5.76
Filler angles 5.77
Cable holders 5.77
Rear panel feet 5.78
Tip-up protection 5.78
Feet 5.79
Hoods 5.79
Tip-up carrying
handles 5.80
Front doors, acrylic
glass, folding /
hinged 5.81
Tip-up feet 5.82
Earthing kit 5.82
Assembly positions
horizontal / centre
rails 5.83
Threaded inserts,
insulation strips 5.85
Z-rails,
perforated rails 5.85
Guide rails 5.86
Chassis plates 5.87
Mounting strips for
chassis plate 5.88
Dimensions 5.89

Various versions

- 2, 3, 4 and 6 U in 4 widths and 4 depths

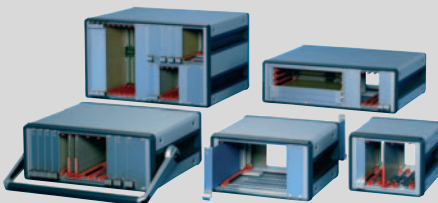

02004009

Version

- Desk-top case with carrying handle




02004002

FRONT PANEL
FAST TRACK




Desk-top cases - *compacPRO*



Case 2, 3 and 4 U

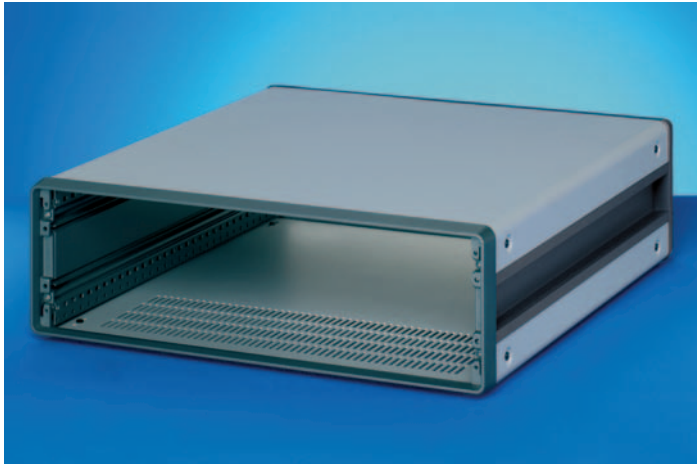

02004005

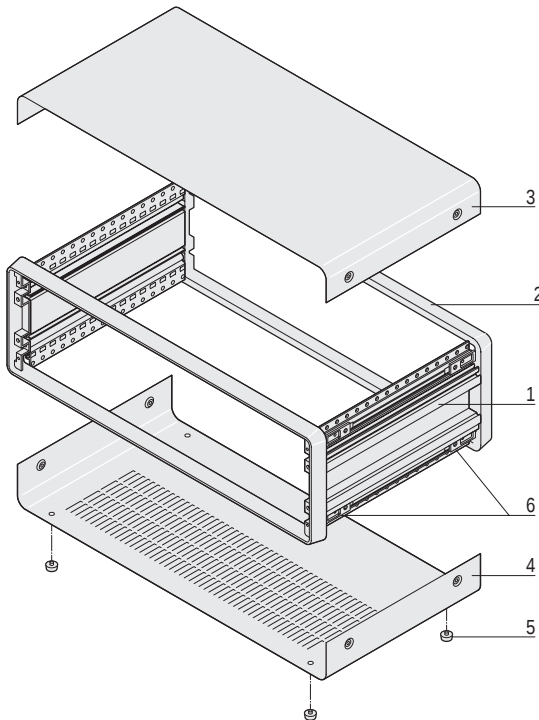

02004053

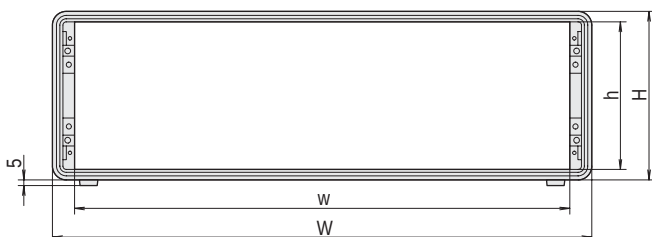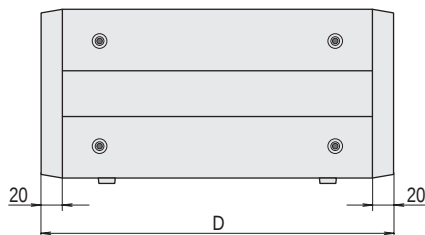

02004054

Delivery comprises (kit, item 1 and 2 assembled)

Item	Qty	Description
1	2	Side panel, Al extrusion, RAL 7016
2	2	Frame, Al die-cast, RAL 7016
3	1	Cover, Al, 1.5 mm, RAL 9006, with GND/earthing connection
4	1	Base with perforation, Al, 1.5 mm, RAL 9006, with GND/earthing connection
5	4	Case foot with anti-slip protection, PC, black
6	8	Mounting adaptor cover plate, pre-mounted
7	1	The assembly kit allows to assemble a full-width front panel and a rear panel additionally

Order Information

Height U	Usable width HP	Width W mm	Width w mm	Height H mm	Height h mm	Depth D mm	Order no.
2	42	257	219	102.6	84.4	271	14575-023
2	42	257	219	102.6	84.4	331	14575-025
2	42	257	219	102.6	84.4	391	14575-027
2	84	471	432	102.6	84.4	271	14575-063
2	84	471	432	102.6	84.4	331	14575-065
2	84	471	432	102.6	84.4	391	14575-067
3	28	186	148	147.1	129.3	271	14575-103
3	28	186	148	147.1	129.3	331	14575-105
3	42	257	219	147.1	129.3	271	14575-123
3	42	257	219	147.1	129.3	331	14575-125
3	42	257	219	147.1	129.3	391	14575-127
3	63	364	326	147.1	129.3	271	14575-143
3	63	364	326	147.1	129.3	331	14575-145
3	63	364	326	147.1	129.3	391	14575-147
3	84	471	432	147.1	129.3	271	14575-163
3	84	471	432	147.1	129.3	331	14575-165
3	84	471	432	147.1	129.3	451	14575-169
3	84	471	432	147.1	129.3	511	14575-171
4	42	257	219	191.6	173.8	271	14575-223
4	42	257	219	191.6	173.8	331	14575-225
4	63	364	326	191.6	173.8	271	14575-243
4	63	364	326	191.6	173.8	331	14575-245
4	63	364	326	191.6	173.8	391	14575-247
4	84	471	432	191.6	173.8	331	14575-265
4	84	471	432	191.6	173.8	391	14575-267
4	84	471	432	191.6	173.8	451	14575-269
4	84	471	432	191.6	173.8	511	14575-271




For further information www.schroff.biz/oneclick
oneClick code = Order no.




Desk-top cases - *compacPRO*



Case 6 U

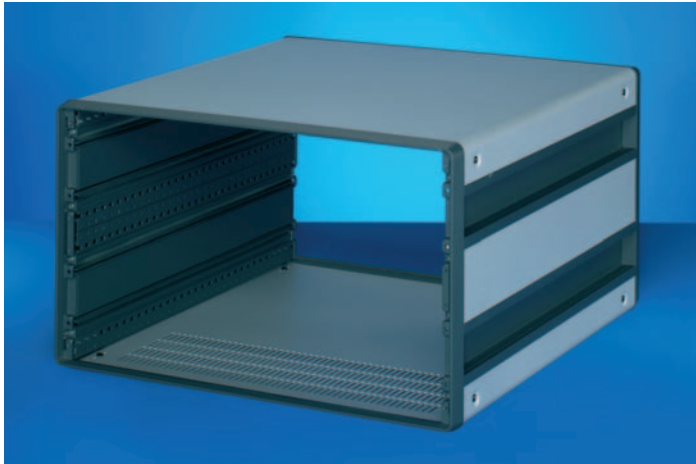

02004006

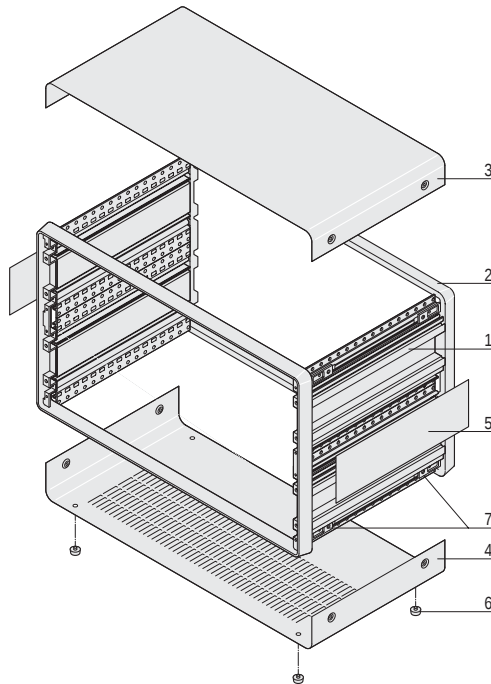

02004055

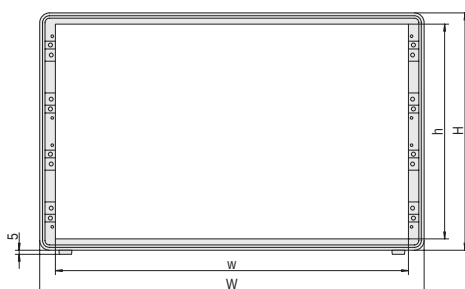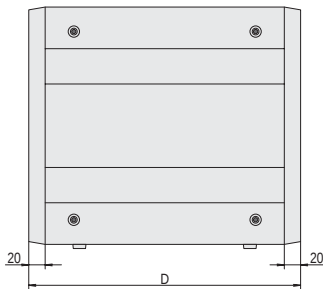

02004056

Delivery comprises (kit item 1, 2 and 5 assembled)

Item	Qty	Description
1	4	Side panel sections, Al extrusion, RAL 7016, 2 x 3 U
2	2	Frame, Al die-cast , RAL 7016
3	1	Cover, Al, 1.5 mm, RAL 9006, with GND/earthing tag
4	1	Base with perforation, Al, 1.5 mm , RAL 9006, with GND/earthing connection
5	2	Side, Al, 0.8 mm, RAL 9006
6	4	Case foot with anti-slip protection, PC, black
7	8	Mounting adaptor, pre-mounted
8	1	The assembly kit allows to assemble a full-width front panel and a rear panel

Order Information


Usable width HP	Width W mm	Width w mm	Height H mm	Height h mm	Depth D mm	Order no.
63	364	326	280.5	262.9	331	14575-445
63	364	326	280.5	262.9	391	14575-447
84	471	432	280.5	262.9	271	14575-463
84	471	432	280.5	262.9	331	14575-465
84	471	432	280.5	262.9	391	14575-467
84	471	432	280.5	262.9	451	14575-469
84	471	432	280.5	262.9	511	14575-471



For further information www.schroff.biz/oneclick
oneClick code = Order no.

Desk-top cases - *compacPRO*

Front panel / rear panel

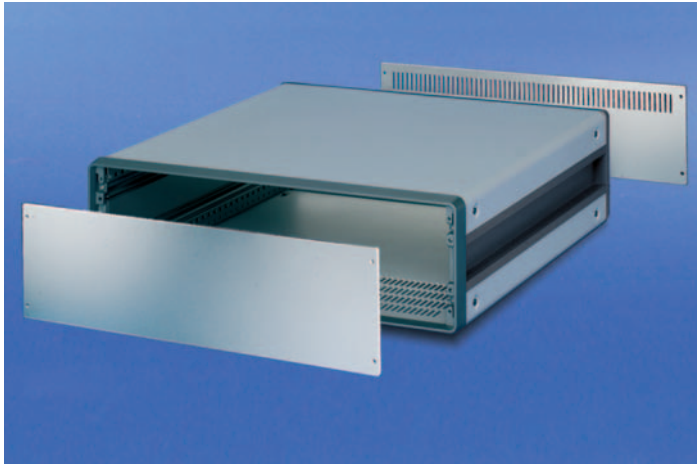

- Front panels and rear panels are screwed on front or backframe of case

Delivery comprises (kit)

Item	Qty	Description
1	1	Rear panel with perforation, Al anodised, cut edges plain, 28, 42, 63 HP = 2 mm thick; 84 HP = 2.5 mm
2	1	Front panel without perforation, Al anodised, cut edges plain, 3 mm


Order Information

Height U	Width HP	Height H mm	Height h mm	Width B mm	Width b mm	Rear panel Order no.	Front panel Order no.
2	42	84	66	238.7	226.3	30823-015	30823-209
2	84	84	66	452.1	439.7	30823-512	30823-215
3	28	128.4	100	167.5	155.1	30823-021	30823-254
3	42	128.4	100	238.7	226.3	30823-024	30823-257
3	63	128.4	100	345.4	333.1	30823-027	30823-224
3	84	128.4	100	452.1	439.7	30823-515	30823-260
4	42	172.9	144.5	238.7	226.3	30823-033	30823-269
4	63	172.9	144.5	345.4	333.1	30823-036	30823-227
4	84	172.9	144.5	452.1	439.7	30823-518	30823-272
6	63	261.8	233.4	345.4	333.1	30823-045	30823-230
6	84	261.8	233.4	452.1	439.7	30823-521	30823-284

Note


- The delivery of the cases contains an assembly kit for the assembly of a rear and a front panel

Rear panel / front panel

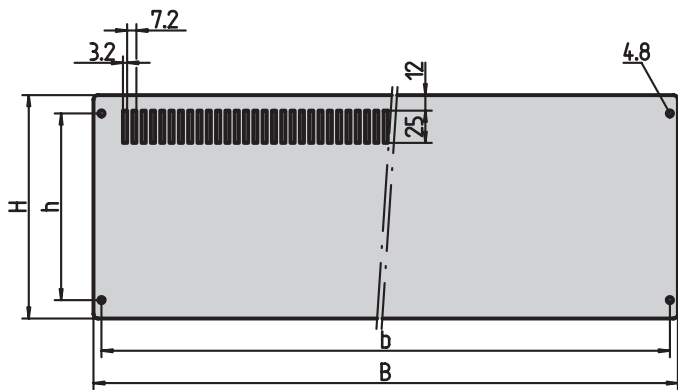

CPA30656

Front panel / rear panel, assembly parts not visible

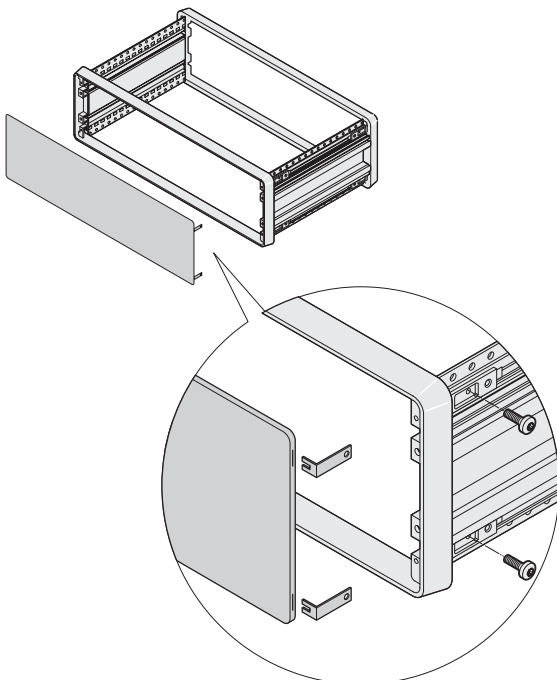

Delivery comprises (kit)

Item	Qty	Description
1	1	Front panel, Al anodised, cut edges plain, 2.5 mm
2	4	Mounting bracket
3	1	Assembly kit


Order Information

Height U	Width HP	Height H mm	Height h mm	Width B mm	Width b mm	Order no.
2	42	84.0	66.0	238.7	226.3	24575-035
2	84	84.0	66.0	452.1	439.7	24575-075
3	28	128.4	100.0	167.5	155.1	24575-115
3	42	128.4	100.0	238.7	226.3	24575-135
3	63	128.4	100.0	345.4	333.1	24575-155
3	84	128.4	100.0	452.1	439.7	24575-175
4	42	172.9	144.5	238.7	226.3	24575-235
4	63	172.9	144.5	345.4	333.1	24575-255
4	84	172.9	144.5	452.1	439.7	24575-275
6	63	261.8	233.4	345.4	333.1	24575-455
6	84	261.8	233.4	452.1	439.7	24575-475


02004061

Desk-top cases – *compacPRO*

Filler angle

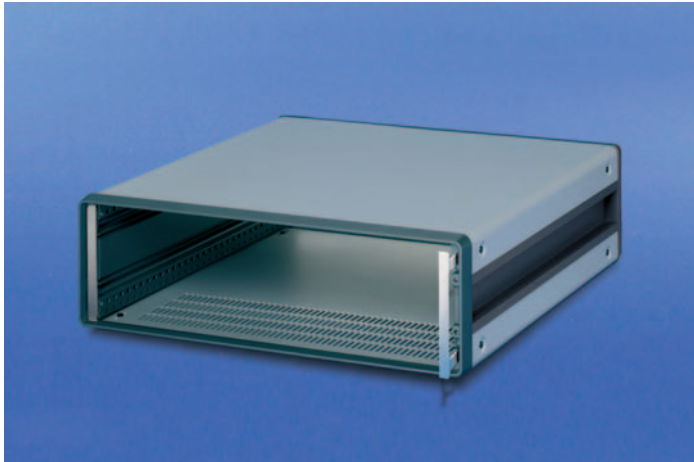

02005002

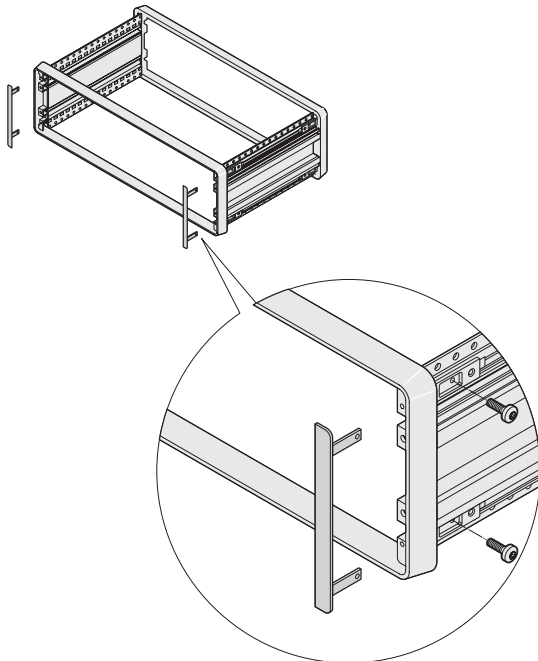

02004062

- For lateral covering of the frame and to set up a consistent front level with front panels and plug-in units

Delivery comprises (kit)

Item	Qty	Description
1	2	Filler angle, Al extrusion, anodised, plain cut edges

Order Information

Height	Order no.
U	
2	24575-019
3	24575-119
4	24575-219
6	24575-419


Note

- The delivery of the cases contains an assembly kit




For further information www.schroff.biz/oneclick
oneClick code = Order no.

Cable holder

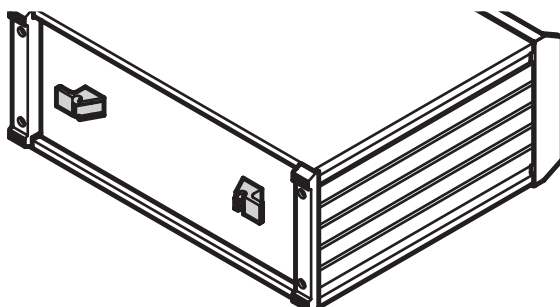

PPA45107

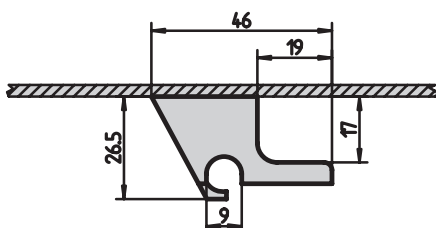

PPA45110

Delivery comprises (kit)

Item	Qty	Description
1	2	Cable support, ABS, UL 94 V-0, RAL 7016, for cables between 8 mm and 12 mm
2	1	Drilling template, two holes in rear panel for each cable support
3	1	Assembly kit

Order Information

Description	Order no.
Cable holder	24575-800



For further information www.schroff.biz/oneclick
oneClick code = Order no.




Desk-top cases - *compacPRO*

Rear panel foot



02005004

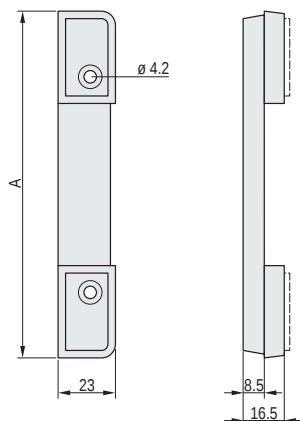

02004063

Delivery comprises (kit)

Item	Qty	Description
1	2	Feet with rubber insert, PC, UL 94 V-0, RAL 7016
2	1	Assembly kit


Order Information

For case height	A	Order no.
U	mm	
3	139	24575-114
4	183.5	24575-214



For further information www.schroff.biz/oneclick
oneClick code = Order no.

Tip-up protection

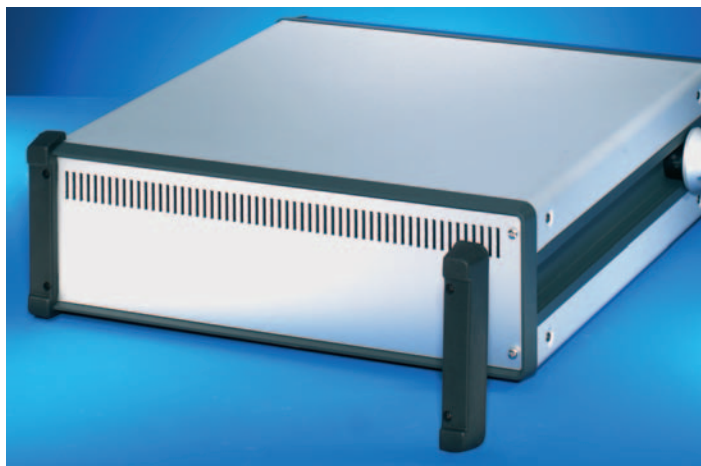

02005005

Delivery comprises

Item	Qty	Description
1	2	Tip-up protection, PU foam, black
2	1	Assembly kit

Order Information


For case height	Order no.
U	
3	20823-675
4	20823-676



For further information www.schroff.biz/oneclick
oneClick code = Order no.


Desk-top cases - *compacPRO*

Foot made of plastic foam

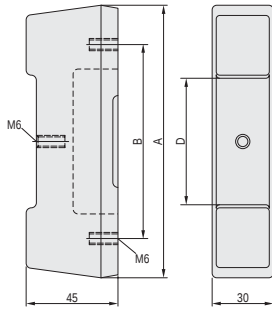

02004065

Dimension for modification of the rear panel

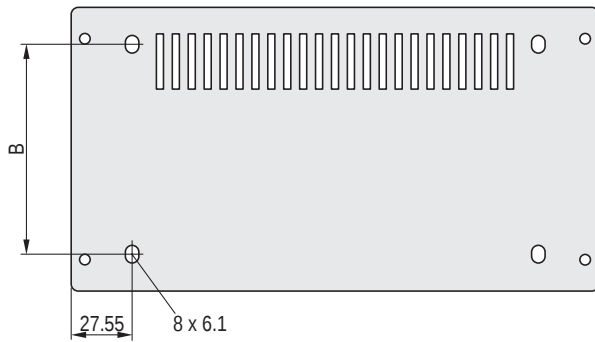

02004066

Delivery comprises (kit)

Item	Qty	Description
1	2	Feet, PU foam, black, 75° shore
2	1	Assembly kit

Order Information

Height U	A mm	B mm	D mm	Order no.
3	133.5	95	65	20823-668
4	177.8	139.5	95	20823-669

■ Rear panel, see page 5.76



For further information www.schroff.biz/oneclick
oneClick code = Order no.

Hood



02005006

Delivery comprises (kit)

Item	Qty	Description
1	1	Hood, ABS, RAL 7016, wall thickness < 4 mm
2	1	Assembly kit

Order Information


Height U	Width HP	A mm	Order no.
3	42	267	24575-136
3	63	373.5	24575-156
3	84	480	24575-176
Cable support PC, black, UL 94 V-0, PU 2 pieces			20823-674

Note

- To install hood the following parts must be assembled on the case:
- Foot, plastic foam, see page 5.79
- Rear panel, see page 5.76




For further information www.schroff.biz/oneclick
oneClick code = Order no.

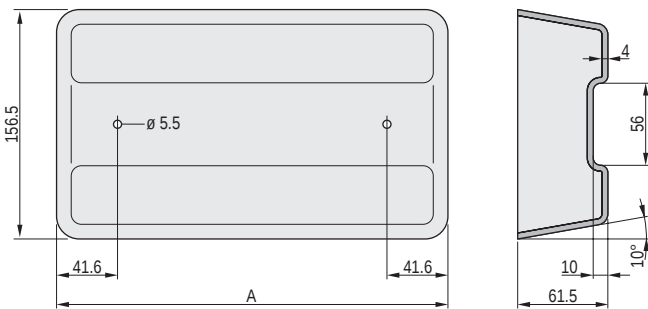

02004064

Cable support

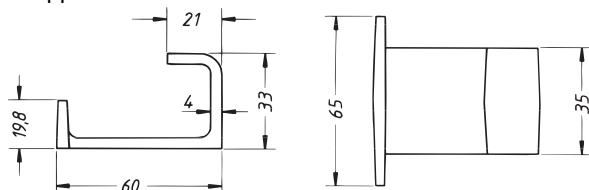

A4-512



Desk-top cases - *compacPRO*

Tip-up carrying handle



02004002

- With powder-coated handle bar
- Handle bar adjustable in 30 degree increments by pressing button
- Load-carrying capacity 20 kg

Delivery comprises (kit)



Item	Qty	Description
1	1	Carrying bar, Al profile, painted RAL 7016
2	2	Handle side section, Zn die-cast, powder coated, length 180 mm
3	2	Safety insert, St, 1.5 mm, black
4	1	Assembly kit incl. drilling template for side panel

Order Information

For case height	Width	Order no.
U	HP	
2	42	24575-038
2	84	24575-078
3, 4	28	24575-118
3, 4	42	24575-138
3, 4	63	24575-158
3, 4	84	24575-178

Dimensions

Case width	a	b	c
HP	mm	mm	mm
28	249.32	180.32	202.72
42	320.44	251.44	273.84
63	427.12	358.12	380.52
84	533.80	464.80	487.20

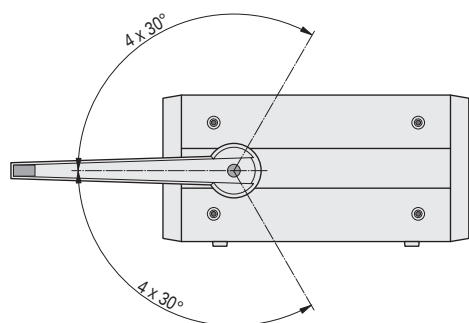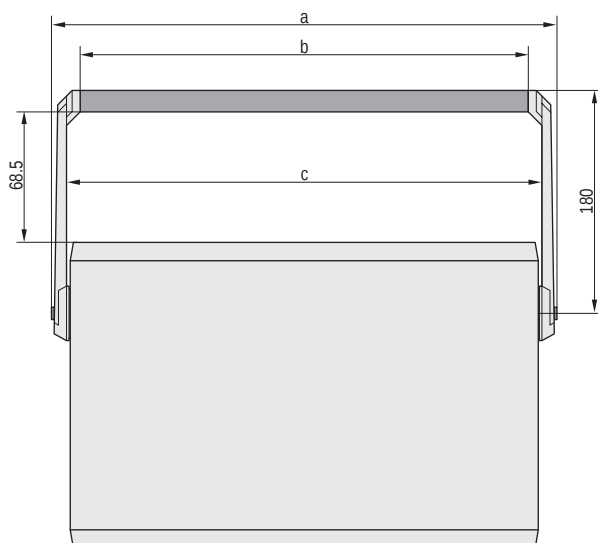

02004080



For further information www.schroff.biz/oneclick
oneClick code = Order no.



Desk-top cases - *compacPRO*

Front door, acrylic glass, folding / hinged



02005006

- Assembly of the hinge above or below
- With fast-action latch
- Lock retrofittable

Delivery comprises (kit)


Item	Qty	Description
1	2	Side leg, Al, die-cast, RAL 7016
2	1	Front door, PMMA, blue grey toned, acrylic glass 3 mm
3	1	Fast-action latch, PC, UL 94 V-0, black
4	2	Spacer plate, Al, 3 mm, chromated
5	1	Assembly kit

Order Information

Height U	Width HP	Order no.
3	42	24575-137
3	63	24575-157
3	84	24575-177
Lock for front door Cylinder, 2 keys, assembly parts		21100-647


Dimensions

Height U	b HP	H mm	h mm	B mm
3	42	139.50	128.40	229.60
3	36	139.50	128.40	336.40
3	84	139.50	128.40	443.00

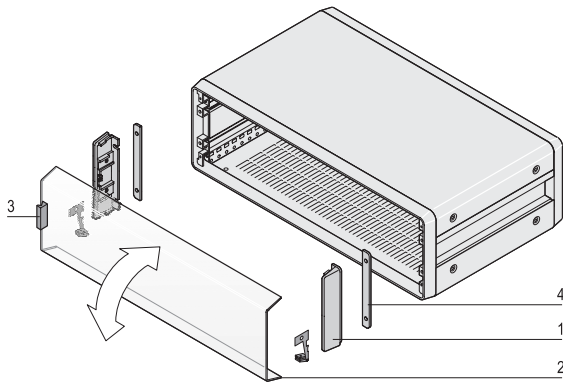


02004069

Front door, folding / hinged

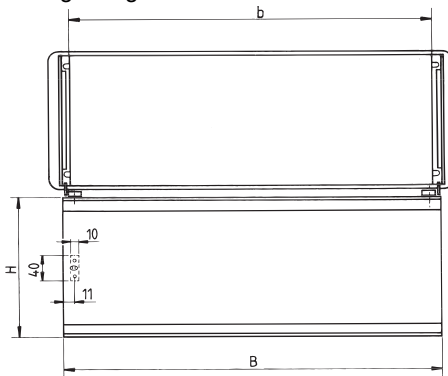

a4-2265

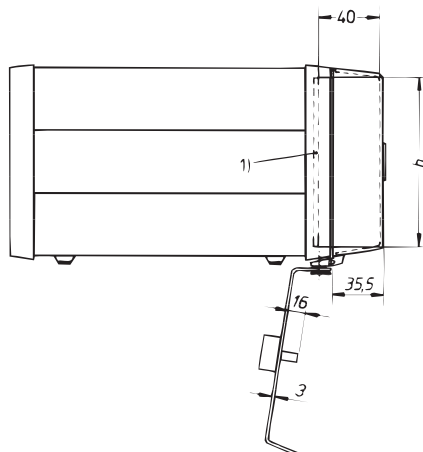

a4-225


1) Front panel



For further information www.schroff.biz/oneclick
oneClick code = Order no.

Desk-top cases - *compacPRO*

Tip-up foot 2 made of plastic

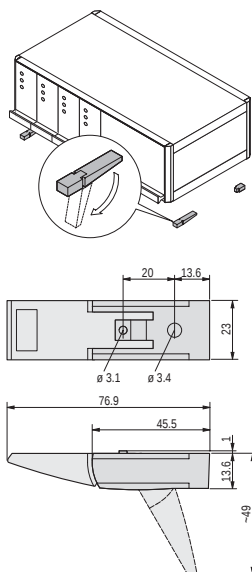

01802075

- Load-carrying capacity 25 kg per foot, max. case weight 50 kg
- Can be used instead of standard feet
- Mounting holes in bottom of casing


Delivery comprises (kit)

Item	Qty	Description
1	4	Foot, PA, UL 94 V-0
2	4	Anti-slip protection, TPE
3	2	Tip-up, PA UL 94 V-0
4	1	Assembly kit

Order Information

Description	RAL 7016 anthracite	RAL 9006 silver
	Order no.	Order no.
Tip-up foot 2, plastic	20603-002	20603-001

Tip-up foot made of Al die-cast

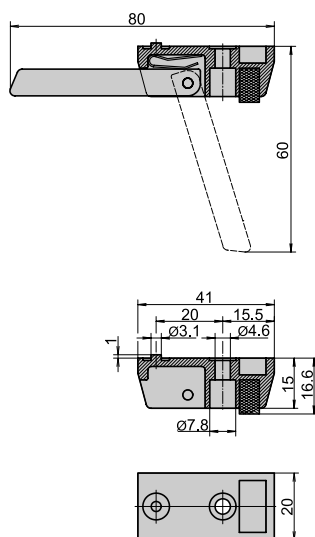

AZA43836


- Load-carrying capacity 50 kg per foot
- Can be used instead of standard feet
- Mounting holes in bottom of casing

Order Information

Description	Qty / PU	Order no.
Foot with tip-up, Al die-cast, silver	1	10603-002
Foot without tip-up, Al die-cast, silver	1	10603-001
Cylinder head screw with slot M4 × 12, St, zinc-plated, PU 100 pieces		21101-211
Hexagon nut M4, St, zinc-plated, PU 100 pieces		21100-211
Washer A4, St, zinc-plated, PU 100 pieces		21100-207

Delivery may be in Standard Pack Quantity: Please order 10 pieces or a multiple. Pricing is per individual item.

Earthing kit

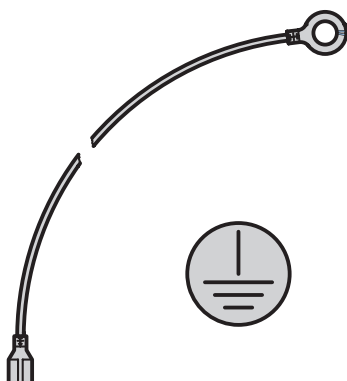

AZA43284

- Protective GND/earth connections in accordance with
EN 50178
EN 60950
EN 61010-1
EN 61010-1A2


Order Information

Description	Qty / PU	Order no.
GND/earthing kit, CU wire 1.5 mm ² , PVC covered, green / yellow, for the connection of side panel, base, cover and rear panel	1	24575-801

Desk-top cases - *compacPRO*


Assembly position horizontal rail / centre rail

Case 2 U

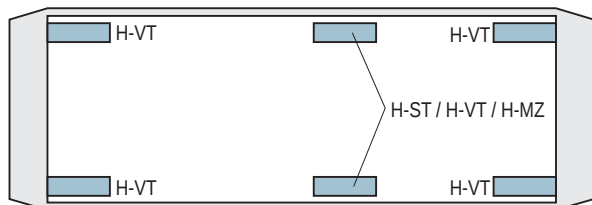


02004073

Case 3 U + 4 U

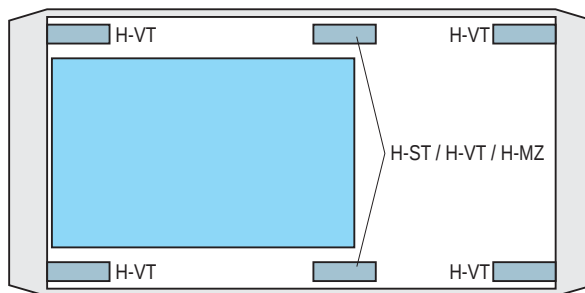


02004074

Case 6 U

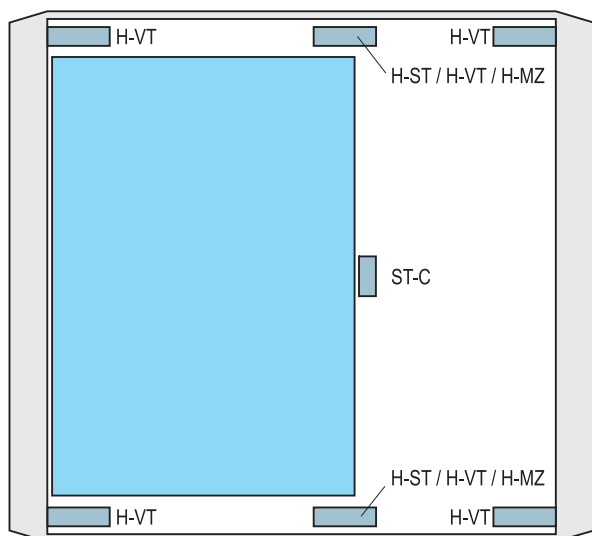


02004076

Case 2 x 3 U (6 U)

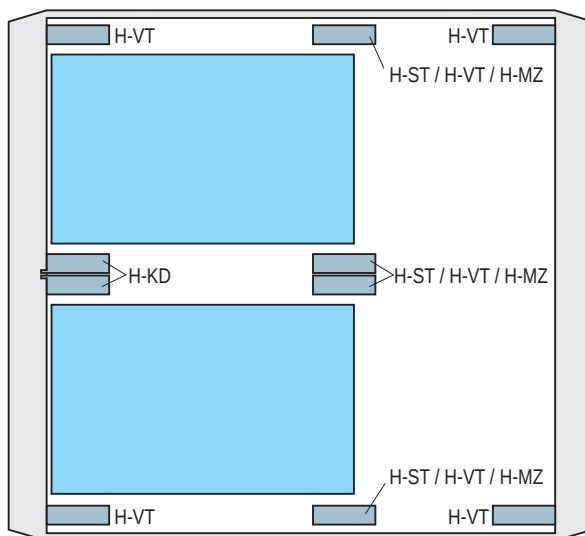

02004077

Horizontal rail

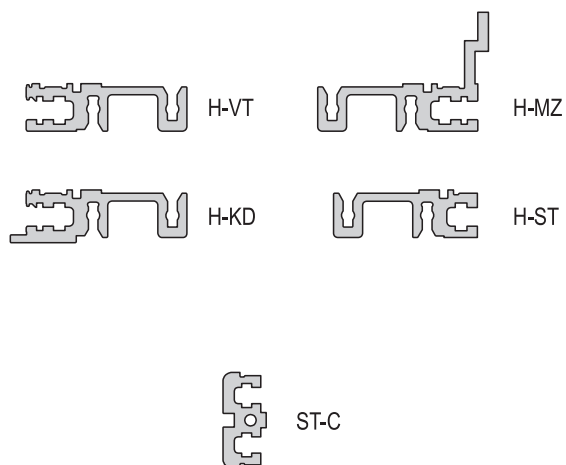

02004078

Desk-top cases - *compacPRO*


Horizontal rail, front/rear/centre

Order Information

For assembly at top or bottom, with HP print > 28 HP, Al extrusion, finish anodised, contact surface conductive		Type H-ST robust standard	Type H-VT robust + 3 mm	Type H-MZ robust with Z-rail	Type H-KD robust short top
		 06197011 For indirect mounting of backplanes by insulation strip, order insulation strip separately	 06197009 For direct backplane assembly	 06102010 For direct mounting of connectors, in accordance with EN 60603-2 (DIN 41612)	 06197008 For high mechanical demands
Usable length HP	Length mm	SPQ 1) 10 pieces	SPQ 1) 10 pieces	SPQ 1) 10 pieces	SPQ 1) 10 pieces
28	147.32	34560-528	34560-728	34560-928	—
42	218.44	34560-542	34560-742	34560-942	34560-242
63	325.12	34560-563	34560-763	34560-963	34560-263
84	431.8	34560-584	34560-784	34560-984	34560-284
Screw, M4 x 14, PU 100 pieces		24560-130	24560-130	24560-130	24560-130
Screw, M4 x 10, necessary if guide rail is screwed on slot 1, PU 100 pieces				24560-155	24560-155

1) Delivery may be in Standard Pack Quantity (SPQ). Please order the 'SPQ' quantity or a multiple. Pricing is per individual item.

Horizontal rail centre type ST-C

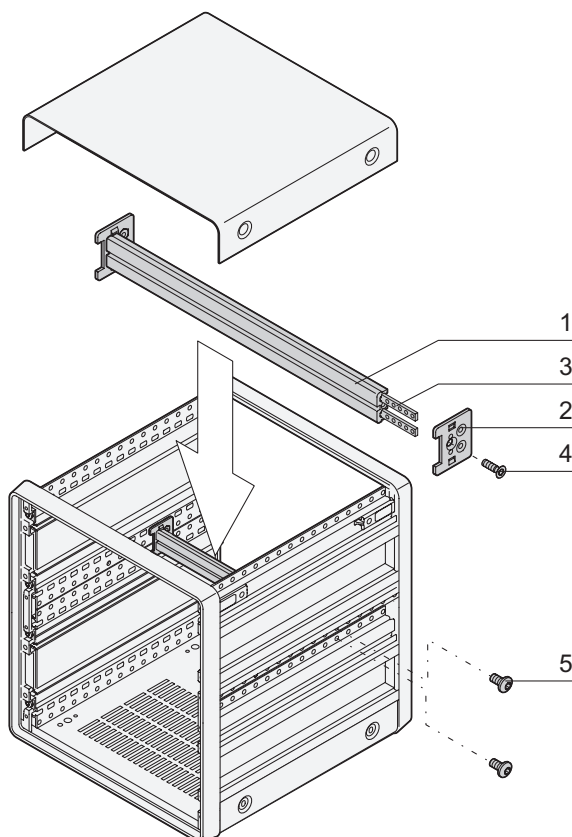

- For indirect backplane assembly
- For the 6 U compacPRO case

Delivery comprises (kit, item 1 up to 4 pre-mounted)

Item	Qty	Description
1	1	Horizontal rail, Al extrusion, anodised, conductive contact surfaces
2	2	Adaptor plates, Al
3	2	Threaded inserts M 2.5 , St, zinc-plated
4	2	Counter sunk screw, M4 x 14
5	4	Pan head screw M4 x 6

Order Information

Usable width HP	Length mm	Order no.
63	316.9	24575-454
84	428.6	24575-474
Insulation strip 63 HP, PBT UL 94 V-O, grey, SPQ 10 pieces		30894-444
Insulation strip 84 HP, PBT UL 94 V-O, grey, SPQ 10 pieces		60817-061



For further information www.schroff.biz/oneclick
oneClick code = Order no.

Desk-top cases - *compacPRO*

Threaded insert, insulation strip

Order Information

Usable length HP	Threaded inserts			Insulation strips		
	Length mm	M2.5 SPQ 1) 10 pieces	M3 SPQ 1) 10 pieces	Length mm	1 piece	Length mm
28	147.32	34561-328	—	144.2	—	147.32
42	217.94	34561-342	—	210.4	60817-118	217.94
63	324.62	34561-363	—	316.88	—	324.62
84	431.3	34561-384	34561-484	428.64	60817-061	431.3
Grub screw M2.5 x 8, PU 100 pieces		21100-276	—		—	
Grub screw M3 x 8, PU 100 pieces		—	21100-646		—	

1) Delivery may be in Standard Pack Quantity (SPQ). Please order the 'SPQ' quantity or a multiple. Pricing is per individual item.

Z-rail, perforated rail

Order Information

Usable length HP	Length mm	Z-rail IEC 60603-2, DIN 41612	Z-rail for connectors, 31 pin, DIN 41617	Perforated rail EN 60603-2, DIN 41612
		1 piece	1 piece	1 piece
28	142.24	30822-033	—	30497-006
42	213.36	30822-047	—	30822-203
60	304.8	30822-065	30819-783	30822-204
84	426.7	30822-089	30819-808	30822-206
Screw M2.5 x 7, PU 100 pieces		24560-147	24560-147	—
Screw M2.5 x 10, PU 100 pieces		—	—	24560-148

Desk-top cases - *compacPRO*

Guide rail, one-piece

- For printed board lengths: 70, 160, 220, 280, 340, 400 mm
- Material: up to 280 mm length PBT UL 94-V-0,
> 280 mm length, end piece PBT UL 94-V-0, middle part
Al extrusion, stable version
- Guide rails:
 - Can be snapped into Al profile horizontal rails
 - Pluggable on 1.5 mm thick metal

Order Information

Board height mm	Groove width mm	Colour mm	For plug-in units and frame-type units "Standard"			For boards without front panel For accessories			For large modules, Al extrusion "Stable Version"
			PU 2) 10 pieces	SPQ 1) 50 pieces	SPQ 1) 10 pairs	PU 2) 10 pieces	SPQ 1) 50 pieces	SPQ 1) 50 pieces	SPQ 1) 10 pieces
70	2	red	–	34579-230	–	–	–	–	–
100	2	red	–	–	–	–	64560-082	–	–
160	2	red	24560-351	64560-001	64560-074	24560-373	64560-005	64560-076	–
160	2	grey	–	–	–	–	64560-055	–	34562-881
220	2	red	24560-353	64560-002	64560-075	24560-374	64560-006	64560-078	–
220	2	grey	–	–	–	–	64560-166	–	34562-882
280	2	red/silver	24560-379	–	–	24560-375	–	64560-080	34562-883
340	2	red/silver	24560-380	–	–	24560-376	–	–	34562-884
400	2	silver	–	–	–	–	–	–	34562-885
160	2.5	red	–	64560-096	–	–	–	–	34564-881
220	2.5	red	–	64560-098	–	–	–	–	34564-882
280	2.5	grey/silver	–	–	–	–	–	–	34564-883
340	2.5	grey/silver	–	–	–	–	–	–	34564-884
400	2.5	silver	–	–	–	–	–	–	34564-885

Accessories

ESD clip, PU 50 pieces	24560-255	24560-255	24560-255	24560-255	24560-255	24560-255	–
ESD clip, for alignment pin, PU 50 pieces	–	–	–	–	–	–	–
Retention screw, PU 100 pieces	24560-141	24560-141	24560-141	24560-141	24560-141	24560-141	24560-157
Board retainer, red, PU 10 pieces	–	–	–	24560-377	24560-377	24560-377	–
Printed board handle, red, PU 10 pieces	–	–	–	24560-378	24560-378	24560-378	–
Identification strips for printed board handle, red, PU 1 sheet = 438 pieces	–	–	–	60817-228	60817-228	60817-228	–
Coding block top, red, SPQ 50 pieces	–	–	–	34579-232	34579-232	34579-232	–
Coding block top, grey, SPQ 50 pieces	–	–	–	34579-233	34579-233	34579-233	–
Coding block at bottom, red, SPQ 50 pieces	–	–	–	34579-234	34579-234	34579-234	–
Coding block at bottom, grey, SPQ 50 pieces	–	–	–	34579-235	34579-235	34579-235	–
Coding peg, PU 100 pieces	–	–	–	20817-501	20817-501	20817-501	–


1) Delivery may be in Standard Pack Quantity (SPQ). Please order the 'SPQ' quantity or a multiple. Pricing is per individual item.

2) Order no. comprises one Packaging Unit (PU); multiple items in one pack. Pricing per PU.


Desk-top cases - *compacPRO*

Chassis plate

Chassis plate full width

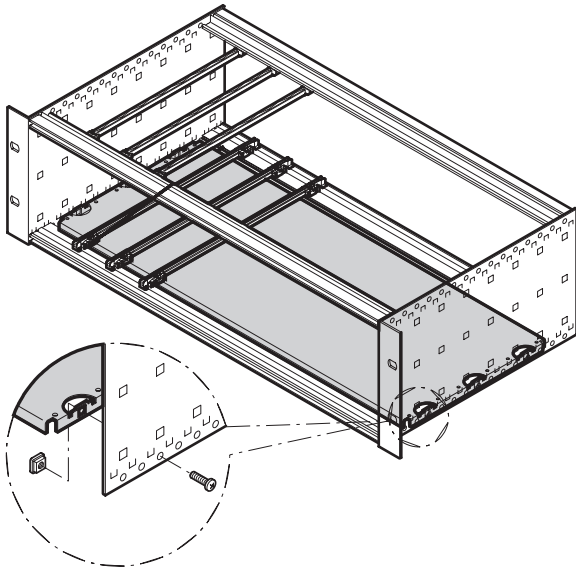

Chassis plate partial width

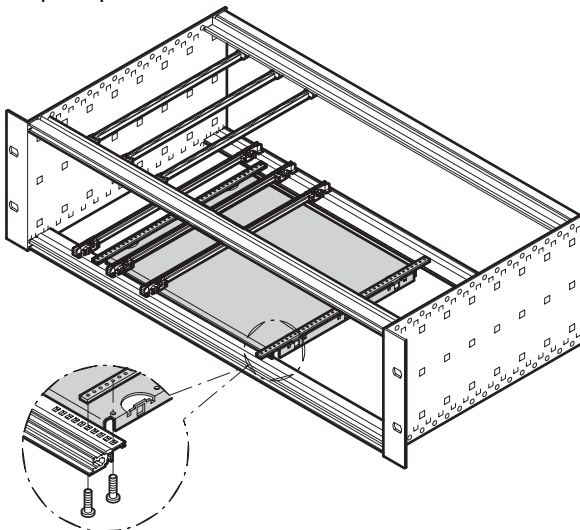

BPA45875

BPA45876

- For assembly of heavy accessories

■ Chassis plate full width

The chassis plate is as wide as the system case and is fixed on the side panel

■ Chassis plate part width

The chassis plate in part width is assembled on a side panel with one mounting strip

Delivery comprises

Item	Qty	Description
1	1	Chassis plate, Al, 1.5 mm

Order Information


Width HP	W mm	w mm	n	Board height mm	Order no.
28	146.88	137.16	1	160	34562-745
28	146.88	137.16	2	220	34562-749
28	146.88	137.16	4	340	34562-757
42	217.99	208.28	1	160	34562-746
42	217.99	208.28	2	220	34562-750
42	217.99	208.28	4	340	34562-758
63	324.67	314.96	1	160	34562-747
63	324.67	314.96	2	220	34562-751
63	324.67	314.96	4	340	34562-759
84	431.35	421.64	1	160	34562-748
84	431.35	421.64	2	220	34562-752
84	431.35	421.64	4	340	34562-760
Torx pan head screw Torx screw M4 × 6, St, zinc-plated, PU 100 pieces					24560-151
Square nuts M4, St, zinc-plated, PU 100 pieces					24560-140

Note

- Square nuts required for assembly on side panel
- 280 mm deep version available on request
- For partial width mounting strips are necessary; please order separately, see page 5.88



For further information www.schroff.biz/oneclick
oneClick code = Order no.

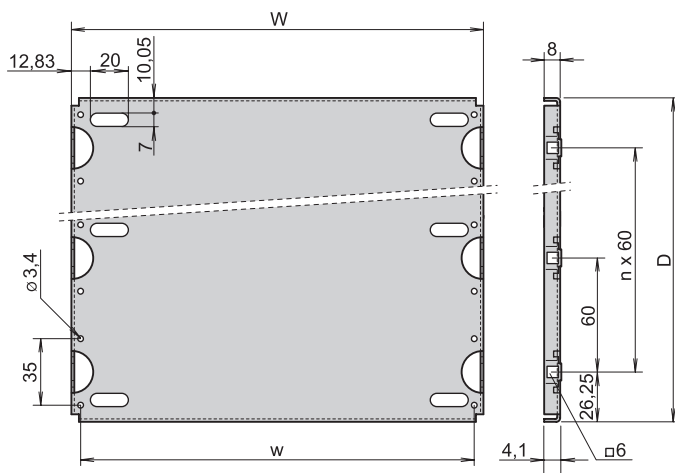


06103057

Depth D = board height - 47.5 mm

Desk-top cases - *compacPRO*

Mounting strip for chassis plate

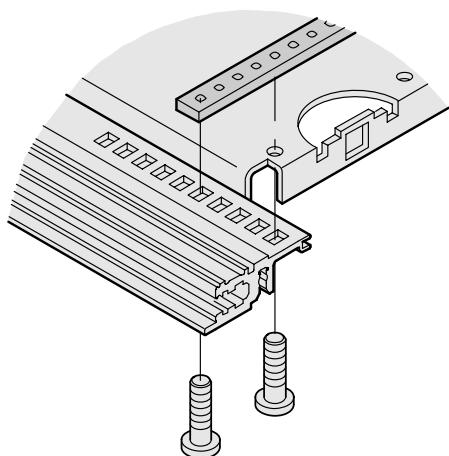

BPA46557

- For assembly of chassis plates in partial widths
- Suitable for assembly on all europacPRO horizontal rails

Delivery comprises

Item	Qty	Description
1	1	Assembly strips, St, zinc-plated, 2 mm

Order Information

Length mm	Board height mm	Order no.
142.4	160	30840-021
202.4	220	30840-033
322.4	340	30840-057

Assembly parts Torx screw, M2.5 × 5, St, zinc-plated, PU 100 pieces **24560-146**

Note

- 4 screws are required per assembly strip




For further information www.schroff.biz/oneclick
oneClick code = Order no.

Desk-top cases - *compacPRO*


Dimensions

Extruded side panel 2 U

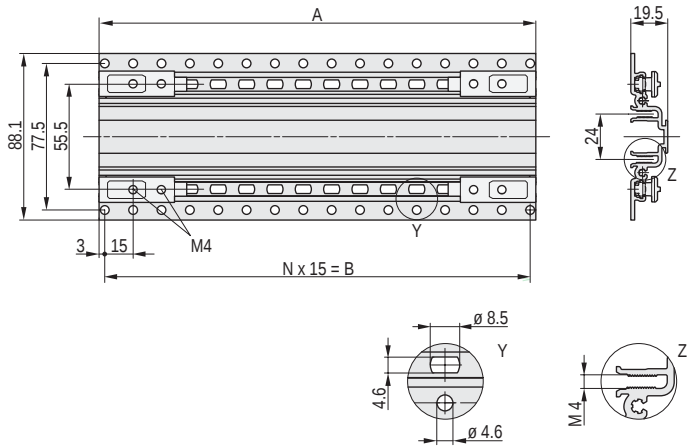


02004057

Extruded side panel 3 U

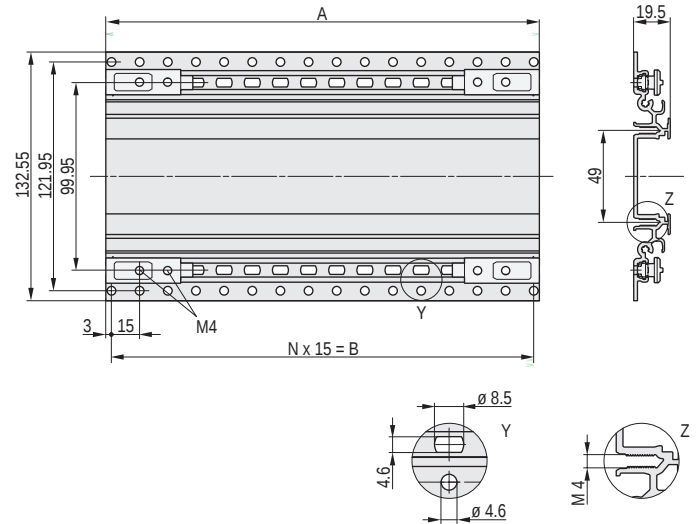


02004058

Extruded side panel 4 U

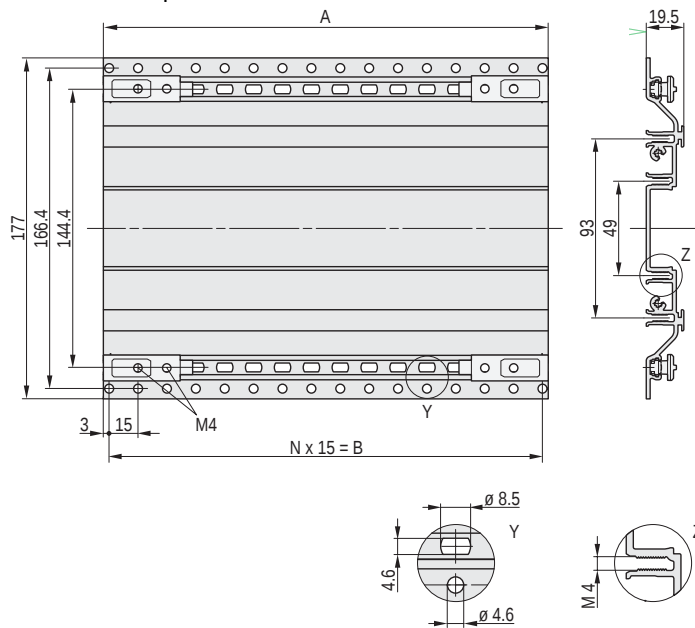

02004059

Extruded side panel 6 U

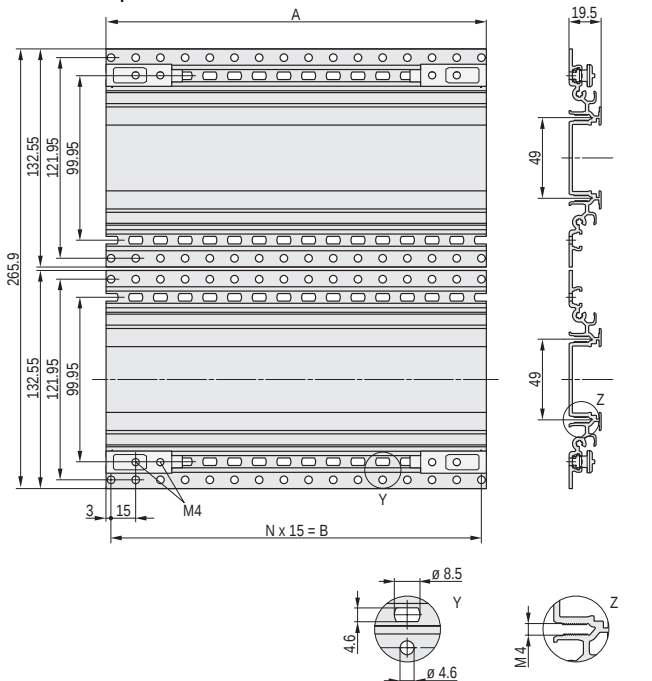

02004059

Dimensions

For case depth	Max. mounting depth	Dimensions	
mm	mm	A in mm	B in mm
271	250	231	15 15 = 225
331	310	291	19 15 = 285
391	370	351	23 15 = 345
451	430	411	27 15 = 405
511	490	471	31 15 = 465

Note

Side panel for 6 U case consists of two 3 U extruded side panels