

Mini-Lynx Ball

ML BALL 827 E27 9W SLV

0035406

Range features



CE

PRODUCT OVERVIEW

Ordering number	0035406
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Ball
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	BALL
EAN code	5410288354064
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Efficacy (Rated) (lm/w)	50
Watt (Nominal) (W)	9
Equivalent watt (W)	40
Voltage (V)	220-240

Mini-Lynx Ball

ML BALL 827 E27 9W SLV

0035406

DATA TABLE

General data

Ordering number	0035406
Dry applications use only	Yes
Technology	Compact Fluorescent
Energy saving lamp	Yes
Energy class	A
Average life (Rated) (h)	10000
Average life (Nominal) (h)	10000
Lamp finish	Frosted
Lamp shape	Ball
Dimmable	No
Cap/Base	E27
Type	BALL
EAN code	5410288354064
E-number SE	8357580
Long description	
Product name	ML BALL 827 E27 9W SLV
Lamp mercury content (mg)	<2
Starting time (max) (s)	<1.5
Warm-up time to 60% of full light (max) (s)	<60
Control gear required	NO
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	30000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Lumen maintenance at end of nominal life (%)	60
Luminous flux (Nominal) (lm)	450

Mini-Lynx Ball

ML BALL 827 E27 9W SLV

0035406

Electrical data

kWh per 1000 hours burning time	9
Efficacy (Rated) (lm/w)	50
Watt (Rated) (W)	9
Watt (Nominal) (W)	9
Equivalent watt (W)	40
Voltage (V)	220-240
Lamp power factor	=0.55

Physical data


Weight (kg)	0.05
Lamp Length (mm) - C/L	98.5±2
Max. Lamp Diameter (mm) - D	51±1
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	11.50 x 5.00 x 5.00
Outer package dimensions (L x W x H) (cm)	28.50 x 12.00 x 14.00

Mini-Lynx Ball

ML BALL 827 E27 9W SLV

0035406

TECHNICAL DRAWINGS

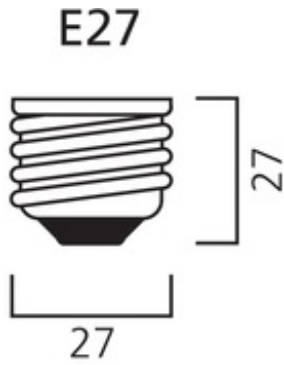

ENERGY LABEL

