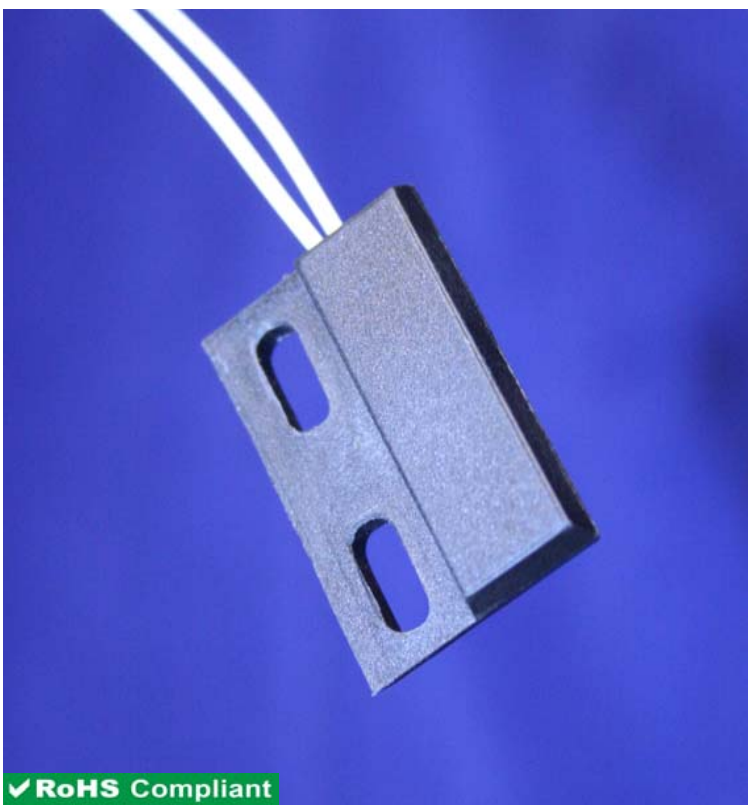


# Datasheet


## Rectangular Proximity Switch - Normally Open Contacts

Part Number : 811-0736

Product Data Sheet

**PICTURE**


✓ RoHS Compliant

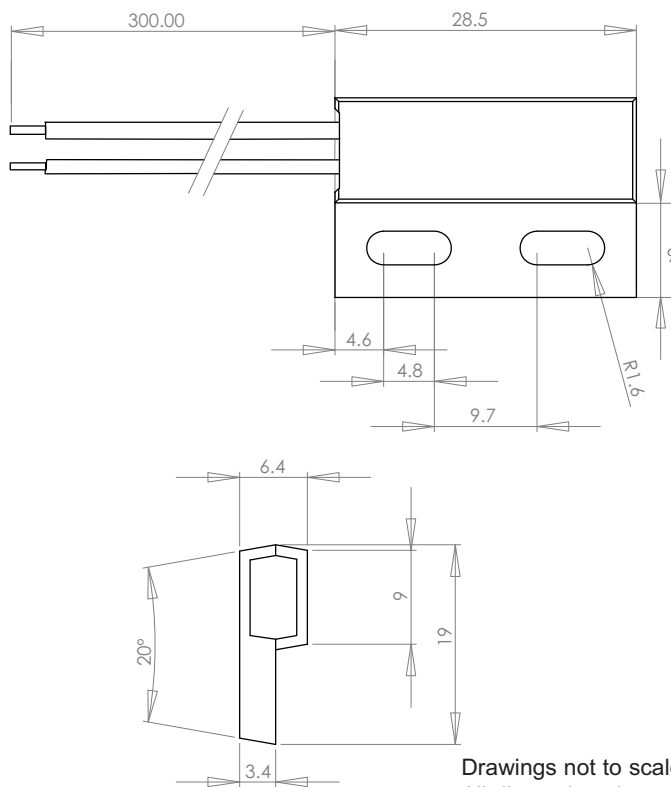**DIMENSIONS**


Drawings not to scale  
All dimensions in mm nominal

**SPECIFICATION**

Contact Form / Style	Normally Open	
Switching Voltage	Max Volts AC	250
Switching Current	Max Amps	0.5
Switching Capacity (Resistive)	Max W/VA	10
Switching Distance	Min mm	10
Contact Resistance	Max mOhms	150
Operating Temperature	Celsius	- 40° to 105°
Case Material	Glass filled Nylon (30% glass)	
Cable	2 x20 AWG White PVC Insulated	

**Applications Include**

- Position and limit sensing.
- Linear actuators.
- Security system switch.
- Door Switch.

**Options**

- Also available with 2 core flex.
- Normally Closed & Changeover versions available.
- Custom cable types, cable lengths, connectors or crimp terminals available.
- If you do not see what you need, just ask, as there is a strong possibility we can do it !

**Did you know we also sell?**

**Rev. No.**
**Revision Note**
**Date**
**Signature**

1

Datasheet

24-04-14

ML