



Air & Water hose reel

RS Stock No. 423-1618

Manufacturer No. CA33118M118


Catalogue page. 3 - 4189

DIMENSIONS

A - 787mm

B - 457mm

C - 552mm

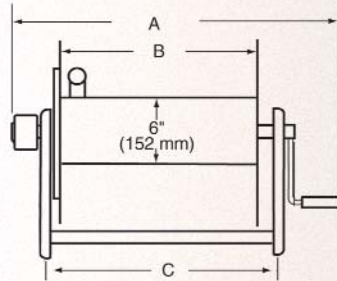

30000 SERIES

Air & Water

Corrosion proof composite material

Reelcare's 30000 Series reels with large storage capacity are designed for harsh, heavy duty applications that require long lengths of hose. 30000 Series reels are manufactured from high quality steel components which are individually powder coated to give added corrosion resistance. Each reel is supplied complete with a full flow swivel assembly to allow for maximum product delivery.

Available to suit maximum lengths of the following hose sizes:

Hose I.D.	1/4"	3/8"	1/2"	3/4"
Length	191m	137m	99m	54m



FEATURES & BENEFITS

- Adjustable spool rotation drag that eliminates hose backlash
- Zinc-plated swivel with AFLAS "O" ring seals
- Full flow shaft and ball bearing swivel

- Permanently lubricated dual main bearings
- All bolted construction - no welds to crack
- Temperature operating range from -20° F (-29° C) to +250° F (121° C)
- Vibration-proof self-locking fasteners

Stocked Items

PART NUMBERS		Max I.D.		PRESSURE		CONNECTION		WEIGHT
RS Stock Number	Manufacturers Part No.	mm	inch	Bar	PSI	inlet	outlet	with hose
Alternative model 423-1602	CA32112M118	12mm	1/2"	207	3000	1/2"	1/2"	22kg
423-1618	CA33118M118	19mm	3/4"	207	3000	3/4"	3/4"	25kg

***Please note: The 30000 Series is not suitable for drain jetting applications**