


Item no.: 281-622/281-542  
 Product description: Fused disconnect terminal block with pivotable fuse holder for miniature metric fuses 5 x 30 mm 30 - 65 V with blown fuse indication by led

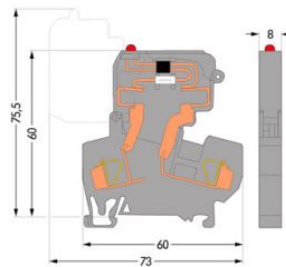

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

Current intensity EN	6.3 A
Current intensity EN	10 A
Product group	1 (Rail Mounted Terminal Blocks)
for miniature metric fuses	5 x 30 mm
Residual current in case of blown fuse (Neon lamp)	< 0.4 mA
Residual current in case of blown fuse (LED)	6 mA
Cross section [mm <sup>2</sup> ]	0.08 - 4 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Connection method	CAGE CLAMP®CONNECTION
Measured voltage EN	800 V
Measured shock voltage	8 kV
Pollution degree	3
Current intensity EN	10 A
Current intensity EN	6.3 A
Weight	17.96 g
Color	grey
Wiring type	Front-entry
No. of connection Points	2

No. of potentials	2
Height	60 mm
Height	2.36 in
Width	8 mm



Width	0.315 in
Depth	60 mm
Depth	2.36 in
Strip length from	9 mm
Strip length to	10 mm
Strip length	0.37 in
Safety information 1	The nominal voltage and nominal current are defined by the indicator lamp or the fuse.
Mounting	TS 35
Safety information 2	Leakage current in case of blown fuse: LED 6 mA



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
281-622/281-542	ABS	05-HG476175/3-PDA	800	10	0,08-4
281-622/281-542	CCA	NL5470	800	10	0,08-4
281-622/281-542	CSA	154112-1505034	65	10	28-12
281-622/281-542	KEMA	2036066.01	800	10	4
281-622/281-542	PRS	TE/1718/880590/08	800	10	0,08-4
281-622/281-542	UR	E45172	65	10	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected