


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
<b>69,85</b>	120	29,795	132	186	4000	6000	482/472/Q

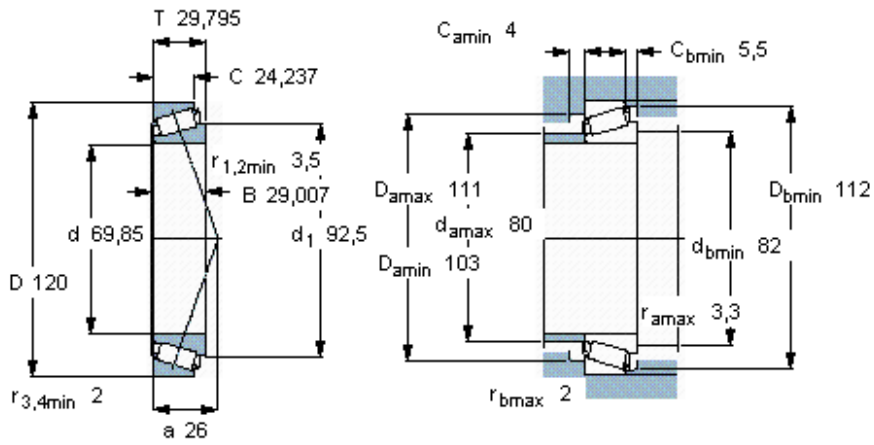

**Calculation factors**

$e = 0,37$

$Y = 1,6$

$Y_0 = 0,9$