


RVS

PVC Insulated Coil-buckling Connection Soft Wire

铜芯聚氯乙烯绝缘聚氯乙烯护套绞型连接用软电线

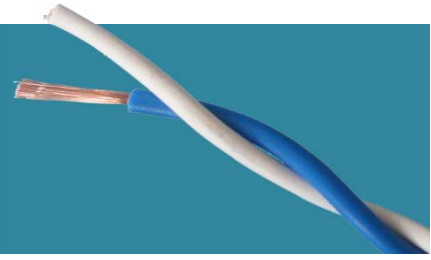

Application

- These cables are suitable for use of rate voltage 300/300V and below power plants, fixed wiring and flexible connection for electrical appliances.

Construction

- Conductor: Flexible bare, annealed copper, acc to IEC60228 - 2004 class5
- Insulation: Polyvinyl chloride (PVC)
- Color: White/White, Red/Blue, Red/Black or customer-specified

Technical Data

- Nominal voltage: 300/300V
- Temperature range: 0°C~70°C

Standards / Material properties

- Approvals: CCC ; CE
- Application standards: GB/T 5023-2008; IEC 60227

应用

- 本产品分别适用于额定电压300/300V及以下的动力装置、固定布线及挠性连接电器之用。

结构

- 导体：退火软铜线，符合IEC60228 -2004 五类导体
- 绝缘：聚氯乙烯
- 颜色：双白，红蓝，红黑或客户指定

技术参数

- 额定电压：300/300V
- 工作温度：0°C~70°C

标准 / 材料性能

- 认证: CCC; CE
- 应用标准: GB/T 5023-2008; IEC 60227

Type selection

Cores×cross-sec	Insulation Thickness	Outerø	Weight
Nr×mm ²	mm	ca,mm	ca,kg/km
2×0,5	0,8	6,0	24
2×0,75	0,8	6,2	31
2×1	0,8	6,5	33,6
2×1,5	0,9	7,5	42,6
2×2,5	1,0	8,5	68
2×4	1,1	10,1	100
2×6	1,2	12,4	144

Dimensions and specifications may be changed without prior notice