



Self-aligning ball bearings, cylindrical and tapered bore

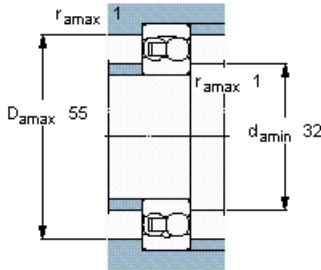

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	-
25	62	17	19	5,4	0,28	22000	15000	0,26	1305 ETN9

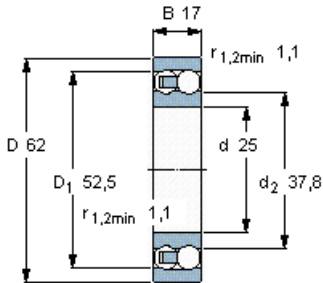

Calculation factors

e 0,28
 Y_1 2,2
 Y_2 3,5
 Y_0 2,5