 



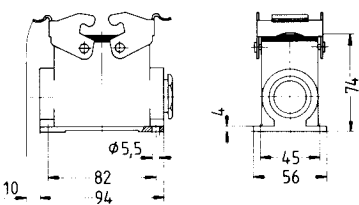
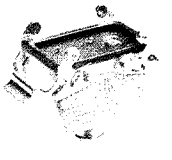
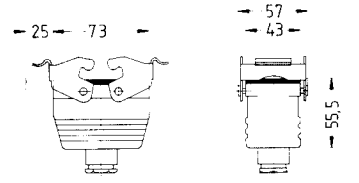

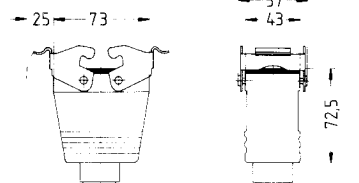


# Locking clip on hood and housing

Style	Ordering number	Cable entry			Description	Outline drawing dimensions in mm		
		 PG	 PG	 PG				
<b>Surface-mounted housing</b> side entry high construction 	49.60.24.07	21			HD.24.SG-VS.1.21			
	49.60.24.80		21		HD.24.SG-VS.1.21.Z			
	49.60.24.08	2x21			HD.24.SG-VS.2.21			
	49.60.24.96		2x21		HD.24.SG-VS.2.21.Z			
	49.60.24.09	29			HD.24.SG-VS.1.29			
	49.60.24.81		29		HD.24.SG-VS.1.29.Z			
	49.60.24.48	2x29			HD.24.SG-VS.2.29			
	49.60.24.97		2x29		HD.24.SG-VS.2.29.Z			
	51.49.60.24.07	21			HD-K.24.SG-VS.1.21			
	51.49.60.24.80		21		HD-K.24.SG-VS.1.21.Z			
	51.49.60.24.08	2x21			HD-K.24.SG-VS.2.21			
	51.49.60.24.96		2x21		HD-K.24.SG-VS.2.21.Z			
	51.49.60.24.09	29			HD-K.24.SG-VS.1.29			
	51.49.60.24.81		29		HD-K.24.SG-VS.1.29.Z			
51.49.60.24.48	2x29			HD-K.24.SG-VS.2.29				
51.49.60.24.97		2x29		HD-K.24.SG-VS.2.29.Z				
<b>Cable-to-cable hood</b> top entry standard construction 	42.70.10.05	16			HB.10.KDO-VS.1.16			
	42.70.10.79		16		HB.10.KDO-VS.1.16.Z			
	42.70.10.69			16	HB.10.KDO-VS.1.16.G			
	42.70.10.07	21			HB.10.KDO-VS.1.21			
	42.70.10.80		21		HB.10.KDO-VS.1.21.Z			
	42.70.10.70			21	HB.10.KDO-VS.1.21.G			
	51.42.70.10.05	16			HB-K.10.KDO-VS.1.16			
	51.42.70.10.79		16		HB-K.10.KDO-VS.1.16.Z			
	51.42.70.10.69			16	HB-K.10.KDO-VS.1.16.G			
	51.42.70.10.07	21			HB-K.10.KDO-VS.1.21			
	51.42.70.10.80		21		HB-K.10.KDO-VS.1.21.Z			
	51.42.70.10.70			21	HB-K.10.KDO-VS.1.21.G			
	high construction 	49.70.24.07	21				HD.24.KDO-VS.1.21	
		49.70.24.80		21			HD.24.KDO-VS.1.21.Z	
49.70.24.70				21	HD.24.KDO-VS.1.21.G			
49.70.24.09		29			HD.24.KDO-VS.1.29			
49.70.24.81			29		HD.24.KDO-VS.1.29.Z			
49.70.24.71				29	HD.24.KDO-VS.1.29.G			
51.49.70.24.07		21			HD-K.24.KDO-VS.1.21			
51.49.70.24.80			21		HD-K.24.KDO-VS.1.21.Z			
51.49.70.24.70				21	HD-K.24.KDO-VS.1.21.G			
51.49.70.24.09		29			HD-K.24.KDO-VS.1.29			
51.49.70.24.81		29		HD-K.24.KDO-VS.1.29.Z				
51.49.70.24.71			29	HD-K.24.KDO-VS.1.29.G				