

# Datasheet

ENGLISH




## 3 way terminal block 5.08mm

RS Stock 790-1193



### Dimensions: (mm)

#### PCB Layout

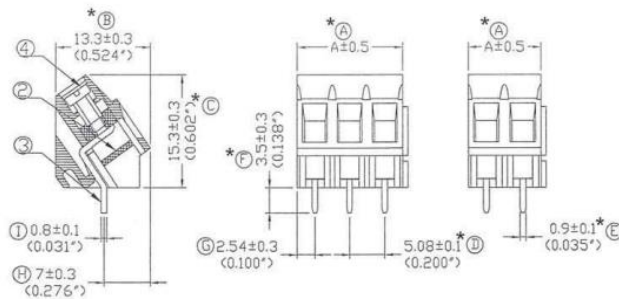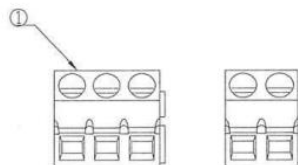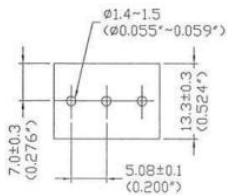

### Specification

Current Rating: 16Amp AC300V  
 Insulation Withstands Volts: AC2000V Min  
 Insulation Resistance: >2000M  $\Omega$  DC500V  
 Operation Temperature: -40°C to + 105°C  
 Wire Strip Length: 4mm~5mm  
 Wire Range: 12~26 AWG  
 Screw Torque: 5.0lb-inch

### Material

Insulating Body: Polyamide 66(UL94V-0)  
 Screw: Steel / Finish: Zinc Plated  
 Terminal: Brass/ Tin Plated  
 Cage Clamp: Brass / Finished: Tin Plated  
 RoHS Compliant