



MASTER LEDtube Value

MASTER LEDtube VLE 1200mm 20W865 T8C

The Philips MASTER LEDtube integrates a LED light source into a traditional fluorescent form factor. Its unique design creates a perfectly uniform visual appearance which cannot be distinguished from traditional fluorescent. For those that are looking for value for money within limited budget and re-lamping efforts for better light effect and lifetime.

Product data

• General Characteristics

Main Application	Industrial
Cap-Base	G13
Rated Lifetime (hours)	40000 hr
Nominal Lifetime hours	40000 hr
B50L70	40000

• Light Technical Characteristics

Color Code	865
Beam Angle	150 D
Correlated Color Temperature	6500 K
Color rendering index	83
Rated Luminous Flux	2100 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	<6
Rated Beam Angle	150 D

• Electrical Characteristics

Wattage	20 W
Voltage	220-240 V
Line Frequency	50/60 Hz
Power Factor	0.9 (min) -
Dimmable	No
Rated Wattage	20 W
Starting Time	0.5 (max) s
Lamp voltage	100-240 V
Warm-up Time to 60% Light Outp	instant full light
Energy saving product	Yes

Suitable for accent lighting	No
------------------------------	----

• Temperature Characteristics

T-case maximum	55 (max) C
Operating temperature	-20 (min), 45 (max) C
T-Storage	-40 (min), 65 (max) C

• Environmental characteristics

Energy Efficiency Label (EEL)	A+
-------------------------------	----

• Measuring Conditions

Switching cycle	50000X
-----------------	--------

• Product Dimensions

Length A1	1198.0 mm
Fixing Hole Distance	1205.0 mm
A2 Length	
Length A3	1212.0 mm
Mounting hole diameter	25.68 mm
Circular outline dimension	28 mm

• Approval & Application Chars

VDE marking	No
CE marking	Yes
UL certificate	No
RoHS compliance	Yes



PHILIPS

MASTER LEDtube Value


KEMA Keur certificate Yes

Pieces per pack 1
 Packing configuration 10
 Packs per outerbox 10
 Bar code on pack - EAN1 8718291735250
 Bar code on outerbox - EAN3 8718291735267
 Logistic code(s) - 12NC 929000287102
 Net weight per piece 0.270 kg

Product Data


Order code 929000287102
 Full product code 929000287102
 Full product name MASTER LEDtube VLE 1200mm 20W865 T8C
 Order product name MST LEDtube VLE 1200mm 20W865 T8C

Dimensional drawing

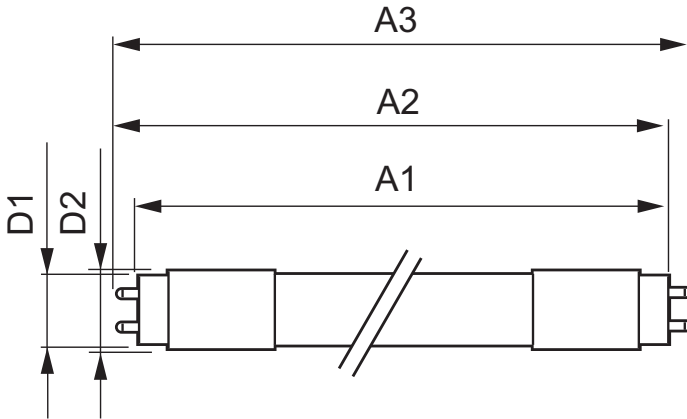


MASTER LEDtube VLE 1200mm 20W865 T8C

Product	A (Norm)	A1 (Norm)	A2 (Norm)	A3 (Norm)	B (Min)	B (Norm)	B (Max)	D (Min)	D (Norm)	D (Max)	D1 (Norm)	D2 (Norm)
LEDtube VLE 1200mm 20W/865 T8 C	-	1198.0	1205.0	1212.0	-	-	-	-	-	-	25.68	28

 

G13

Photometric data

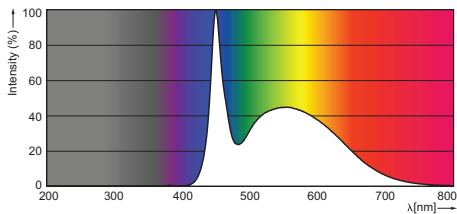

VLE 1200 mm 14.5 W, 16 W, 1500 mm 20 W /865 T8 C



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, July 27
data subject to change