


Verbatim 2013 Range - USB Drives

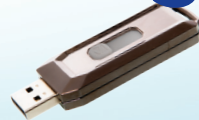

Store 'n' Go - USB 3.0 USB Drive	Store 'n' Go - V3 USB Drive	Store 'n' Go - Clip-it USB	Store 'n' Go - Executive USB	Store 'n' Go - Classic USB	Store 'n' Go - Micro USB	Store 'n' Go - Micro+ USB Drive	Store 'n' Go - PinStripe USB	Store 'n' Go - Nano USB Drive	Secure 'n' Go - Secure Data USB Drive
Part Number: 43895/43896/43897	Part Number: 49171/2/3/4 49175/6/7/8/9/80 49182/83/89	Part Number: 43900/01/ 439009/10/11/12/13	Part Number: 44067/68/74	Part Number: 43990/91/92/93/94	Part Number: 44047/48/49/50/51 47422/23/24/25/26 /27/28	Part Number: 97756/7/8/9 97760/1/3/6 96664	Part Number: 49061/2/3/4/5/71 47395/96/97/98/89 49066/67/68/69/70 49056/57	Part Number: 97463/64/65	Part Number: 44070/71/72
Capacities: 16GB - 64GB	Capacities: 8GB - 128GB	Capacities: 4GB	Capacities: 16GB - 64GB	Capacities: 4GB - 64GB	Capacities: 4GB - 32GB	Capacities: 8GB - 32GB	Capacities: 4GB - 128GB	Capacities: 8GB - 32GB	Capacities: 4GB - 32GB
Interface: USB 3.0	Interface: USB 3.0	Interface: USB 2.0	Interface: USB 2.0	Interface: USB 2.0	Interface: USB 2.0	Interface: USB 3.0	Interface: USB 2.0	Interface: USB 2.0	Interface: USB 2.0
Description: Store 'n' Go USB 3.0 USB Drive offers extreme transfer speed, large capacity, and plug 'n' play operation. Push & pull enclosure design protects the USB interface.	Description: Verbatim's newly designed V3 USB Drive offers SuperSpeed data transfer rates and is available in a range of six colours and black.	Description: Verbatim's Clip-it USB Drive combines flash storage with the simple functionality of a paperclip, making it a wonderfully practical solution for daily business or private users. Available in five vibrant colours plus white and black.	Description: Verbatim's Executive USB Drive offers very high read/write speeds and comes in a tough yet sleek and stylish metal casing.	Description: The Store 'n' Go Classic USB Drive has a push and pull sliding feature which protects the USB connection when it is not in use.	Description: Verbatim's Store 'n' Go Micro USB Drive features new System in Package (SIP) technology which integrates all the electronic components into one of the smallest and most reliable USB drives. Available in five vibrant colours and black.	Description: The Store 'n' Go Micro USB Drive Plus, a rugged portable solution perfect for storing music, videos, school projects or photos that conveniently clips onto key chains, binders, notebooks and more. Available in six vibrant colours and black.	Description: The "PinStripe" utilises a pull-mechanism which protects the USB connector without requiring a separate cap. Available in six vibrant colours and black.	Description: Ultra-small USB drive offering up to 32GB of storage which can be plugged in and left in devices such as Netbook PCs, Car Radios, Digital Picture Frames, Tablet PCs etc.	Description: The secure USB drive offers a powerful 256bit AES hardware-encryption and mandatory password which ensures that the data on the drive is always encrypted and secure.
Write Speed (up to): 70MB/sec	Write Speed (up to): 12MB/sec (8 & 16GB) 25MB/sec (32 - 128GB)	Write Speed (up to): 2.5MB/sec	Write Speed (up to): 25MB/sec	Write Speed (up to): 8MB/sec	Write Speed (up to): 2.5MB/sec (4GB) 5MB/sec (16 & 32GB)	Write Speed (up to): 3MB/sec	Write Speed (up to): 2.5MB/sec (4-16GB) 5MB/sec (32-128GB)	Write Speed (up to): 4MB/sec	Write Speed (up to): 8MB/sec
Read Speed (up to): 120MB/sec	Read Speed (up to): 40MB/sec (8GB) 60MB/sec (16GB) 80MB/sec (32 - 128GB)	Read Speed (up to): 8MB/sec	Read Speed (up to): 25MB/sec	Read Speed (up to): 14MB/sec	Read Speed (up to): 8MB/sec (4GB) 12MB/sec (16 & 32 GB)	Read Speed (up to): 10MB/sec	Read Speed (up to): 8MB/sec 12MB/sec (32-128GB)	Read Speed (up to): 4MB/sec	Read Speed (up to): 14MB/sec
Target Customer: Heavy data users.	Target Customer: Heavy Data users.	Target Customer: General users, office supply.	Target Customer: Executives. Heavy data users.	Target Customer: Heavy/regular users.	Target Customer: General users.	Target Customer: General users.	Target Customer: General users.	Target Customer: General users.	Target Customer: Sensitive data users.
Special Features: Very fast.	Special Features: Uses a slide and lock mechanism to protect the connector of the drive when not in use.	Special Features: Ingenious clip design. RedDot Award, best of the best 2010.	Special Features: Metal casing. High read and write speed. Sleek design.	Special Features: Strong performance.	Special Features: Smallest form factor, ideal to attach to a mobile phone or bunch of keys. Waterproof.	Special Features: Flexible Protective Cover, shield USB connector and withstands rough handling in stride.	Special Features: Range of six colours and black for every personality.	Special Features: Small size, can be semi-permanently left in the netbook, car radio, digital photo frame etc...	Special Features: Built-in 256bit hardware encryption to ensure data is kept secure.



www.verbatim.com

Verbatim
Technology you can trust

Verbatim 2013 Range - Memory Cards & SSD



Secure Digital Pro (Class 10) UHS-I Cards	Secure Digital Premium (Class 10) SDHC & SDXC	Secure Digital Standard (Class 4)	microSDHC Premium (Class 10) with/without adaptor	microSD/SDHC Standard (Class 4) with/without adaptor	Compact Flash	Universal Memory Card Reader	6.35cm (2.5") SSD Drive SATA - III Bare Drive/Upgrade Kit	USB 3.0 External SSD
Part Number: 49191/92	Part Number: 43960/61/62/63 44024	Part Number: 44016/18/20/22	Part Number: 44010/11/12/13 44080/81/82/83/84	Part Number: 44001/02/04/07/08 43965/66/67/68	Part Number: 44038/39/40/41	Part Number: 47264	Part Number: 47378/79 47617/18 47613/14 - upgrade kit	Part Number: 47633/22/23
Capacities: 16GB - 32GB	Capacities: 4GB - 64GB	Capacities: 4GB - 32GB	Capacities: 4GB - 64GB	Capacities: 2GB - 32GB	Capacities: 2GB - 16GB	Capacities: N/A	Capacities: 120GB / 128GB / 240GB / 256GB	Capacities: 64GB / 128GB / 256GB
Description: Lightning fast data transfer speeds of up to 600x make Verbatim's Secure Digital Pro UHS-I flash memory cards perfect for use in memory-hungry, high performance digital still and video cameras, as well as other multi-media devices. UHS-I cards can achieve the highest speeds only when paired with a UHS-I device. For devices without the UHS-I interface, the guaranteed maximum data transfer rate for Class 10 will be 10MB/Sec.	Description: Class 10 SDHC memory cards have fast data transfer speeds making them ideal for both professional and serious amateur photographers. Compatible with all devices that display the SDHC logo. The class 10 SDXC card with UHS-I bus interface provides read speeds of up to 90MB per second and the exFAT file system enables the card to efficiently organise large data files.	Description: Class 4 SDHC memory cards designed for use in devices such as digital cameras and camcorders. The cards are compatible with all devices that display the SD logo or have an SD slot.	Description: MicroSDHC memory cards have a higher capacity and faster data transfer speed than microSD memory cards. Designed especially for mobile phones, this memory card consumes very little power, which helps to preserve the battery life of your mobile phone. MicroSDHC memory cards are compatible with devices which display the microSDHC logo.	Description: Class 4 microSD/SDHC memory cards enable you to store more of your photos, videos, ring tones and music from your mobile phone. Designed especially for mobile phones, this tiny memory card consumes very little power, therefore preserving the battery life of your mobile phone. MicroSD memory cards are compatible with devices which display the MicroSD logo.	Description: CompactFlash memory cards are ideal for use in digital cameras, MP3 players and PDA's. They are fully erasable so can be used many times over for accurate picture and music storage. CompactFlash memory cards are compatible with devices which display the CompactFlash logo.	Description: Memory Card Compatibility: CompactFlash (Type I and II) IBM Microdrive SecureDigital SDHC / SDXC miniSD microSD microSDHC Multimedia card RS-MMC MMCmicro* Memory Stick Memory Stick PRO Memory Stick Duo Memory Stick PRO Duo Memory Stick Micro SmartMedia Card xD Picture Card	Description: Transform your laptop or PC's internal hard drive to a state of the art high performance SATA III Solid State Drive. Verbatim's solid state drives offer improved system and application performance, 100% silent operation, longer battery life time for laptops, and are shock resistant SATA 6Gb/s Native Command Queuing (NCQ) SATA III is backward compatible with SATA II and SATA I	Description: Compact, lightweight and housed in a sleek black, credit card size enclosure, Verbatim's USB3.0 External SSD is ideal for users that demand maximum performance in data storage devices. With USB 3.0 connectivity it handles large data transfers quickly - perfect for video editing, interchanging large amounts of data or maximizing gaming performance. Operates silently and features low power consumption for extending laptop battery life.
Target Customer: Semi-professional video makers / photographers.	Target Customer: High volume digital camera users.	Target Customer: Regular digital camera/camcorder users.	Target Customer: All mobile phone users seeking higher performance storage.	Target Customer: All mobile phone users.	Target Customer: Users of traditional SLR cameras with a compatibility slot.	Target Customer: Memory Card Reader is compatible with memory cards used in digital cameras, mobile phones, camcorders and PDA's	Target Customer: Desktop/Laptop users.	Target Customer: Netbook/laptop users.
Special Features: Very fast.	Special Features: High capacities available.	Special Features: Standard SD cards.	Special Features: Fast data transfer speeds. High capacities available. Available in Class 4 & 10.	Special Features: Standard MicroSD card.	Special Features: Compact Flash format to support SLR cameras.	Special Features: 5 Slot Reader for 19 different Memory Cards.	Special Features: High Speed: Reading up to 550MB/sec and writing up to 510MB/sec	Special Features: Highspeed: reading up to 265MB/sec and writing up to 225MB/sec.



www.verbatim.com

Verbatim
Technology you can trust