

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51005-0500](#)
Status: **Active**
Description: 2.00mm Pitch Wire-to-Wire Receptacle Housing, 5 Circuits

Documents:

[3D Model](#) [Packaging Specification SPK-51005-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-51005-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [51005](#)
 Application Signal, Wire-to-Wire
 MolexKits Yes
 Product Name N/A
 UPC 800753693333

Physical

Circuits (maximum) 5
 Color - Resin Natural
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Lock to Mating Part None
 Material - Resin Polyester
 Net Weight 164.710/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.00mm
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Electrical

Current - Maximum per Contact 2A

Material Info

Reference - Drawing Numbers

[Packaging Specification](#) SPK-51005-001
[Product Specification](#) PS-51005-001, RPS-51005-001, RPS-51005-002
[Sales Drawing](#) SD-51005-001

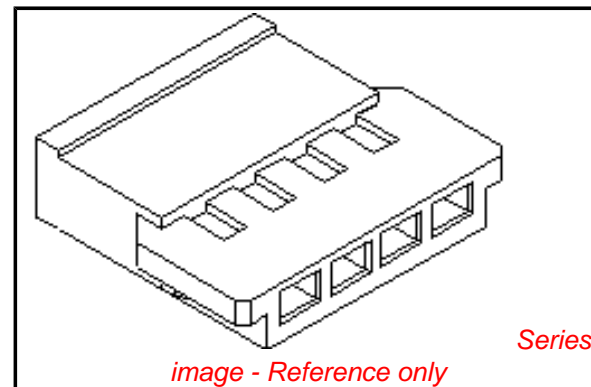


image - Reference only

EU RoHS

**ELV and RoHS
 Compliant**
**REACH SVHC
 Contains SVHC: No**
**Low-Halogen Status
 Not Low-Halogen**

China RoHS



**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[51005Series](#)

Mates With

[51006 Male Housing](#)

Use With

[50013](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION