



Datasheet

ENGLISH

Stock No: 102-6558

RS Pro 30mm High Nylon Threaded Hex Spacer



Hex Threaded Standoff

HTSN-2\HNSM-2\HTSN-3

Black, Nylon 6/6, RMS-172

Product Details


Plastic spacer with external and internal thread

Plastic spacer bolts with external and internal thread.

Temperature-resistant up to:	approx. 110°C
Material:	Polyamide
Colour:	Black


Dimensions:

Type 1

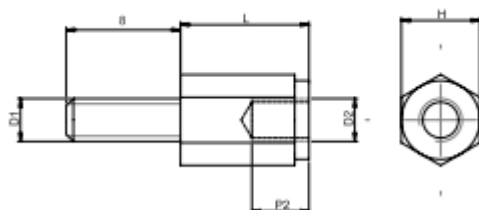

Type 1 Female/Male

Part Number	Thread *D1 & D2*	Dimensions (mm)			Std Pack Qty
		L	*H*	*P2*	
HNSM2.5-5-5-2	M2.5	5	5	3	500
HNSM2.5-8-5-2	M2.5	8	5	5	500
HNSM2.5-10-5-2	M2.5	10	5	8	500
HNSM2.5-12-5-2	M2.5	12	5	9	500
HNSM2.5-15-5-2	M2.5	15	5	10	500
HNSM2.5-18-5-2	M2.5	18	5	10	500
HNSM2.5-20-5-2	M2.5	20	5	10	500
HNSM2.5-25-5-2	M2.5	25	5	10	500
HTSN-M3-5-5-2	M3	5	5.5	3	500
HTSN-M3-8-5-5-2	M3	8	5.5	5	500
HNSM3-10-5-5-2	M3	10	5.5	8	500
HNSM3-12-5-5-2	M3	12	5.5	9	500
HNSM3-15-5-5-2	M3	15	5.5	10	500
HNSM3-18-5-5-2	M3	18	5.5	10	500
HNSM3-20-5-5-2	M3	20	5.5	10	500
HNSM3-25-5-5-2	M3	25	5.5	10	500
HNSM3-30-5-5-2	M3	30	5.5	10	500
HNSM3-35-5-5-2	M3	35	5.5	10	500
HTSN-M3-5-6-2	M3	5	6	3	500
HTSN-M3-8-6-2	M3	8	6	5	500
HTSN-M3-10-6-2	M3	10	6	8	500
HTSN-M3-12-6-2	M3	12	6	9	500
HTSN-M3-15-6-2	M3	15	6	10	500
HTSN-M3-18-6-2	M3	18	6	10	500
HTSN-M3-20-6-2	M3	20	6	10	500
HTSN-M3-25-6-2	M3	25	6	10	500
HTSN-M3-30-6-2	M3	30	6	10	500
HTSN-M3-35-6-2	M3	35	6	10	500
HTSN-M3-5-8-2	M3	5	8	3	500
HTSN-M3-8-8-2	M3	8	8	5	500
HTSN-M3-10-8-2	M3	10	8	8	500
HTSN-M3-12-8-2	M3	12	8	9	500
HTSN-M3-15-8-2	M3	15	8	10	500
HTSN-M3-18-8-2	M3	18	8	10	500
HTSN-M3-20-8-2	M3	20	8	10	500
HTSN-M3-25-8-2	M3	25	8	10	500
HTSN-M3-30-8-2	M3	30	8	10	500
HTSN-M3-35-8-2	M3	35	8	10	500
HTSN-M4-5-8-2	M4	5	8	3	500
HTSN-M4-8-8-2	M4	8	8	5	500
HTSN-M4-10-8-2	M4	10	8	8	500
HTSN-M4-12-8-2	M4	12	8	9	500
HTSN-M4-15-8-2	M4	15	8	10	500
HTSN-M4-18-8-2	M4	18	8	10	500
HTSN-M4-20-8-2	M4	20	8	10	500
HTSN-M4-25-8-2	M4	25	8	10	500
HTSN-M4-30-8-2	M4	30	8	10	500
HTSN-M4-35-8-2	M4	35	8	10	500
HTSN-M4-40-8-2	M4	40	8	10	500
HTSN-M5-10-10-2	M5	10	10	8	500
HTSN-M5-12-10-2	M5	12	10	9	500
HTSN-M5-15-10-2	M5	15	10	10	500
HTSN-M5-18-10-2	M5	18	10	10	500
HTSN-M5-20-10-2	M5	20	10	10	500
HTSN-M5-25-10-2	M5	25	10	10	500
HTSN-M5-30-10-2	M5	30	10	10	500
HTSN-M5-35-10-2	M5	35	10	10	500
HTSN-M5-40-10-2	M5	40	10	10	500

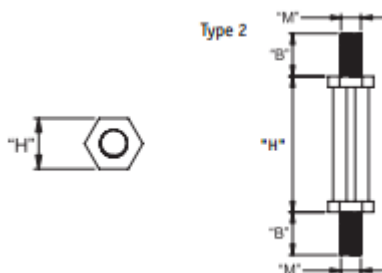

Type 2 Male/Male

Part Number	Thread *M*	Dimensions (mm)			Std Pack Qty
		L	*H*	*B*	
HTSN-M2.5-5-3	M2.5	5	5	6	500
HTSN-M2.5-8-3	M2.5	8	5	6	500
HTSN-M2.5-10-3	M2.5	10	5	6	500
HTSN-M2.5-12-3	M2.5	12	5	6	500
HTSN-M2.5-15-3	M2.5	15	5	6	500
HTSN-M2.5-18-3	M2.5	18	5	6	500
HTSN-M2.5-20-3	M2.5	20	5	6	500
HTSN-M2.5-25-3	M2.5	25	5	6	500
HTSN-M3-5-3	M3	5	6	6	500
HTSN-M3-8-3	M3	8	6	6	500
HTSN-M3-10-3	M3	10	6	6	500
HTSN-M3-12-3	M3	12	6	6	500
HTSN-M3-15-3	M3	15	6	6	500
HTSN-M3-18-3	M3	18	6	6	500
HTSN-M3-20-3	M3	20	6	6	500
HTSN-M3-25-3	M3	25	6	6	500
HTSN-M3-30-3	M3	30	6	6	500
HTSN-M3-35-3	M3	35	6	6	500
HTSN-M4-5-3	M4	5	6	6.4	500
HTSN-M4-8-3	M4	8	6	6.4	500
HTSN-M4-10-3	M4	10	6	6.4	500
HTSN-M4-12-3	M4	12	6	6.4	500
HTSN-M4-15-3	M4	15	6	6.4	500
HTSN-M4-18-3	M4	18	6	6.4	500
HTSN-M4-20-3	M4	20	6	6.4	500
HTSN-M4-25-3	M4	25	6	6.4	500
HTSN-M4-30-3	M4	30	6	6.4	500
HTSN-M4-35-3	M4	35	6	6.4	500
HTSN-M4-40-3	M4	40	6	6.4	500