




ENGLISH


Product Datasheet

# Din Rail mini Terminal Blocks, 4sq.mm



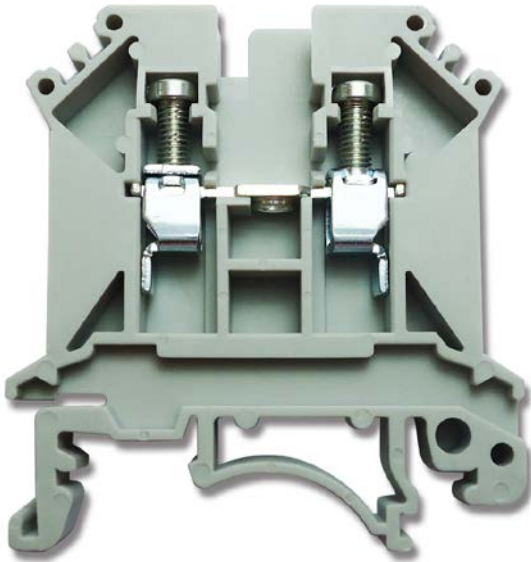

 

 
Screw Clamp mini Terminal Blocks, 30A, 600V, 22-10 AWG, 0.5-4 sq.mm, Grey  
878-7525

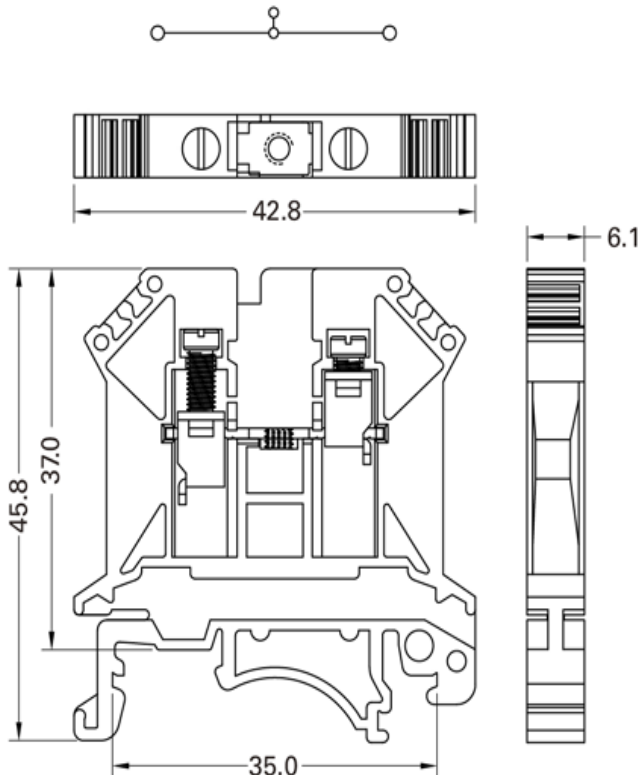

Dimensions in mm



**Product Specifications:**

Specifications	4mm <sup>2</sup>
<b>Technical Date</b>	<b>Rated voltage / Rated current / Wire size</b>
UL	600V / 30A / AWG 22-10
CSA	600V / 30A / AWG 22-10
IEC	800V / 32A / 0.5-4mm <sup>2</sup>
Insulating impulse voltage withstand/pollution degree	8KV / 3
Torque (in -lbs)	10
Clamping Screw (M)	M3
Insulation stripping length (mm)	8~10 mm
Net weight per piece	7.2 g
Material / Available Color (Standard Color: Beige)	 Red   Orange   Beige   Blue   Grey   White   Black
<b>Rail Dimensions</b>	<b>T / W / H (mm)</b>
For TS35x7.5 	6.1 x 42.5 x 47
For TS35x15 	6.1 x 42.5 x 54.5
<b>Accessories</b>	<b>Cat. No.</b>
End Bracket 	8787553
	8787556
End plate 	8787544
Cross 	8787581