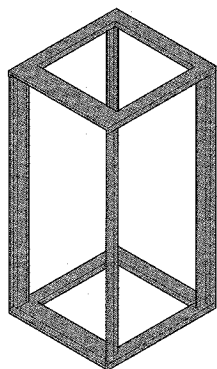




 
 
 
 
 
Ordering *minirack* Service PLUS+

- Assembled to your requirements
- No surcharge
- Prompt delivery
- Environment-friendly – just one package



All parts with ^S) can be assembled to Service PLUS+ cabinets. This applies to the parts in the table below and other accessories. Please add the **suffix /05** (e.g. 20230-489/05) and indicate the **position**. Please do **not** add a suffix if parts are required loose.

MFA44468

Note			19" frame	universal frame	Side panel	Rear panel	Door glazed	Door glazed/framed	Door steel
All parts incl. assembly parts. Unless otherwise stated: doors are hinged on the left and glazed doors assembled at the front.			 MFA44469	 MFA44469	 MFA44470	 MFA44471	 MFA44475	 MFA44477	 MFA44473
Qty			1	1	2	1	1	1	1
Material			Al die-cast frame, Al extrusions, 4 rubber feet, >20 U 4 Al feet		St 1 mm	St 1 mm	Sekurit 6 mm	Al extrusion	St 1 mm
Finish			RAL 7030		RAL 7035	RAL 7035	gray tint	RAL 7035	RAL 7035
Notes			1)	2)		with vents at top	with safety lock and assembly parts, can be mounted at the front or rear		
Dimensions page			13.16	13.17	–	–	13.16	13.16	13.16
External cabinet dimensions									
U	H	W x D mm							
6	337	553 x 400	20230-457	20230-722	20230-478^S)				
		553 x 500	20230-458	20230-723	20230-479^S)	20230-499^S)	20117-738^S)	20230-439^S)	20230-426^S)
		553 x 600	20230-459	–	20230-480^S)				
9	470	553 x 400	20230-460	20230-724	20230-481^S)				
		553 x 500	20230-461	20230-725	20230-482^S)	20230-500^S)	20117-739^S)	20230-442^S)	20230-429^S)
		553 x 600	20230-462	–	20230-483^S)				
12	604	553 x 400	20230-463	20230-726	20230-484^S)				
		553 x 500	20230-464	20230-727	20230-485^S)	20230-501^S)	20117-741^S)	20230-443^S)	20230-431^S)
		553 x 600	20230-465	20230-728	20230-486^S)				
		553 x 780	20230-526	–	20230-531^S)				
16	782	553 x 400	20230-466	20230-729	20230-487^S)				
		553 x 500	20230-467	20230-730	20230-488^S)	20230-502^S)	20117-714^S)	20117-769^S)	21117-184^S)
		553 x 600	20230-468	20230-731	20230-489^S)				
		553 x 780	20230-527	–	20230-532^S)				
20	960	553 x 400	20230-469	20230-732	20230-490^S)				
		553 x 500	20230-470	20230-733	20230-491^S)	20230-503^S)	20117-745^S)	20117-770^S)	21117-185^S)
		553 x 600	20230-471	20230-734	20230-492^S)				
		553 x 780	20230-528	–	20230-553^S)				
25	1182	553 x 400	20230-472	–	20230-493^S)				
		553 x 500	20230-473	20230-735	20230-494^S)	20230-504^S)	20117-746^S)	20117-771^S)	21117-186^S)
		553 x 600	20230-474	20230-736	20230-495^S)				
		553 x 780	20230-529	20230-737	20230-534^S)				
34	1582	553 x 400	20230-475	–	20230-496^S)				
		553 x 500	20230-476	20230-738	20230-497^S)	20230-505^S)	20117-748^S)	20117-765^S)	21117-188^S)
		553 x 600	20230-477	20230-739	20230-498^S)				
		553 x 780	20230-530	20230-740	20230-535^S)				

1) front/rear 19" mounting plane recessed 33mm/60mm optional 2) front universal, rear 19" mounting plane recessed 33 mm