

## Micro-Lynx

MICRO-LYNX LUNA 840 GX53 6W SLV

0035905



### Range features

CE

### PRODUCT OVERVIEW

Ordering number	0035905
Technology	Compact Fluorescent
Light colour	840 Cool White
Energy class	A
Average life (Rated) (h)	2000
Lamp shape	Disc
Lamp finish	Frosted
Dimmable	No
Cap/Base	GX53
Type	GX53
EAN code	5410288359052
CRI (Ra)	80
Colour temperature (K)	4000
Luminous flux (Rated) (lm)	235
Efficacy (Rated) (lm/w)	39
Watt (Nominal) (W)	6
Voltage (V)	220-240

# Micro-Lynx

MICRO-LYNX LUNA 840 GX53 6W SLV

**0035905**

## DATA TABLE

### General data

<b>Dry applications use only</b>	Yes
<b>Ordering number</b>	0035905
<b>Technology</b>	Compact Fluorescent
<b>Average life (Rated) (h)</b>	2000
<b>Energy saving lamp</b>	Yes
<b>Average life (Nominal) (h)</b>	10000
<b>Energy class</b>	A
<b>Lamp finish</b>	Frosted
<b>Lamp shape</b>	Disc
<b>Dimmable</b>	No
<b>Cap/Base</b>	GX53
<b>Type</b>	GX53
<b>EAN code</b>	5410288359052
<b>E-number SE</b>	8357593
<b>Long description</b>	
<b>Product name</b>	MICRO-LYNX LUNA 840 GX53 6W SLV
<b>Lamp mercury content (mg)</b>	< 2,5 mg
<b>Starting time (max) (s)</b>	0,9-1,5 s
<b>Warm-up time to 60% of full light (max) (s)</b>	4 s
<b>Control gear required</b>	NO
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	10000
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	20

### Optical data

<b>Light colour</b>	840 Cool White
<b>CRI (Ra)</b>	80
<b>Colour temperature (K)</b>	4000
<b>Luminous flux (Rated) (lm)</b>	235
<b>Lumen maintenance at end of nominal life (%)</b>	85
<b>Luminous flux (Nominal) (lm)</b>	235

# Micro-Lynx

*MICRO-LYNX LUNA 840 GX53 6W SLV*

**0035905**

## Physical data


<b>Weight (kg)</b>	0.06
<b>Lamp Length (mm) - C/L</b>	17,5 mm
<b>Max. Lamp Diameter (mm) - D</b>	75,2 max.
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	8.10 x 8.10 x 2.95
<b>Outer package dimensions (L x W x H) (cm)</b>	28.00 x 19.50 x 9.20

## Micro-Lynx

MICRO-LYNX LUNA 840 GX53 6W SLV

0035905

### TECHNICAL DRAWINGS

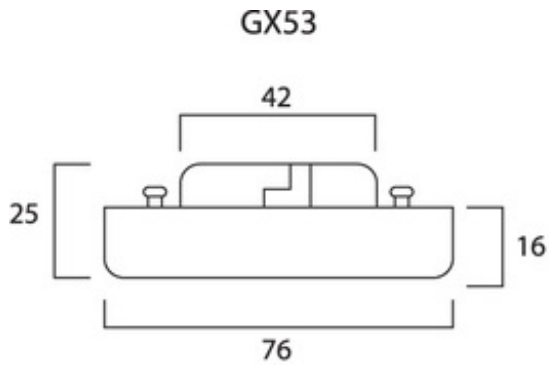

### ENERGY LABEL

