


Item # 70-782E14-1, 70-782E14-1 Socket / 10 Amp Rating, 300 Volts

14 Pin Economy, Ice Cube, DIN/Panel Mount with Rising Elevator Box Terminals, Module Compatible

This Item is Normally Stocked

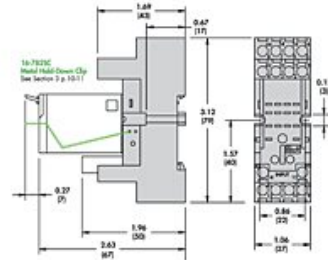

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

Specifications

Check Inventory	Check Distributor Inventory
Contact Configuration	4PDT
Number of Terminals	14
Mounting Style	DIN Rail Panel

Electrical Rating

Current Rating	10 A
Nominal Voltage Rating	300 V

Temperature

Storage Range	- 40 to + 105 °C
---------------	------------------

Construction

Protection Category (Finger Safe)	IP 20
Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Steel Zinc Plated
Screw Style	Combination Head
Screw Size	M3 mm
Screw Torque 3 mm (Maximum)	7 / 0.8 Lb-in / Nm
Terminal Connection	Elevator
Terminal Layout	Logic
Base	Square

Miscellaneous

Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm ₂
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm ₂
DIN Rail Mounting, EN 60715	35 mm
Chassis Mount Screw Torque	7 / 0.8 Lb-in / Nm
Flammability Rating	94V-0 Class
Body Color	Light Gray
DIN Locking Method	Metal Compression Spring

Product Certifications

Agency Approvals	CE RoHS UL CSA
-------------------------	-------------------------