

## X-CELL RECHARGEABLE TORCHES



- 1/2 mile halogen beam
- Up to 8 hours light
- Robust/NATO coded
- c/w X-Cell **"Green"** battery and charging leads
- Charges *direct* from both mains and vehicle with no separate chargers/adaptors required
- Cost-saving — up to 3,000 recharge cycles
- Cannot be overcharged or damaged if left in discharged state
- Spot/Flood adjustment
- Floats beam up

Model	Operating Time	Weight	Recharge Time	Strap/Stand	Dimensions (all models)	Colour
2500H	4 hours	1 kg	12/14 hours	No	210mm × 124mm × 135mm	Standard colour Yellow with White lens rim
550H	4 hours	1.1 kg	12/14 hours	Yes		Khaki with Black lens rim available on request
800H	8 hours	1.2 kg	16/18 hours	Yes		Other colours available to special order

### BULBS

N300 standard fitted halogen bulb — 50,000 candlepower, 0.3 amp, 500 hours life

N500 doubles power output — 100,000 candlepower, 0.5 amp, 500 hours life

N1000 **Specialist Application.** The ultimate halogen bulb. (High temperature bulb holder also available to allow an amazing 70 minutes continuous use in 800H.) — 400,000 candlepower, 1.8 amp, 50 hours life.

**ACCESSORIES** — Wall bracket, Charging lead c/w cigar lighter plug


## FLUORESCENT RECHARGEABLE LANTERNS



- 8' high-efficiency 6 watt fluorescent tube
- Wide shadow-free light
- c/w X-Cell **"Green"** battery and charging leads
- Charges *direct* from both mains and vehicle with no separate chargers/adaptors required
- Polycarbonate lens
- Lightweight and weatherproof
- Integral keyhole for semi-permanent mounting

Model	Battery	Operating Time	Weight	Recharge Time	Dimensions (all models)	Colours
F-1	Plus	2 hours	1 kg	12/14 hours	240mm × 165mm × 28mm	Khaki or Black
F-2	Major	4 hours	1.1 kg	16/18 hours		

## X-CELL RECHARGEABLE BATTERIES

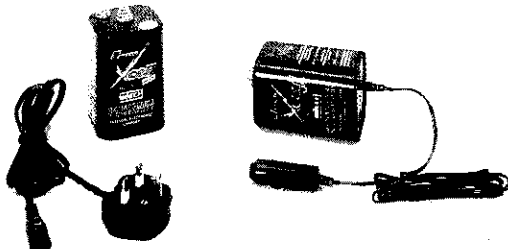

- Instantly converts 6 volt equipment to economical, environmentally friendly operation
- The only *complete* rechargeable replacement for 6 volt (PJ996) lantern battery
- Totally maintenance free — will not leak or corrode
- Up to 3,000 recharge cycles
- c/w charging leads
- Charges *direct* from both mains and vehicle — no separate chargers/adaptors required
- Retains charge for over one year
- Cannot be overcharged or damaged if left in discharged state
- Protected against short circuit
- Operates from -40°C to +60°C
- Negligible running cost — less than 0.5p per charge

And remember . . . the **GREEN PRODUCT AWARD!** — by using this battery you are helping to save the environment.

Model	Discharge Time in standard 6 volt handlamp	Recharge Time	Weight	Dimensions	Maximum Continuous Current
Plus	3 hours	12/14 hours	585 gms	97mm × 60mm × 60mm	4-5 amps
Major	4.5 hours	16/18 hours	655 gms	97mm × 60mm × 60mm	4-5 amps