


TDE Series European Footprint Pcb DSub


A new addition to the TDE series meeting the footprint requirements of DIN41652 variant 2 and offering a high level of performance and standard features.

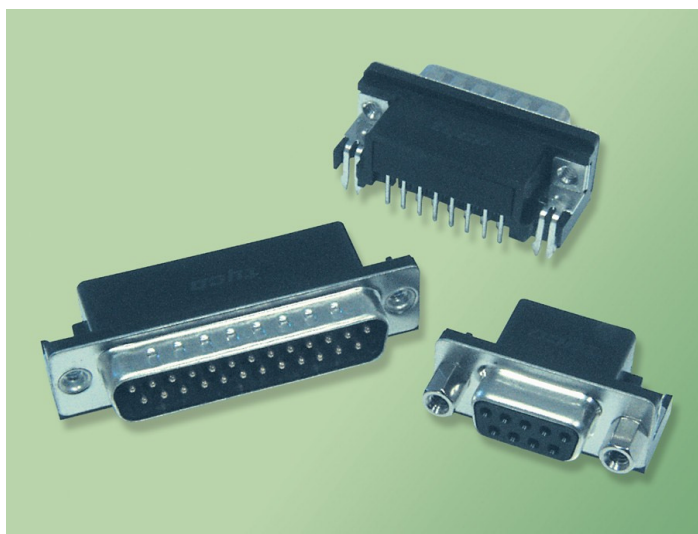

- Low Cost
- European standard pcb footprint in accordance with DIN 41652 variant 2
- 0.38um (15u") Gold Plated Contacts
- Boardlocks Included as Standard
- Choice of 4-40 or M3 Threaded Inserts or Female Screwlocks
- UL Approved

Specification

Front shell	Steel, tin plated
Housing	Black thermoplastic
Flammability	UL 94V-0
Contact material - pin	Brass
Contact material - socket	Phosphor bronze
Contact area plating	0.38um Au
Current rating	5A
Insulation resistance	1000 MΩ min
Dielectric strength	500Vdc for 2 mins
Temperature rating	-55 to +105C
UL file no	E28476

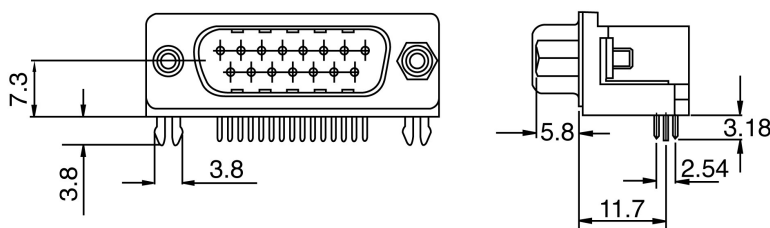

All dimensions in mm

Plug with Boardlocks

No of Ways	4-40 Threaded Inserts	4-40 Female Screwlocks	M3 Threaded Inserts	M3 Female Screwlocks
9	1-1634580-2	3-1634580-2	2-1634580-2	4-1634580-2
15	1-1634581-2	3-1634581-2	2-1634581-2	4-1634581-2
25	1-1634582-2	3-1634582-2	2-1634582-2	4-1634582-2
37	1-1634583-2	3-1634583-2	2-1634583-2	4-1634583-2

Socket with Boardlocks

No of Ways	4-40 Threaded Inserts	4-40 Female Screwlocks	M3 Threaded Inserts	M3 Female Screwlocks
9	1-1634584-2	3-1634584-2	2-1634584-2	4-1634584-2
15	1-1634585-2	3-1634585-2	2-1634585-2	4-1634585-2
25	1-1634586-2	3-1634586-2	2-1634586-2	4-1634586-2
37	1-1634587-2	3-1634587-2	2-1634587-2	4-1634587-2