


Compact PCB Antennas for GSM Cellular applications where high performance is required from a small size.

GSMQB Antenna

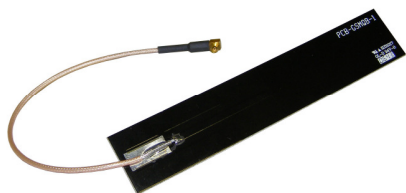

GSMMQB Antenna



- | | |
|--|--|
| <ul style="list-style-type: none"> • Higher Performance PCB Antenna • 850/900/1800/1900MHz • Active gain: +1dB • Linear Polarisation • 15cm RG178 Connecting Lead • VSWR ≤ 2.0 • Groundplane Independent • Available with SMA/ufl or MMCX Fixing • Power Rating 10W • Operates from 2.7—5.5V | <ul style="list-style-type: none"> • Miniature Sized PCB Antenna • 850/900/1800/1900MHz • VSWR ≤ 3.0 • Omni Directional • Horizontal Polarisation • 10cm RG174 Connecting Lead • 50 Ω Impedance • Power Rating 10W • Supplied with ufl Connector • Alternative connectors available on request |
|--|--|

Part Numbers

	Length	Width	Max Height	Cable Length	Connector
ANT-GSMQB-MMCX	110mm	20mm	5mm	100mm	MMCX 90°
ANT-GSMQB-SMA	110mm	20mm	5mm	100mm	SMA
ANT-GSMMQB-UFL	34mm	7mm	0.8mm	100mm	ufl

R F Solutions Ltd., Lewes, E. Sussex. BN8 6JL. England.

Email : sales@rfsolutions.co.uk <http://www.rfsolutions.co.uk>

Tel: +44 (0)1273 898 000 Fax: +44 (0)1273 480 661