

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130006-1163](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change® A-Size Single-Ended Cordset, 5 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 1.83m (6.0') Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Cordsets
Series [130006](#)
Connector End A Mini-Change®
Connector End B Pigtail
IP Rating IP67
Overview [Brad® Mini-Change® Connectors](#)
Product Name Mini-Change®
Protocol N/A
Region America
Type Single Ended
UPC 78678843252

Physical

Cable Diameter 12.70mm (.500")
Cable Length 1.83m (6.0')
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Female-Pigtail
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Contact Copper Alloy
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Net Weight 336.560/g
Orientation Straight
Poles 5
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 16
Wire/Cable Type STOOW

Electrical


Current - Maximum per Contact 8A
Voltage - Maximum 600V

Material Info

Old Part Number 105000A01F060

Reference - Drawing Numbers

Sales Drawing SD-130006-001

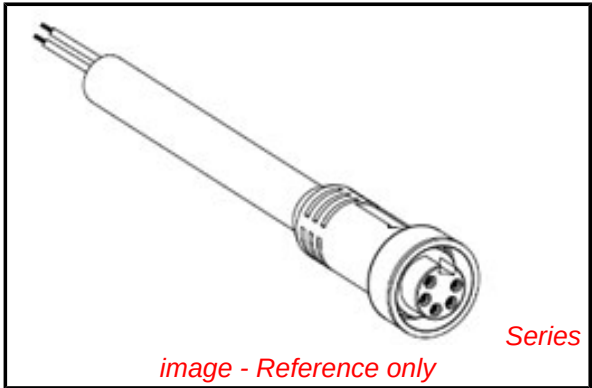

EU RoHS
RoHS Compliant by Exemption
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS

Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[130006Series](#)

This document was generated on 10/01/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION