

Intashield IS-200/IS-250

PCI 2 Port RS232

■ PRODUCT INFORMATION

- IS-200 Standard height
Bracket Height = 120mm
- IS-250 Low profile
Bracket Height = 80mm

■ OPERATING SYSTEMS:

- Windows 7 - 32bit & 64bit
- Windows Vista - 32bit & 64bit
- Windows XP - 32bit & 64bit

■ PRODUCT FEATURES:

- 2x9 pin, D type RS232 Serial Ports
- Low profile card is a 1 + 1 configuration requiring a second bracket for the port on the fly lead
- Universal PCI Bus - will fit into any PCI slot 5V or 3.3V
- Fully Plug & Play - simple installation and test software provided
- 1 year Warranty with option to sign up for additional free year

■ SPECIFICATIONS:

- UART: 16550
- Speed: 115,200 maximum baud rate
- Data Bits: 5, 6, 7 or 8
- Stop Bits: 1, 1.5 or 2
- Parity: odd, even, none, mark or space
- FIFO Size: 16 byte




IS-200

This card provides 2 industry standard 9 pin RS232 serial COM ports in a single PCI slot.

As PCI is fully Plug and Play compatible your BIOS and operating system will automatically configure the card ensuring conflict free installation. Choose between standard height and low profile options.

IS-200/250

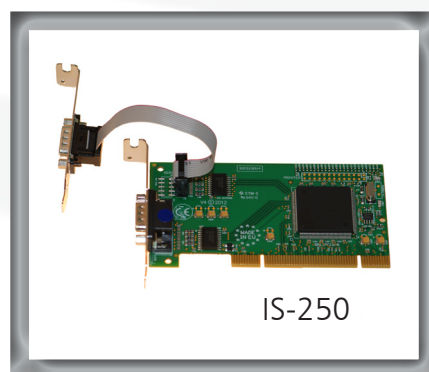

IS-250