

Datasheet

RS Pro BA9s Filament Indicator Lamp, Clear, 24 V, 83 mA, 10000h

RS Stock No: **577-471**



Product Details

RS Pro BA9s filament indicator lamp comes with clear lens. It performs at a rated voltage of 24 V and current of 83 mA from a stabilised 50 Hz AC supply. The lamp has 10000 h life. The power consumption may vary up to $\pm 10\%$ compared to the listed values at the rated supply voltage.

Features and Benefits

- Ambient temperature is in the range +20 to +25°C
- No mechanical vibration is present
- 5% below will significantly increase lamp life




Specifications:

Current Rating	83 mA
Diameter	9 mm
Lamp Base	BA9s
Lamp Size	T9
Length	23 mm
Lens Colour	Clear
Life Hours	10000 h
Luminosity	6.3 lm
Voltage Rating	24 V

RS Stock No.	577-471
--------------	---------

DRAWING

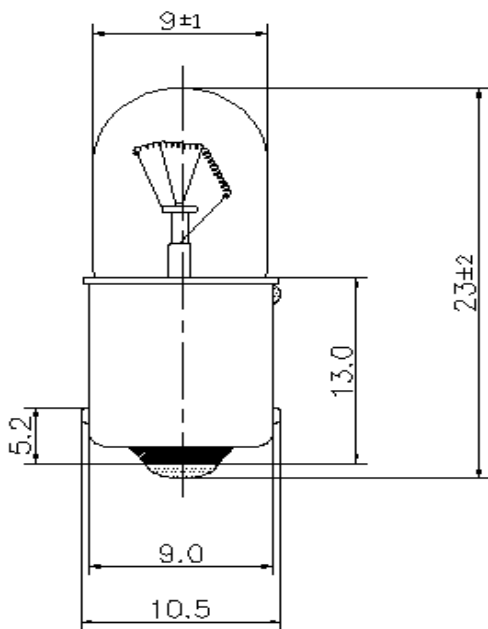

Unit : mm

1. Structure	Bulb Type	T9 Clear
	Bulb Diameter	9±1mm
	Length	23±2mm
	Base Type	BA9S
2. Design Characteristics	Voltage	24V
	Wattage	2W±10%
	Amperage	83.333mA±10%
	Filament Type	C-2F
		Vacuum type
Life Hours	10,000Hrs	