

Elite shaverlight (with push plate and shaver socket)

ELITE CHROME 11W LYNX-S PUSH PLATE+SHAVER

0053401



Product features

- Slim profile 11w compact fluorescent shaverlight for either vertical or horizontal surface mounting which is suitable for Zone 3 bathroom applications (no waterjets). Luminaire comes complete with push plate for switching of the lamp, dual voltage (120V/240V) shaver socket and 11w Lynx-S warm white (2700K) lamp. Chrome finish.



PRODUCT OVERVIEW

Certifications	CE
Colour temperature (K)	2700
Colour	Chrome
Control gear mounting	Integral
Control gear type	Conventional
CRI (Ra)	80
Product EAN number	5410288534015
Electrical protection	Class II
Environment	Internal
General application	Hospitality, Residential & Consumer
IP rating	IP21
Product code	0053401
Light colour	Warm white
Mount	Wall Surface
Product name	ELITE CHROME 11W LYNX-S PUSH PLATE+SHAVER
Included lamp	0025883
ETIM Class	EC002892

DATA TABLE

General data

Certifications	CE
Environment	Internal
General application	Hospitality, Residential & Consumer
Product code	0053401
Mount	Wall Surface
Product name	ELITE CHROME 11W LYNX-S PUSH PLATE+SHAVER
ETIM Class	EC002892

Optical data

Colour temperature (K)	2700
-------------------------------	------

Elite shaverlight (with push plate and shaver socket)

ELITE CHROME 11W LYNX-S PUSH PLATE+SHAVER

0053401

CRI (Ra)	80
Distribution type	Symmetric
Light colour	Warm white
Adjustable chromaticity	N

Electrical data

Control gear mounting	Integral
Control gear type	Conventional
Electrical protection	Class II
Energy efficiency level	A
kWh per 1000 hours burning time	14
Mains voltage (V)	100-240V~

 
Physical data

Colour	Chrome
Diffuser finish	Opal
Nominal Product Height (mm)	92
IP rating	IP21
Nominal Product Length (mm)	480
Weight (kg)	1.354
Nominal Product Width (mm)	50

Packaging

Product EAN number	5410288534015
Packaging single height (cm)	53.0
Packaging single length (cm)	5.4
Single packaging type	Carton
Packaging single width (cm)	12.0
Units per outer package	1
Packaging outer height (cm)	5.4
Packaging outer length (cm)	53.0
Packaging outer width (cm)	12.0

TECHNICAL DRAWINGS




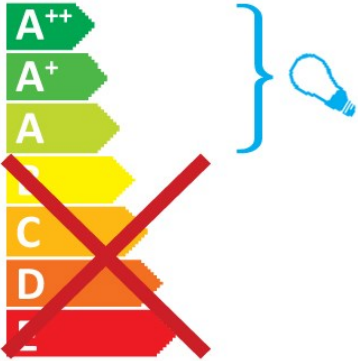
Elite shaverlight (with push plate and shaver socket)

ELITE CHROME 11W LYNX-S PUSH PLATE+SHAVER


0053401


SYLVANIA 0053401

 This luminaire is compatible with bulbs of the energy classes:





This luminaire is sold with a bulb of the energy class:

874/2012 

 This luminaire is compatible with bulbs of the energy classes:

This luminaire is sold with a bulb of the energy class:

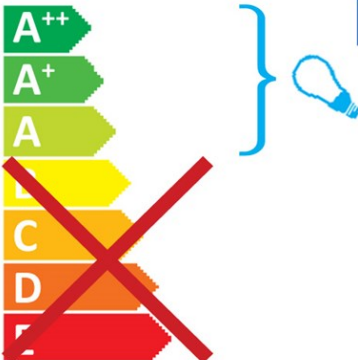

SYLVANIA 0053401  874/2012