

1455

Extruded Aluminum

Key Features:

- Designed to house P.C. boards or for equipment interfacing.
- Sized for standard Eurocards.
- P.C. boards mount horizontally by sliding into internal slots extruded into the enclosure body.
- Rugged body constructed from extruded aluminum with a minimum thickness of .06" (1.5 mm).
- Extruded body includes a slide removable "belly" plate - except in smaller sizes "A" through "D"

Includes:

- Two aluminum end panels - finish matched to extruded aluminum body (or link here if you prefer our solid plastic end panel version)
- Two black ABS plastic bezels (your option to install)
- Extruded aluminum body - choice of clear, black, blue or red anodized finish
- Self adhesive rubber feet. Replacements are available - order part number **1421T2CL** (pack of 24).
- All hardware - end panel screws are #6 x 3/8" TTT - thread rolling, steel screws with a #4 flat head phillips drive. Zinc plate finish - either clear or black (black screws are used on the black, blue & red models).
- For black replacement screws (quantity 100) order part number **1455MS100BK**
- For clear replacement screws (quantity 100) order part number **1455MS100**
- NOTE: Recommended screw torque is 5 lbf/in

Extras

Replacement Rubber Feet (24-pack)



1421T2CL

Replacement Screws (100-pack)



1455MS100BK



1455MS100



www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244

Most models feature a slide-in belly plate for easy access to the inside of the enclosure.



All models feature internal PC board slots for easy mounting and assembly.



Accessories



Plastic bezels available in 5 colors: Yellow, Red, Transparent Red, Black, and Transparent Blue.

Mix and match colors with extra end panels. Available in four anodized finishes: black, clear, red, and blue.



Flanged end panels kits are available in clear or black anodize. Both come with black screws.

Refer to accessories table for part numbers.



1455

Extruded Aluminum

Part Number With Aluminum End Panels	Part Number With Plastic End Panels	Anodized Color	Units	Length	Width	Height
1455D601	1455D602	Clear	Inches mm	2.36 60	1.76 45	0.99 25
1455D601BK	1455D602BK	Black				
1455D601BU		Blue				
1455D601RD		Red				
1455D801	1455D802	Clear	Inches mm	3.15 80	1.76 45	0.99 25
1455D801BK	1455D802BK	Black				
1455D801BU		Blue				
1455D801RD		Red				
	1455A802	Clear	Inches mm	3.15 80	2.76 70	0.47 12
	1455A802BK	Black				
	1455A802BU	Blue				
	1455A802RD	Red				
	1455B802	Clear	Inches mm	3.15 80	2.82 71.7	0.75 19
	1455B802BK	Black				
	1455B802BU	Blue				
	1455B802RD	Red				
1455C801	1455C802	Clear	Inches mm	3.15 80	2.13 54	0.91 23
1455C801BK	1455C802BK	Black				
1455C801BU	1455C802BU	Blue				
1455C801RD	1455C802RD	Red				
	1455A1002	Clear	Inches mm	3.94 100	2.76 70	0.47 12
	1455A1002BK	Black				
	1455A1002BU	Blue				
	1455A1002RD	Red				
	1455B1002	Clear	Inches mm	3.94 100	2.82 71.7	0.75 19
	1455B1002BK	Black				
	1455B1002BU	Blue				
	1455B1002RD	Red				
	1455A1202	Clear	Inches mm	4.72 120	2.76 70	0.47 12
	1455A1202BK	Black				
	1455A1202BU	Blue				
	1455A1202RD	Red				
	1455B1202	Clear	Inches mm	4.72 120	2.82 71.7	0.75 19
	1455B1202BK	Black				
	1455B1202BU	Blue				
	1455B1202RD	Red				
1455C1201	1455C1202	Clear	Inches mm	4.72 120	2.13 54	0.91 23
1455C1201BK	1455C1202BK	Black				
1455C1201BU		Blue				
1455C1201RD		Red				



1455

Extruded Aluminum

Part Number With Aluminum End Panels	Part Number With Plastic End Panels	Anodized Color	Units	Length	Width	Height
1455J1201	1455J1202	Clear	Inches mm	4.72 120	3.07 78	1.06 27
1455J1201BK	1455J1202BK	Black				
1455J1201BU		Blue				
1455J1201RD		Red				
1455K1201	1455K1202	Clear	Inches mm	4.72 120	3.07 78	1.69 43
1455K1201BK	1455K1202BK	Black				
1455K1201BU		Blue				
1455K1201RD		Red				
1455L1201	1455L1202	Clear	Inches mm	4.72 120	4.06 103	1.2 30.5
1455L1201BK	1455L1202BK	Black				
1455L1201BU		Blue				
1455L1201RD		Red				
1455N1201	1455N1202	Clear	Inches mm	4.72 120	4.06 103	2.09 53
1455N1201BK	1455N1202BK	Black				
1455N1201BU		Blue				
1455N1201RD		Red				
1455J1601	1455J1602	Clear	Inches mm	6.3 160	3.07 78	1.06 27
1455J1601BK	1455J1602BK	Black				
1455J1601BU		Blue				
1455J1601RD		Red				
1455K1601	1455K1602	Clear	Inches mm	6.3 160	3.07 78	1.69 43
1455K1601BK	1455K1602BK	Black				
1455K1601BU		Blue				
1455K1601RD		Red				
1455L1601	1455L1602	Clear	Inches mm	6.3 160	4.06 103	1.2 30.5
1455L1601BK	1455L1602BK	Black				
1455L1601BU		Blue				
1455L1601RD		Red				
1455N1601	1455N1602	Clear	Inches mm	6.3 160	4.06 103	2.09 53
1455N1601BK	1455N1602BK	Black				
1455N1601BU		Blue				
1455N1601RD		Red				
1455P1601	1455P1602	Clear	Inches mm	6.3 160	4.92 125	1.2 30.5
1455P1601BK	1455P1602BK	Black				
1455P1601BU		Blue				
1455P1601RD		Red				
1455Q1601	1455Q1602	Clear	Inches mm	6.3 160	4.92 125	2.03 51.5
1455Q1601BK	1455Q1602BK	Black				
1455Q1601BU		Blue				
1455Q1601RD		Red				



1455

Extruded Aluminum

 
Part Number With Aluminum End Panels	Part Number With Plastic End Panels	Anodized Color	Units	Length	Width	Height
1455R1601	1455R1602	Clear	Inches mm	6.3 160	6.5 165	1.2 30.5
1455R1601BK	1455R1602BK	Black				
1455R1601BU		Blue				
1455R1601RD		Red				
1455T1601	1455T1602	Clear	Inches mm	6.3 160	6.5 165	2.03 51.5
1455T1601BK	1455T1602BK	Black				
1455T1601BU		Blue				
1455T1601RD		Red				
1455L2201	1455L2202	Clear	Inches mm	8.66 220	4.06 103	1.2 30.5
1455L2201BK	1455L2202BK	Black				
1455L2201BU		Blue				
1455L2201RD		Red				
1455N2201	1455N2202	Clear	Inches mm	8.66 220	4.06 103	2.09 53
1455N2201BK	1455N2202BK	Black				
1455N2201BU		Blue				
1455N2201RD		Red				
1455P2201	1455P2202	Clear	Inches mm	8.66 220	4.92 125	1.2 30.5
1455P2201BK	1455P2202BK	Black				
1455P2201BU		Blue				
1455P2201RD		Red				
1455Q2201	1455Q2202	Clear	Inches mm	8.66 220	4.92 125	2.03 51.5
1455Q2201BK	1455Q2202BK	Black				
1455Q2201BU		Blue				
1455Q2201RD		Red				
1455R2201	1455R2202	Clear	Inches mm	8.66 220	6.5 165	1.2 30.5
1455R2201BK	1455R2202BK	Black				
1455R2201BU		Blue				
1455R2201RD		Red				
1455T2201	1455T2202	Clear	Inches mm	8.66 220	6.5 165	2.03 51.5
1455T2201BK	1455T2202BK	Black				
1455T2201BU		Blue				
1455T2201RD		Red				



1455

Extruded Aluminum

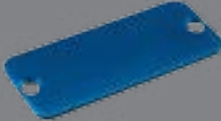
For Part Number Starting With	 Black		 Yellow		 Red		 Translucent Red		 Translucent Blue	
	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack
1455A	1455APLBK	1455APLBK-10								
1455B	1455BPLBK	1455BPLBK-10								
1455C	1455CPLBK	1455CPLBK-10	1455CPLY	1455CPLY-10	1455CPLRED	1455CPLRED-10	1455CPLTRD	1455CPLTRD-10	1455CPLTBU	1455CPLTBU-10
1455D	1455DPLBK	1455DPLBK-10								
1455J	1455JPLBK	1455JPLBK-10	1455JPLY	1455JPLY	1455JPLRED	1455JPLRED-10	1455JPLTRD	1455JPLTRD-10	1455JPLTBU	1455JPLTBU-10
1455K	1455KPLBK	1455KPLBK-10	1455KPLY	1455KPLY	1455KPLRED	1455KPLRED-10	1455KPLTRD	1455KPLTRD-10	1455KPLTBU	1455KPLTBU-10
1455L	1455LPLBK	1455LPLBK-10	1455LPLY	1455LPLY	1455LPLRED	1455LPLRED-10	1455LPLTRD	1455LPLTRD-10	1455LPLTBU	1455LPLTBU-10
1455N	1455NPLBK	1455NPLBK-10	1455NPLY	1455NPLY	1455NPLRED	1455NPLRED-10	1455NPLTRD	1455NPLTRD-10	1455NPLTBU	1455NPLTBU-10
1455P	1455PPLBK	1455PPLBK-10	1455PPPLY	1455PPPLY	1455PPLRED	1455PPLRED-10	1455PPLTRD	1455PPLTRD-10	1455PPLTBU	1455PPLTBU-10
1455Q	1455QPLBK	1455QPLBK-10	1455QPLY	1455QPLY	1455QPLRED	1455QPLRED-10	1455QPLTRD	1455QPLTRD-10	1455QPLTBU	1455QPLTBU-10
1455R	1455RPLBK	1455RPLBK-10	1455RPLY	1455RPLY	1455RPLRED	1455RPLRED-10	1455RPLTRD	1455RPLTRD-10	1455RPLTBU	1455RPLTBU-10
1455T	1455TPLBK	1455TPLBK-10	1455TPLY	1455TPLY	1455TPLRED	1455TPLRED-10	1455TPLTRD	1455TPLTRD-10	1455TPLTBU	1455TPLTBU-10

For Part Number Starting With	 Black		 Yellow		 Red		 Translucent Red		 Translucent Blue	
	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack	2-pack	10-pack
1455C	1455CBBK	1455CBBK-10	1455CBBY	1455CBBY-10	1455CBRED	1455CBRED-10	1455CBTRD	1455CBTRD-10	1455CBTBU	1455CBTBU-10
1455D	1455DBBK	1455DBBK-10	1455DBBY	1455DBBY-10	1455DBRED	1455DBRED-10	1455DBTRD	1455DBTRD-10	1455DBTBU	1455DBTBU-10
1455J	1455JBBK	1455JBBK-10	1455JBBY	1455JBBY-10	1455JBRED	1455JBRED-10	1455JBTRD	1455JBTRD-10	1455JBTBU	1455JBTBU-10
1455K	1455KBBK	1455KBBK-10	1455KBBY	1455KBBY-10	1455KBRED	1455KBRED-10	1455KBTRD	1455KBTRD-10	1455KBTBU	1455KBTBU-10
1455L	1455LBBK	1455LBBK-10	1455LBBY	1455LBBY-10	1455LBRED	1455LBRED-10	1455LBTRD	1455LBTRD-10	1455LBTBU	1455LBTBU-10
1455N	1455NBBK	1455NBBK-10	1455NBBY	1455NBBY-10	1455NBRED	1455NBRED-10	1455NBTRD	1455NBTRD-10	1455NBTBU	1455NBTBU-10
1455P	1455PBBK	1455PBBK-10	1455PBBY	1455PBBY-10	1455PBRED	1455PBRED-10	1455PBTRD	1455PBTRD-10	1455PBTBU	1455PBTBU-10
1455Q	1455QBBK	1455QBBK-10	1455QBBY	1455QBBY-10	1455QBRED	1455QBRED-10	1455QBTRD	1455QBTRD-10	1455QBTBU	1455QBTBU-10
1455R	1455RBBK	1455RBBK-10	1455RBBY	1455RBBY-10	1455RBRED	1455RBRED-10	1455RBTRD	1455RBTRD-10	1455RBTBU	1455RBTBU-10
1455T	1455TBBK	1455TBBK-10	1455TBBY	1455TBBY-10	1455TBRED	1455TBRED-10	1455TBTRD	1455TBTRD-10	1455TBTBU	1455TBTBU-10



1455

Extruded Aluminum

For Part Number Starting With				
	Clear Anodize	Black Anodize	Blue Anodize	Red Anodize
	10-pack	10-pack	10-pack	10-pack
1455C	1455CAL-10	1455CALBK-10	1455CALBU-10	1455CALRD-10
1455D	1455DAL-10	1455DALBK-10	1455DALBU-10	1455DALRD-10
1455J	1455JAL-10	1455JALBK-10	1455JALBU-10	1455JALRD-10
1455K	1455KAL-10	1455KALBK-10	1455KALBU-10	1455KALRD-10
1455L	1455LAL-10	1455LALBK-10	1455LALBU-10	1455LALRD-10
1455N	1455NAL-10	1455NALBK-10	1455NALBU-10	1455NALRD-10
1455P	1455PAL-10	1455PALBK-10	1455PALBU-10	1455PALRD-10
1455Q	1455QAL-10	1455QALBK-10	1455QALBU-10	1455QALRD-10
1455R	1455RAL-10	1455RALBK-10	1455RALBU-10	1455RALRD-10
1455T	1455TAL-10	1455TALBK-10	1455TALBU-10	1455TALRD-10

For Part Number Start- ing With		
	Clear Anodize	Black Anodize
1455C	1455CF	1455CFBK
1455D	1455DF	1455DFBK
1455J	1455JF	1455JFBK
1455K	1455KF	1455KFBK
1455L	1455LF	1455LFBK
1455N	1455NF	1455NFBK
1455P	1455PF	1455PFBK
1455Q	1455QF	1455QFBK
1455R	1455RF	1455RFBK
1455T	1455TF	1455TFBK

Critical Data, No Questions

PDF Data Sheets, 2D AutoCAD, and 3D Models are available for download immediately from our web site.



www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244