

Interface module - UM-D37M/DS/FU/LED/AO/C300/L - 2905243

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




16-channel module for Honeywell C300 analog output cards with disconnect, test points, socketed 500 mA fuses and fuse status indicator.

Why buy this product

- These VARIOFACE modules are used in combination with the relevant front adapters
- Per channel pluggable 500 mA fusing
- Per channel disconnects with test points
- LED blown fuse indication
- Din rail mounting, includes grounding foot
- Per channel shield connection
- UM-PRO housing



Key commercial data

Packing unit	1
GTIN	 4 046356 947091
Custom tariff number	85369010

Technical data

Dimensions

Width	104 mm
Height	142.3 mm
Depth	79 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 85 °C
Ambient temperature (storage/transport)	-40 °C ... 85 °C

General

Max. permissible operating voltage	24 V DC
Max. perm. current (per branch)	500 mA (fuse limited)
Max. permissible current (separate power supply)	4 A (via D-SUB)

Interface module - UM-D37M/DS/FU/LED/AO/C300/L - 2905243

Technical data

General

Number of positions	37
Status display	No
Mounting position	any
Assembly instructions	In rows with zero spacing
Standards/regulations	DIN EN 50178

Connection data for connection 1

Connection name	Field level
Connection method	Screw connection with disconnect
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12
Stripping length	8 mm
Screw thread	M 3

Connection data for connection 2

Connection name	Controller level
Connection method	D-SUB pin strip
Number of positions	37

Supported controller

Controller	HONEYWELL C300
- suitable I/O card	CX-TAOX01
	CX-TAOX11
	CX-TAOX51
	CX-TAOX61
	CX-TAON01
	CX-TAON11
	8X-TAOXA1
	8X-TAOXB1

Classifications

eCl@ss

eCl@ss 4.1	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 8.0	27141152

Interface module - UM-D37M/DS/FU/LED/AO/C300/L - 2905243

Classifications

ETIM

ETIM 4.0	EC001423
ETIM 5.0	EC002780

Accessories

Accessories

System cable

Cable - CABLE-D37SUB/B/B/ 100/KONFEK/S - 2305509



Assembled, shielded circular cable, with D-SUB socket strip, 37-pos. from both sides, cable length: 1 m

Cable - CABLE-D37SUB/B/B/ 200/KONFEK/S - 2305512



Assembled, shielded circular cable, with D-SUB socket strip, 37-pos. from both sides, cable length: 2m

Cable - CABLE-D37SUB/B/B/ 300/KONFEK/S - 2305525



Assembled, shielded circular cable, with D-SUB socket strip, 37-pos. from both sides, cable length: 3 m

Cable - CABLE-D37SUB/B/B/ 400/KONFEK/S - 2900759



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 4 m

Interface module - UM-D37M/DS/FU/LED/AO/C300/L - 2905243

Accessories

Cable - CABLE-D37SUB/B/B/ 600/KONFEK/S - 2900760



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 6 m

Cable - CABLE-D37SUB/B/B/ 800/KONFEK/S - 2900761



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 8 m

Cable - CABLE-D37SUB/B/B/1000/KONFEK/S - 2900762



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 10 m

Cable - CABLE-D37SUB/B/B/1500/KONFEK/S - 2900763



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 15 m

Cable - CABLE-D37SUB/B/B/2000/KONFEK/S - 2900764



Assembled, shielded round cable, with 37-pos. D-SUB socket strip on both sides; cable length 20 m

Necessary add-on products

Interface module - UM-D37M/DS/FU/LED/AO/C300/L - 2905243

Accessories

Front adapters - FLKM-PA-D37/HW/AN/C300 - 2900622



VARIOFACE front adapters, for Honeywell C300, series C I/O, max. 1 x 16 channels (37-pos. D-SUB connector) can be connected

Spare parts


Fuse - FUSE/TE5/500MA/F-10PCS - 2905276



Plug-in fuse (TE5[®]); nominal current: 500 mA; tripping behavior: fast-blow (F)

Drawings

Dimensioned drawing

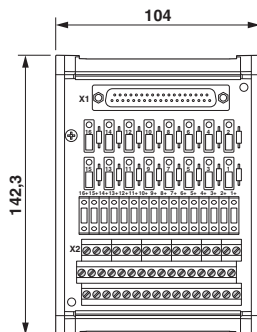

Circuit diagram

