

JST

Hand crimping tool
Type: WC-122

Features

Parallel action
operation

Ratchet release

Easy readjustment
of load

Contact locator with
insulation-stop

Precisely ground
profiles

Ergonomic soft grips
colour: green

Fully recyclable

Applicable terminal:
()HF-001T-0.8BS

Cross section range:
Profile 1: 28 AWG
Profile 2: 24 AWG/26AWG
Profile 3: 22 AWG


Crimp height specification
28 AWG - 0.60mm-0.65mm
26 AWG - 0.70mm
24 AWG - 0.75mm
22 AWG - 0.80mm

Operating instructions see overleaf

193


64

50

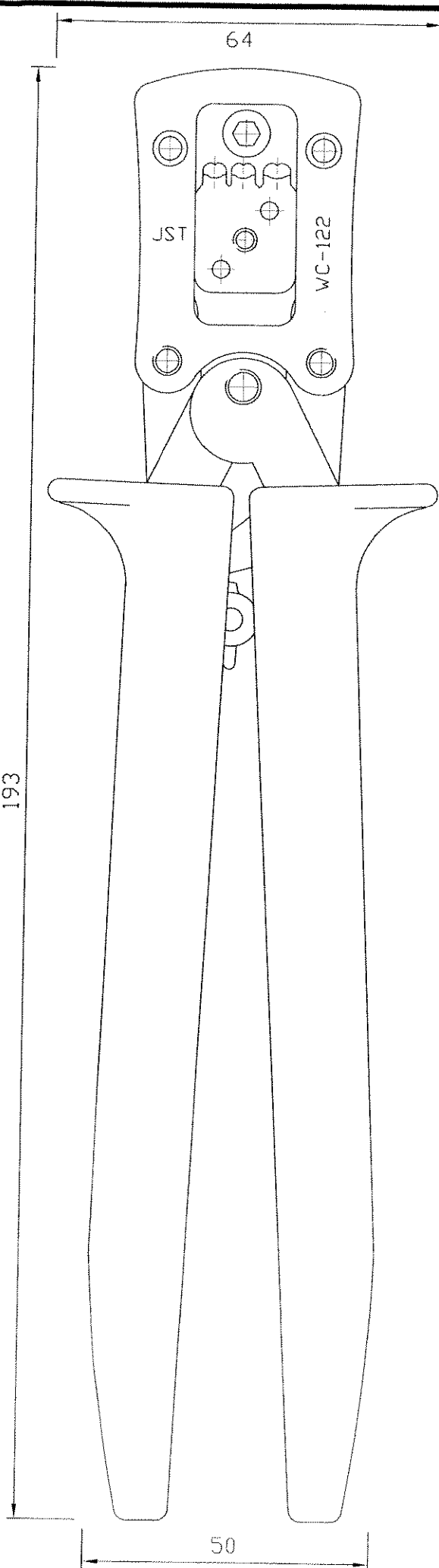

OPERATION INSTRUCTIONS


1.

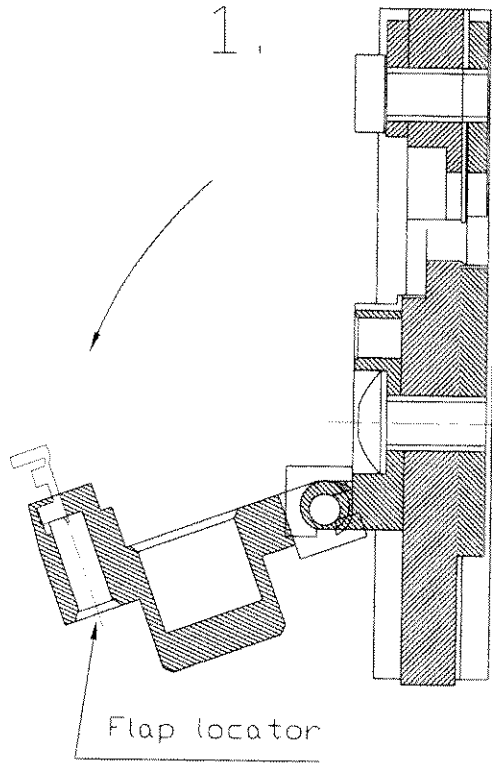

1. Open flap locator and
insert contact up to stop.

2. Close flap locator.


2.

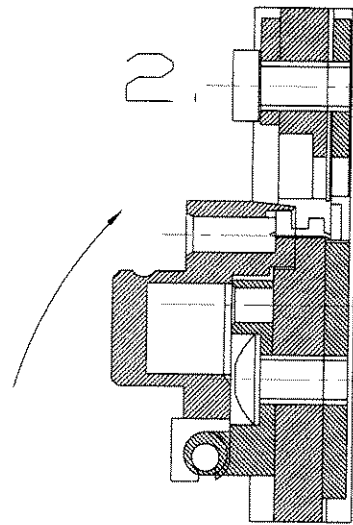


3. Close handtool
until first ratchet.

4. Insert wire up
to stop.

Insulation stop

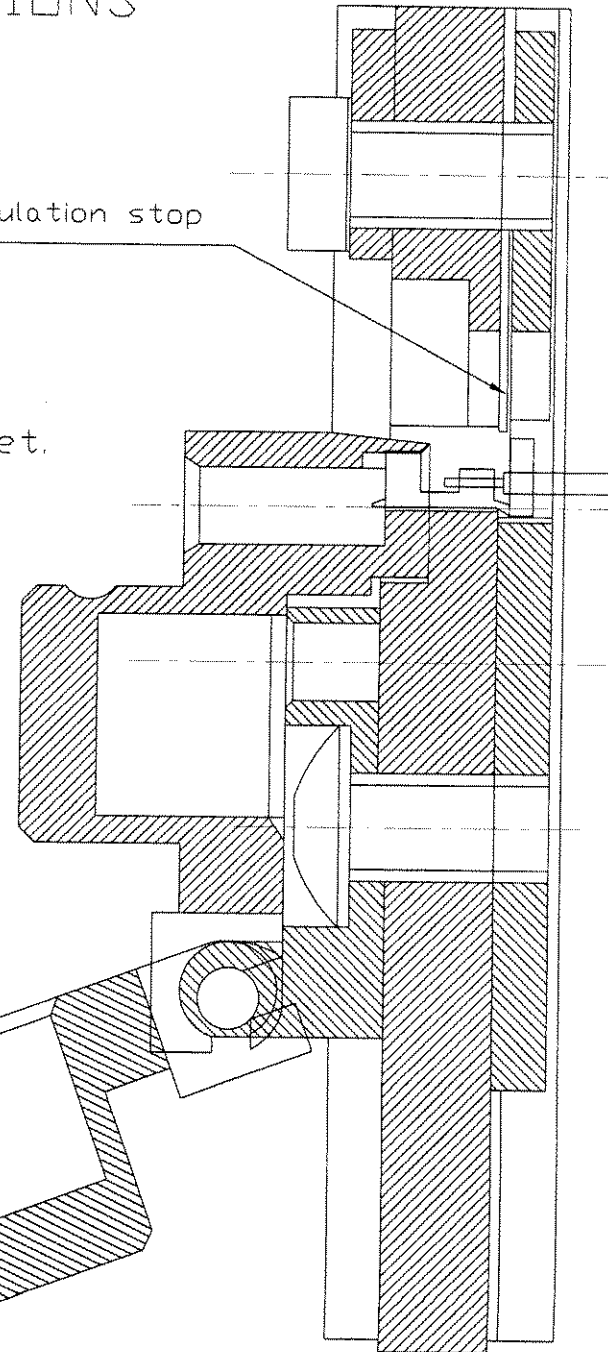

3.

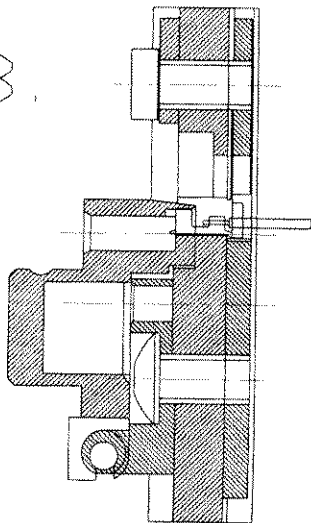

5. Close handtool
until the ratchet
releases.

6. Open flap locator
and carefully
remove the wire.

