

T box - DC-B 6-HTC-M25-M25-M - 1581052


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



DUPLICON, aluminum T-box, type B6, IP67 protection, 2 x M25 cable screw connection thread (without cable screw connection)



Key commercial data

Packing unit	10 pc
GTIN	 4 046356 154840
Weight per Piece (excluding packing)	248.96 g
Custom tariff number	85389099
Country of origin	Slovenia

Technical data

Dimensions

Height	72 mm
Width	81 mm
Length	81 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

General

Type	DC-B6
Housing type	Box mounting bases
Color	pearl gray
Locking type	For double locking latch
No. of cable exits	2
Cable exit	Lateral
Screw connection	none
Type of the screw connection	With M25 thread
Protective cover	No
Housing material	Aluminum die-cast

T box - DC-B 6-HTC-M25-M25-M - 1581052

Technical data

General

Housing surface material	EMC-conductive
--------------------------	----------------

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

Approvals

Approvals

Approvals

VDE Gutachten mit Fertigungsüberwachung


Ex Approvals

Approvals submitted

Approval details

T box - DC-B 6-HTC-M25-M25-M - 1581052

Approvals

VDE Gutachten mit Fertigungsüberwachung 	
Nominal current IN	25 A
Nominal voltage UN	690 V

Accessories

Accessories

Device marking

Label - EML (26,5X12)R SR - 0816854



Label, Roll, silver/matt, Unlabeled, Can be labeled with: THERMOMARK ROLL, THERMOMARK X, THERMOMARK S1.1, Mounting type: Adhesive, Lettering field: 26.5 x 12 mm

Full screw connection

Cable gland - HC-M-KV-M25(11-16) - 1690574



Metal screw connection up to 5 bar, thread length: 7 mm, cable diameter: 11 - 16 mm, WAF 27, screw connection: M25

Cable gland - HC-M-KV-M25(14-21) - 1646007



Metal screw connection up to 5 bar, thread length: 7 mm, cable diameter: 14 - 21 mm, WAF 34, screw connection: M25

Protective cover

Dust protection cover - DC-B 6-CT-P - 1581078




DUPLICON snap-on dust protection cover, polyamide (can be coated)

T box - DC-B 6-HTC-M25-M25-M - 1581052

Accessories

Drawings

Dimensioned drawing

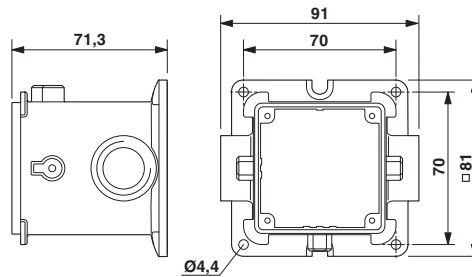

Dimensional drawing
