

LUMCOM 18 W 4000 K

Open distribution batten luminaires with LED



Technical data

Electrical data

Operating mode	ECG
Nominal wattage	18 W
Type of current	AC
Nominal voltage	220...240 V
Mains frequency	50/60 Hz

Photometrical data

Color rendering index Ra	≥ 80
Color temperature	4000 K
Luminous efficacy	98 lm/W
Luminous flux	1780 lm
Light color	840

Light technical data

Beam angle	120 °
------------	-------

Dimensions & weight

Product weight	680.00 g
Length	1180.0 mm
Width	25.0 mm

Functional component FC1

FC1 Functional component	Housing
FC1 Material	Aluminum
Color	Silver

Functional component FC2

FC2 Functional component	End cap
Color	White

Colors & materials


Product color	Silver
Surface feature of cover	Frosted

Temperatures

Product datasheet

Ambient temperature range	-20...+40 °C
----------------------------------	--------------

Additional product data

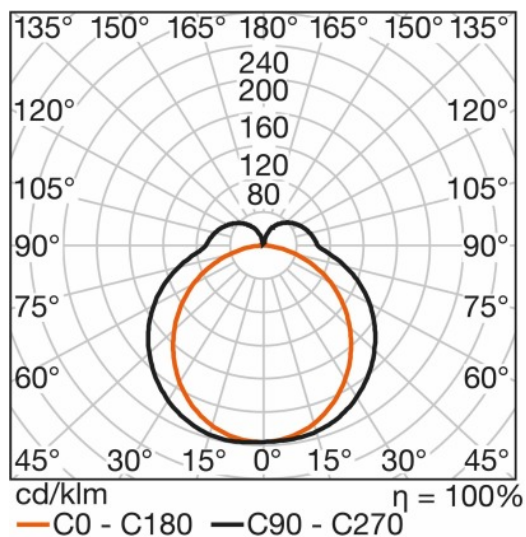

LDC typ luminance

Lamp designation according to LBS	LED
Light source included	Yes
Cover	Cover

Capabilities

Type of installation	Surface-mounted
LED module replaceable	Not replaceable
Arrangement	Single/continuous arrangement

Certificates & standards

Standards	CE
Protection class	II
Type of protection	IP20
EEL of included LED module	A++
Certification	CE

Country specific categorizations

Order number	0LJ211717840
---------------------	--------------

Product datasheet

Country specific information

Product code	METEL-Code	SEG number	STK number	UK Org
4052899909328	-	7010472	4107831	-

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4052899909366	LUMILUX COMBI LED 18 W 4000 K	Shipping carton box 2	72 mm x 125 mm x 1228 mm	11.05 dm ³	2520.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.