

3477PIR080P30-13, tyre RAL 5017


Swivel castor with total lock, tail end of castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole.

Wheel centre made of Polypropylene, Tread: solid rubber, blue non-marking, roller bearing

Technical Data

Wheel diameter	80 mm
Width of Tread	35 mm
Centre hole	13 mm
Offset	44.5 mm
Swivel Interference	242 mm
Overall height	108 mm
Temperature	- 20 / + 60 °C
Standard	EN 12532
Weight	0.954 kg
Swivel Radius	121 mm
Hardness of tread	A 80 Shore
Load capacity	70 kg
Load capacity (static)	140 kg

Roll performance	+	+	+	+	+
Movement noise	+	+	+	+	+
Attrition	+	+	+	+	+
Corrosion resistance	+	+	+	+	+

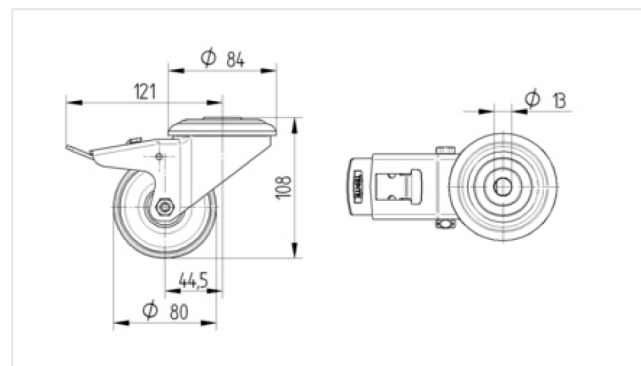

3477PIR080P30-13, tyre RAL 5017

