


Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	47	14	13,8	6,55	0,275	37000	19000	0,12	E2.6303-2Z/C3

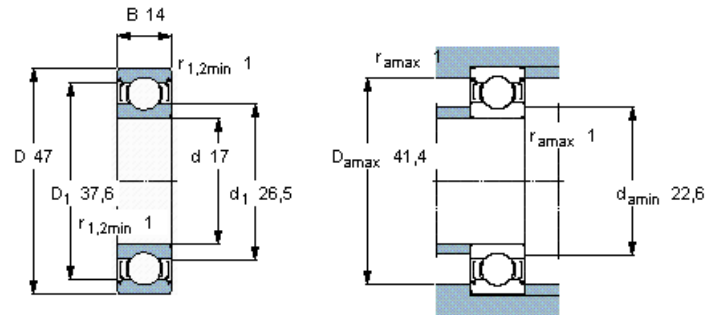

Calculation factors

k_r 0,03
 f_0 12