

## Housing - HC-B 6-SMLD-74/O1PG21 - 1678156

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting base, with single locking latch, height: 74 mm, with gland, 1 x Pg21, with protective cover



### Key commercial data

Packing unit	10 pc
GTIN	 4 017918 151713
Weight per Piece (excluding packing)	328.5 g
Custom tariff number	85389099
Country of origin	Germany
Note	Made to Order (non-returnable)

### Technical data

#### Dimensions

Height	74 mm
Width	57 mm
Length	84 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Note	For contact inserts HC-B6, BB10, DD24, M Tall housings for extra large wiring space
Type	B6
Housing type	Box mounting bases
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	Left (view of the opened single locking latch)
Screw connection	none

# Housing - HC-B 6-SMLD-74/O1PG21 - 1678156

## Technical data

### General

Type of the screw connection	1x Pg21
Protective cover	Yes
Housing material	Aluminum die-cast
Housing surface material	Powder-coated, gray
Seal material	NBR
Material lock	Stainless steel, handle: PA
Material grip body interlock	PA
Material, protective cover	Polyamide
Assembly instructions	For half and full screw connections

## Classifications

### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202

### ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

## Approvals

### Approvals

---

Approvals

EAC

---

## Housing - HC-B 6-SMLD-74/O1PG21 - 1678156

### Approvals

Ex Approvals

---

Approvals submitted

---

### Approval details

EAC

---

### Accessories

#### Accessories

Full screw connection

Cable gland - G-INS-PG21-M68N-PNES-GY - 1411145



Cable gland, Cable gland material: Polyamide, External cable diameter 13 mm ... 18 mm, Shielding: No, Connecting thread: Pg21, Color: silver grey

---

Cable gland - G-INS-PG21-M68N-NNES-S - 1411175



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 13 mm ... 18 mm, Shielding: No, Connecting thread: Pg21, Color: silver

---

Cable gland - G-INSEC-PG21-M68N-NNES-S - 1411200



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 13 mm ... 18 mm, Shielding: Yes, Connecting thread: Pg21, Color: silver

---

Plug for cable screw gland

## Housing - HC-B 6-SMLD-74/O1PG21 - 1678156

### Accessories

Filler plugs - HC-BS-PG21 - 1674529




Filler plugs, for Pg screw connections, type Pg21

---

### Drawings

Dimensioned drawing

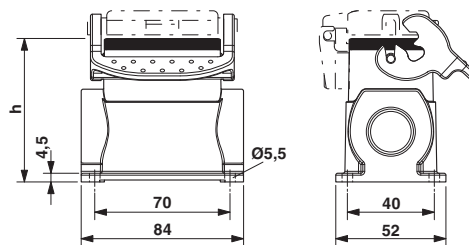

Dimensional drawing; h = 74 mm, a = 45 mm, b = 57 mm