


KEMET Part Number: EFX(01)-240X240T0800 **Not for New Design**
 (UFSEFX010AT080, EFX(01)240X240T0800)

KEMET, EFX, Flex Suppressors, Noise Suppression

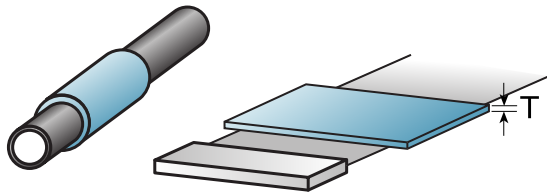

General Information	
Series:	EFX
Style:	Sheet
Description:	Flex Suppressor Halogen Free Type
Features:	High Magnetic Permeability
RoHS:	Yes
Qualifications:	UL94 HB, UL File No. E176124
Environment:	Halogen Free, PVC Free, Lead Free, Red Phosphorus Free
Notes:	Not recommended for new designs, please see FF1(100)-240X240T0800 for replacement

Dimensions	
Sheet Size	240x240mm
T	0.1mm +/-0.05mm

Packaging Specifications	
Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	0.03mm

Specifications	
Temperature Range:	-40/+105°C
Magnetic Permeability:	100 μ At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.2 Atm TYP
Conductivity:	0.22 W/m K
Tensile Strength:	6.8 MPa

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.