


# LabelWriter™ 450

DYMO®

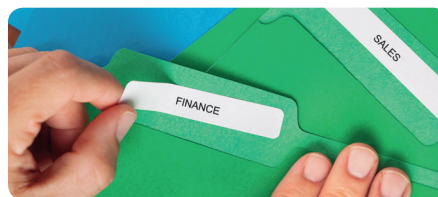

## Professional Label Printer for PC and Mac®

- No expensive ink or toner needed - uses thermal printing technology
- Customize and print address, shipping, file folder and barcode labels, plus name badges and more with DYMO® Label™ v.8 software—all from your PC or Mac®\*
- Save time – create labels directly from text in Microsoft® Word, Excel®, Outlook®, QuickBooks® and other programs or easily print addresses from Outlook® Contacts or Mac® Address Book
- Eliminate the waste and hassles of sheet labels — print precise quantities of labels
- Prints crystal-clear barcodes, labels and graphics with 600 x 300 dpi resolution
- Conserve power with “sleep mode”
- Create custom labels from 60+ label styles and layouts



LABELS



labels/min.\*

\* Compatible with Windows Vista®, Windows® 7, Windows® 8, Mac OS® X 10.5 or later – Intel® only

### Single Unit Includes:

- LabelWriter 450 Label Printer
- Address Labels Starter Roll
- Adapter
- Power Cable
- USB Cable
- Quick Start Guide – PC and Mac®
- Cleaning Card
- DYMO® Label™ v.8 Software Installation CD



### Quick Specs

|                             |                              |
|-----------------------------|------------------------------|
| Unit Dimensions (L x W x H) | 127 x 187 x 134mm            |
| Weight                      | 1.3 kg                       |
| Mac®/PC Compatible          | Yes                          |
| Max Label Width             | 58.42mm                      |
| Resolution                  | 600 x 300 dpi                |
| Printing System             | Direct Thermal               |
| Print Speed                 | 51 labels/minute*            |
| Barcodes                    | Yes                          |
| Power Source                | Adapter Power Cable          |
| Networking                  | Print Server Sold Separately |
| Country of Origin           | China                        |

\*4-line address label

| Item Number | Description               |        | Length (cm) | Width (cm) | Height (cm) | Weight (kg) | QTY | EAN            | Customer Price |
|-------------|---------------------------|--------|-------------|------------|-------------|-------------|-----|----------------|----------------|
| S0838810    | LabelWriter 450 ENG-UK/HK | Unit   | 14.0        | 27.0       | 16.3        | 1.6         | 1   | 3501170838815  |                |
|             |                           | Shelf  | -           | -          | -           | -           | -   | -              |                |
|             |                           | Case   | 43.0        | 27.8       | 35.0        | -           | 6   | 13501170838812 |                |
|             |                           | Pallet | 120.0       | 80.0       | 120.0       | -           | 108 | -              |                |
| Accessories |                           |        |             |            |             |             |     |                |                |
| 925106      | USB Cable                 | Unit   | -           | -          | -           | -           | -   | -              |                |
| 923772      | Power Cable               | Unit   | -           | -          | -           | -           | -   | -              |                |
| 922983      | Cleaning Card             | Unit   | -           | -          | -           | -           | -   | -              |                |
| 931160      | Switching Adapter         | Unit   | 29.7        | 24.2       | 16.3        | 0.5         | -   | -              |                |
| S0787940    | Spool 450 series          | Unit   | -           | -          | -           | -           | -   | -              |                |

dymo.com



**Print one label or hundreds – without the waste and hassles of sheet labels.**

| Label Type     | Description                    | Code #   | Size in mm  | Labels/Roll | Rolls/Box | Adhesive     | Material            |
|----------------|--------------------------------|----------|-------------|-------------|-----------|--------------|---------------------|
| Mailing        | Standard Address Labels        | S0722370 | 28 x 89     | 130         | 2         | Permanent    | Paper               |
|                | Standard Address Labels        | S0722360 | 28 x 89     | 130         | 24        | Permanent    | Paper               |
|                | Assorted Colour labels         | S0722380 | 28 x 89     | 130         | 2         | Permanent    | Paper               |
|                | Large Address Labels           | S0722400 | 36 x 89     | 260         | 2         | Permanent    | Paper               |
|                | Large Address Labels           | S0722390 | 36 x 89     | 260         | 24        | Permanent    | Paper               |
|                | Large Address Labels           | S0722410 | 36 x 89     | 260         | 1         | Permanent    | Transparent Plastic |
|                | Large Return Address Label     | S0722520 | 25 x 54     | 500         | 1         | Permanent    | Paper               |
| Shipping       | Shipping / Name badge Labels   | S0722430 | 54 x 101    | 220         | 1         | Permanent    | Paper               |
|                | Shipping / Name badge Labels   | S0722420 | 54 x 101    | 220         | 12        | Permanent    | Paper               |
| Multit-Purpose | Multi-Purpose Labels           | S0722530 | 13 x 25     | 1000        | 1         | Removable    | Paper               |
|                | Square Multi-Purpose Labels    | S0929120 | 25 x 25     | 750         | 1         | Removable    | Paper               |
|                | Multi-Purpose Labels           | S0722550 | 19 x 51     | 500         | 1         | Removable    | Paper               |
|                | Multi-Purpose Labels           | S0722540 | 57 x 32     | 1000        | 1         | Removable    | Paper               |
|                | Large Multi-Purpose Labels     | S0722440 | 54 x 70     | 320         | 1         | Permanent    | Paper               |
| Specialty      | Suspension file labels         | S0722460 | 12 x 50     | 220         | 1         | Permanent    | Paper               |
|                | LAF Labels small               | S0722470 | 38 x 190    | 110         | 1         | Permanent    | Paper               |
|                | LAF Labels large               | S0722480 | 59 x 190    | 110         | 1         | Permanent    | Paper               |
|                | Small name badge label         | S0722560 | 41 x 89     | 300         | 1         | Removable    | Paper               |
|                | Appointment / name badge cards | S0929100 | 51 x 89     | 300         | 1         | Non-adhesive | Paper               |
|                | Large name badge cards         | S0929110 | 62 x 106    | 250         | 1         | Non-adhesive | Paper               |
|                | CD Labels                      | S0719250 | 57 diameter | 160         | 1         | Permanent    | Paper               |

Country of Origin: Belgium

**DISTRIBUTED BY:**  
Newell Europe Sàrl  
Chemin de Blandonnet 10  
1214 Vernier – Switzerland  
WWW.DYMO.COM



A **Newell Rubbermaid** Brand

This information is being provided for general information purposes and the compliance standards and certifications referenced herein are based on current standards which are subject to change.

©2014 Newell Europe LLC

|                             |                                                                                                                                                                                                     |                                                                                                                                                                                                   |
|-----------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| A NewellRubbermaid Company™ | <b>SCHAWK!</b><br><small>RMZ Milenia Business Park<br/>Campus - 2, 20th Floor<br/>No. 145, Dr.M. G. R. Road<br/>Hundur Chowd [Chennai 600 036 India<br/>T +91 44 4253 7777   www.schawk.com</small> | <div><div>CYAN</div><div>MAGENTA</div><div>YELLOW</div><div>BLACK</div></div>                                                                                                                     |
|                             | Use the PANTONE MATCHING SYSTEM for accurate color reproduction                                                                                                                                     |                                                                                                                                                                                                   |
|                             | <b>VERSION</b>                                                                                                                                                                                      | <b>JOB DESCRIPTION</b> : NRM_EU_Writing_Dymo_1362812_EMEA Product Handbooks_UK Masters<br><b>FILE NAME</b> : DY_1362812_2014_EMEA_LW450_TechSheet_v7.indd<br><b>BRAND</b> : WRITING-DYMO          |
|                             | <b>7</b><br><b>DATE</b> : 10-01-2014<br><b>OPERATOR</b> : MKS                                                                                                                                       | <b>SCHAWK JOB #</b> : 310253D<br><b>NRM JOB #</b> : 1362812<br><b>COMPONENT #</b> : N/A<br><b>CATEGORY OF WORK</b> : COLLATERALS-FACT BOOKS<br><b>NO. OF PAGES#</b> : 2 PAGES<br><b>SIZE</b> : A4 |
|                             | <b>NOTE</b> :                                                                                                                                                                                       |                                                                                                                                                                                                   |