

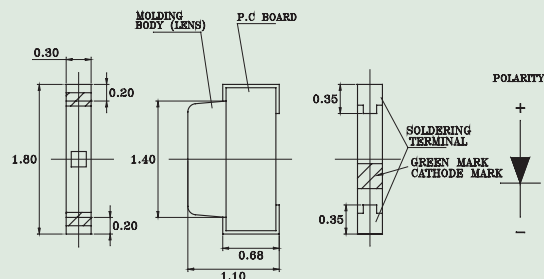
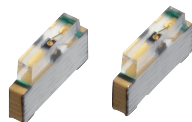


Side View Chip LED 1.8(L) x 1.1(W) x 0.3(H)mm

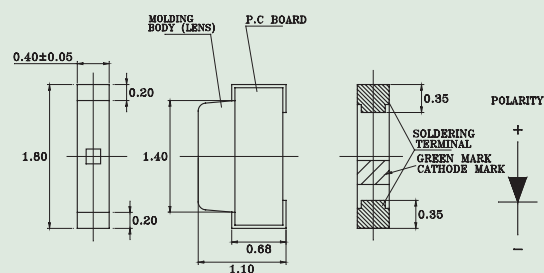

Part No.	Material	Lens Color	Wd	Viewing Angle 2 $\theta_{1/2}^*$	I _v Typ. @ 5mA	V _F Typ. @ 5mA	Tape and Reel
LTST-S482TBKT-5A	InGaN Blue	Water Clear	■ 470nm	130°	28mcd	2.9V	3,000 pcs per Reel
LTST-S482TGKT-5A	InGaN Pure Green	Water Clear	■ 525nm	130°	90mcd	2.9V	3,000 pcs per Reel
LTST-S482KGKT-5A	AlInGaP Yellow Green	Water Clear	■ 571nm	130°	12mcd	1.9V	3,000 pcs per Reel
LTST-S482KSKT-5A	AlInGaP Yellow	Water Clear	■ 589nm	130°	22mcd	1.9V	3,000 pcs per Reel
LTST-S482KFKT-5A	AlInGaP Orange	Water Clear	■ 605nm	130°	24mcd	1.9V	3,000 pcs per Reel
LTST-S482KRKT-5A	AlInGaP Red	Water Clear	■ 631nm	130°	14mcd	1.9V	3,000 pcs per Reel
LTW-482DS5	InGaN White	Yellow	(0.30, 0.29)	130°	71mcd	2.9V	3,000 pcs per Reel

Side View Chip LED 1.8(L) x 1.1(W) x 0.4(H)mm

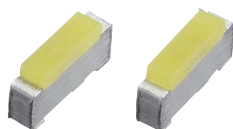

Part No.	Material	Lens Color	Wd	Viewing Angle 2 $\theta_{1/2}^*$	I _v Typ. @ 5mA	V _F Typ. @ 5mA	Tape and Reel
LTST-S481TBKT-5A	InGaN Blue	Water Clear	■ 470nm	130°	28mcd	2.9V	3,000 pcs per Reel
LTST-S481TGKT-5A	InGaN Pure Green	Water Clear	■ 525nm	130°	90mcd	2.9V	3,000 pcs per Reel
LTST-S481KGKT-5A	AlInGaP Yellow Green	Water Clear	■ 571nm	130°	12mcd	1.9V	3,000 pcs per Reel
LTST-S481KSKT-5A	AlInGaP Yellow	Water Clear	■ 589nm	130°	22mcd	1.9V	3,000 pcs per Reel
LTST-S481KFKT-5A	AlInGaP Orange	Water Clear	■ 605nm	130°	24mcd	1.9V	3,000 pcs per Reel
LTST-S481KRKT-5A	AlInGaP Red	Water Clear	■ 631nm	130°	14mcd	1.9V	3,000 pcs per Reel
LTW-481DS5	InGaN White	Yellow	(0.30, 0.29)	130°	71mcd	2.9V	3,000 pcs per Reel