



ENGLISH


Datasheet

RS 13A 1 Gang Switched Surface Mount Fused Connection Unit IP66

RS Stock 699-7109



Dimensions (mm)

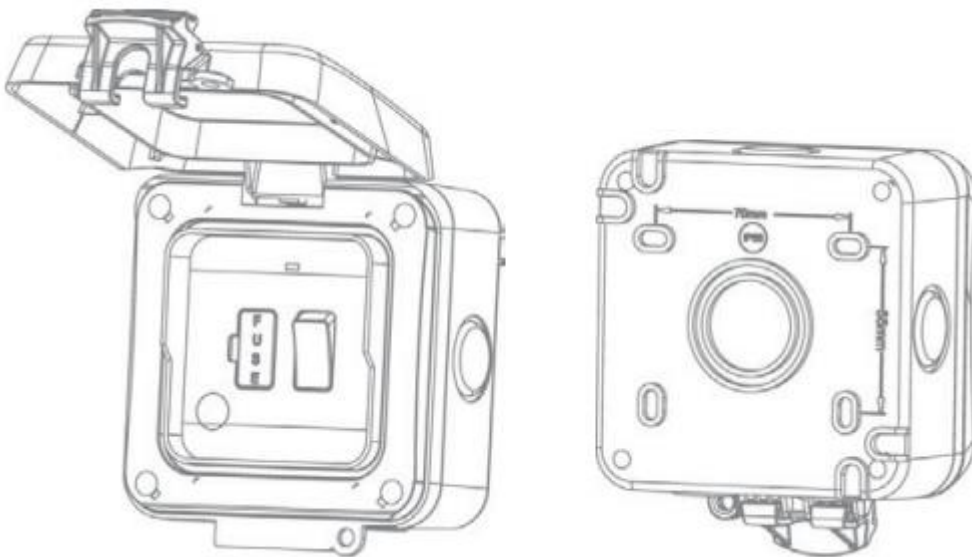



Features:

- IP66 Rated, Weather & dust protection:
High level of protection against ingress from water jets & dust, the durable seals will maintain integrity over the product's life
- Angled colour coded terminals with captive screws
- Ergonomic front cover/Lid:
Bright LED power indicator visible through see-through cover
Hinged cover has simple press to open or press to close operation
Lockable cover
- Multiple gland entry positions:
5 versatile entry options with M25 capability with an easy push out blank plug design
One cut out entry option on rear
- Robust construction:
Polycarbonate housing
High impact resistance
Long lasting, will not crack or fade

Technical Specifications

Standard(s)	BS1363-4
Rating	3,120 Watts Max, 13A 240V ~
Terminal Capacity	3 x 2.5mm ² , 2 x 4.0mm ² & 1 x 6.0mm ²
IP Rating	IP66
RoHS Directive	No
WEEE Directive	No
	Fixings, wall plugs and sealant not included