


Data sheet CONNECTOR TC

RS Stock No. 370-6650

ENGLISH

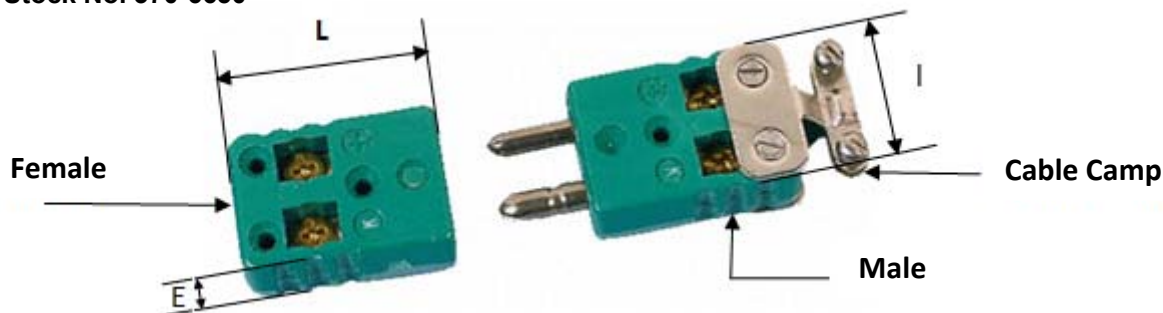

THERMOCOUPLE CONNECTOR	
MAXIMAL TEMPERATURE :	
<ul style="list-style-type: none"> Standard : 200°C Hight Temperature (HT) : 420°C 	
USE : Connector for thermocouple with quick connection without screwing (jab in)	
COLORS :	
<ul style="list-style-type: none"> <u>Standard :</u> <ul style="list-style-type: none"> K : Green J : Black S : Orange <u>High Temperature :</u> <ul style="list-style-type: none"> Red 	
DIMENSIONS : L = 33.34 mm; I = 25.4 mm; E = 12.7 mm	
OPTIONS : Cable camp	

Other Dimension :

Type \	J	K	S
Male			
Standard	334-2694	334-2672	
Standard HT		370-6650	370-6666

Type \	J	K	S
Female			
Standard	334-2717	334-2701	
Standard HT		370-6672	370-6694

	Code
Cable camp	334-6393